




Z-PACK 2mm FutureBus+ Connectors (Continued)

IEC61076-4-0X(48B)

5 Row — Power Modules, Right Angle Receptacle Assemblies (Free-Board Connector), 2mm x 2mm Circuit Grid

 Receptacle Assemblies with Solder Leads and Compliant Press-Fit Leads (10 Positions)



Material and Finish:

Housing — Liquid crystal polymer

Receptacle Contacts Phosphor bronze, duplex plated gold flash over 0.0003 min. palladium-nickel on mating surface, 0.0038 min. tin-lead on solder lead, with entire contact underplated 0.0013 nickel

Related Product Data

Material Specifications — page 293

Compliant Press-Fit Contact Specifications — page 293

Application Tooling — page 360

Technical Documents

Product Specification

108-1441

Application Specification


114-1075

Instruction Sheets


408-6927, 408-9910, 408-9979

Electrical Performance Report

1242176

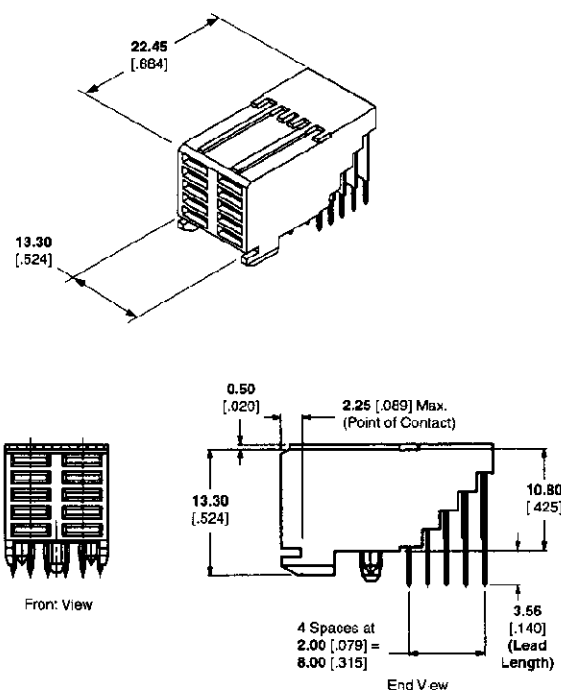

Compliant Press-Fit Leads

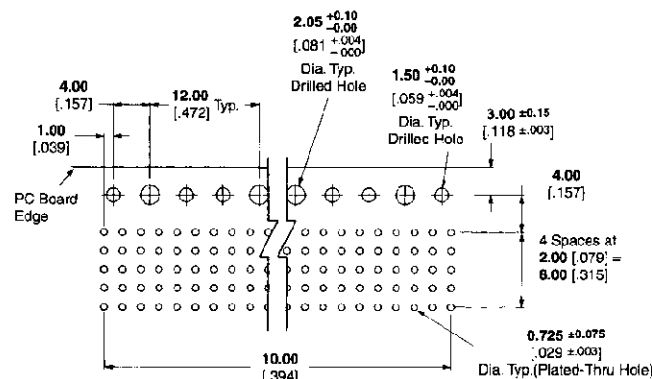

Recommended PC Board Hole Layout
per IPC-D-300, Type II, Class C
(Component Side)

Receptacle Assembly

No. of Positions	Part Number	Seating Tooling
	with Press-Fit Leads	
10	536649-1	Industry Standard Flat Rock