
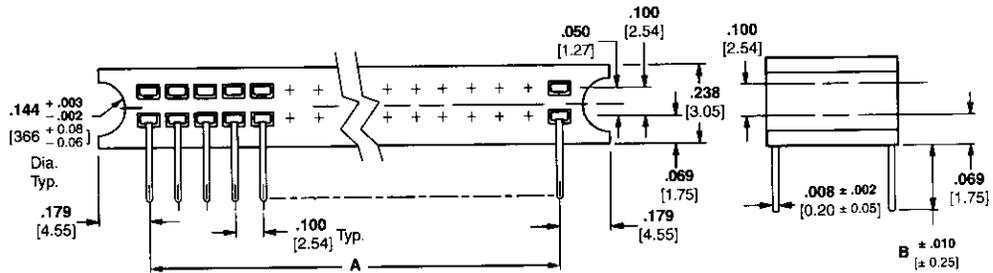
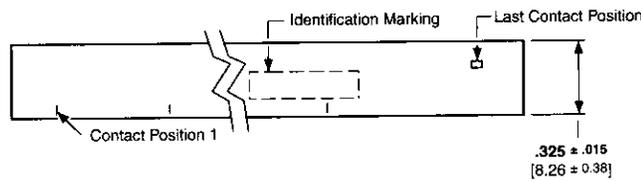


Special Double Row Receptacle Assemblies

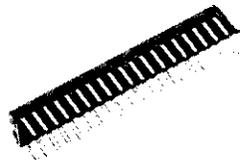

Material and Finish:

Housing — In accordance with MIL-C-55302 or MIL-M-24519 type GST-40F


Contacts — Per MIL-C-55302

Plating Codes:

A — Gold flash over .000050 [0.00127] min. nickel on entire contact, .000050 [0.00127] min. gold on contact area

B — .000050 [0.00127] min. gold over .000050 [0.00127] min. nickel on the entire contact

No. of Pos.	Dimensions		Board Thickness	Plating Code A		Plating Code B	
	A	B		Military Part No M55302/128-	Part No.	Military Part No. M55302/128-	Part No.
22	1.000	.115	.062	AK2A	102192-5	—	—
	25.40	2.92	1.57				
26	1.200	.175	.125	AM2E	102281-6	—	—
	30.48	4.45	3.18				
50	2.400	.115	.062	BH2A	102192-8	—	—
	60.96	2.92	1.57				
		.145	.093	—	—	BH2D	102196-8
		3.68	2.36				
54	2.600	.115	.062	—	—	BK2B	102193-3
	66.04	2.92	1.57				
58	2.800	.115	.062	BM2A	102192-2	BM2B	102193-2
	71.12	2.92	1.57				
60	2.900	.115	.062	BN2A	102192-4	—	—
	73.66	2.92	1.57				
80	3.900	.115	.062	CG2A	102192-9	—	—
	99.08	2.92	1.57				
84	4.100	.115	.062	—	—	CJ2B	102193-1
	104.14	2.92	1.57				
100	4.900	.115	.062	DA2A	1-102192-0	DA2B	1-102193-0
	124.46	2.92	1.57				
102	5.000	.115	.062	—	—	DB2B	102193-7
	127.00	2.92	1.57				

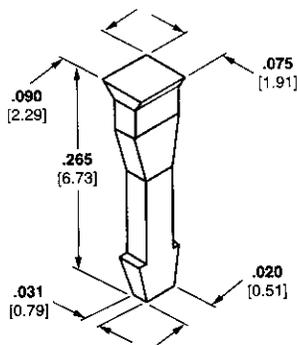

Keying Plug —
Military Part Number
M55302/127-00KY
Part Number 102188-1