

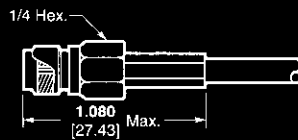


Jack

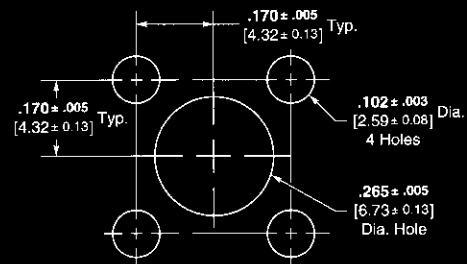

RG/U	Part No.	Body Material and Finish	Center Contact Crimp			Ferrule Crimp	
			Military Tool	Positioner	Setting	Military Tool	Die Part No.
58, 58A, 58B, 58C	447648-1	Brass, Ni plated	M22520/2-01	K997	6	M22520/5-01	M25520/5-11 A
142, 142A, 142B	447648-2	Brass, Ni plated	M22520/2-01	K997	7	M22520/5-01	M22520/5-11 A
174, 174A, 188, 188A, 316	447648-3	Brass, Ni plated	M22520/2-01	K997	4	M22520/5-01	M22520/5-35 B
174DB, 188DB, 316DB	447648-4	Brass, Ni plated	M22520/2-01	K997	4	M22520/5-01	M22520/5-35 B



Panel Jack

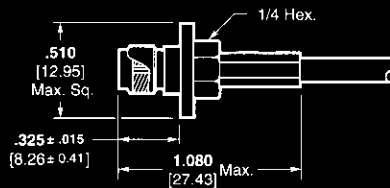

Recommended Panel Cutout

RG/U	Part No.	Body Material and Finish	Center Contact Crimp			Ferrule Crimp	
			Military Tool	Positioner	Setting	Military Tool	Die Part No.
58, 58A, 58B, 58C	447649-1	Brass, Ni plated	M22520/2-01	K997	6	M22520/5-01	M25520/5-11 A
142, 142A, 142B	447649-2	Brass, Ni plated	M22520/2-01	K997	7	M22520/5-01	M22520/5-11 A
174, 174A, 188, 188A, 316	447649-3	Brass, Ni plated	M22520/2-01	K997	4	M22520/5-01	M22520/5-35 B
174DB, 188DB, 316DB	447649-4	Brass, Ni plated	M22520/2-01	K997	4	M22520/5-01	M22520/5-35 B
Belden YR20621 (RG58 Type)	447649-5	SST, passivated	M22520/2-01	K997	6	M22520/5-01	M22520/5-11 A
174, 174A, 188, 188A, 316	447649-6	SST, passivated	M22520/2-01	K997	4	M22520/5-01	M22520/5-35 B

Bulkhead Jack

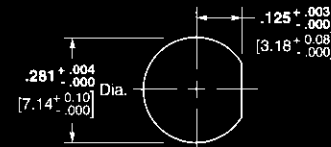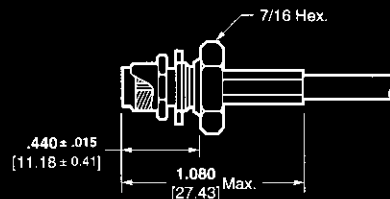

Recommended Panel Cutout

RG/U	Part No.	Body Material and Finish	Center Contact Crimp			Ferrule Crimp	
			Military Tool	Positioner	Setting	Military Tool	Die Part No.
58, 58A, 58B, 58C	447650-1	Brass, Ni plated	M22520/2-01	K997	6	M22520/5-01	M25520/5-11 A
142, 142A, 142B	447650-2	Brass, Ni plated	M22520/2-01	K997	7	M22520/5-01	M22520/5-11 A
174, 174A, 188, 188A, 316	447650-3	Brass, Ni plated	M22520/2-01	K997	4	M22520/5-01	M22520/5-35 B
174DB, 188DB, 316DB	447650-4	Brass, Ni plated	M22520/2-01	K997	4	M22520/5-01	M22520/5-35 B
Belden YR20621 (RG58 Type)	447650-5	SST, passivated	M22520/2-01	K997	6	M22520/5-01	M22520/5-11 A
174, 174A, 188, 188A, 316	447650-6	SST, passivated	M22520/2-01	K997	4	M22520/5-01	M22520/5-35 B
142, 142A, 142B	447650-7	SST, passivated	M22520/2-01	K997	7	M22520/5-01	M22520/5-11 A
174DB, 188DB, 316DB	447650-8	SST, passivated	M22520/2-01	K997	4	M22520/5-01	M22520/5-35 B