

PQFP Sockets (MICRO-PITCH) — Standard (Continued)**Materials and Finish**

Housing — High temperature thermoplastic, 94V-0 rated, black

Cover — Polyphenylene sulfide (PPS), 94V-0 rated, black

Contacts — Phosphor bronze with .000200 [.000508] tin over .000050 [.00127] nickel



Insertion Hand Tools

100 Pos. 822253-1

132 Pos. 822253-2

**Extraction Tool**

Part No. 822254-1

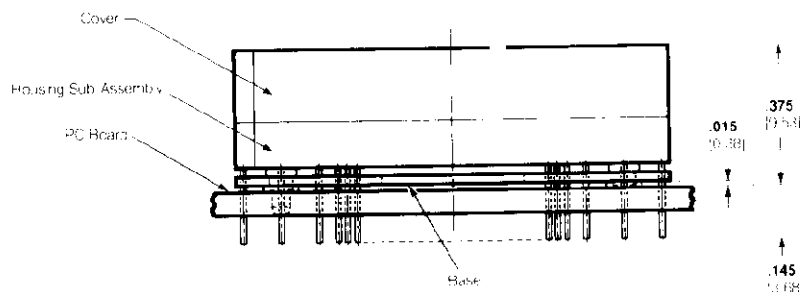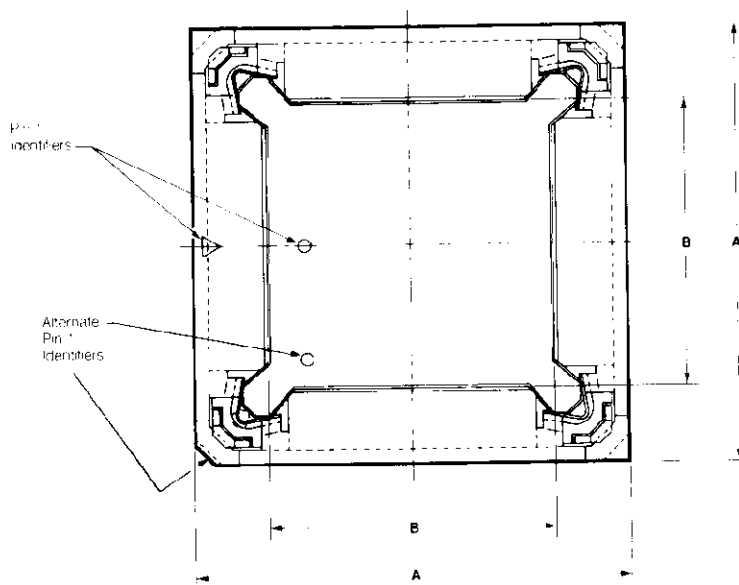

No. of Pos.	Dimensions		Conventional AMP Sockets		Replacement for 3M TEXTOL Sockets	
	A	B	Housing Sub-Assembly	Cover	Housing Sub-Assembly	Cover
100	1.140 28.96	.750 19.05	821949-4	821939-1	822064-4	821939-1
132	1.340 34.04	.950 24.13	821949-5	821942-1	822064-5	821942-1

¹Conventional footprint: see page 90.

²Reverse footprint: see page 91

Packaging Quantities:

100 Position — 19 Pcs./Tube, 54 Tubes/Box Total = 1026 Pcs./Box

132 Position — 16 Pcs./Tube, 45 Tubes/Box Total = 720 Pcs./Box