


Tab Contacts

**Tabs 3.0 x 0.64 mm,
Mates with
MIC I Receptacles**

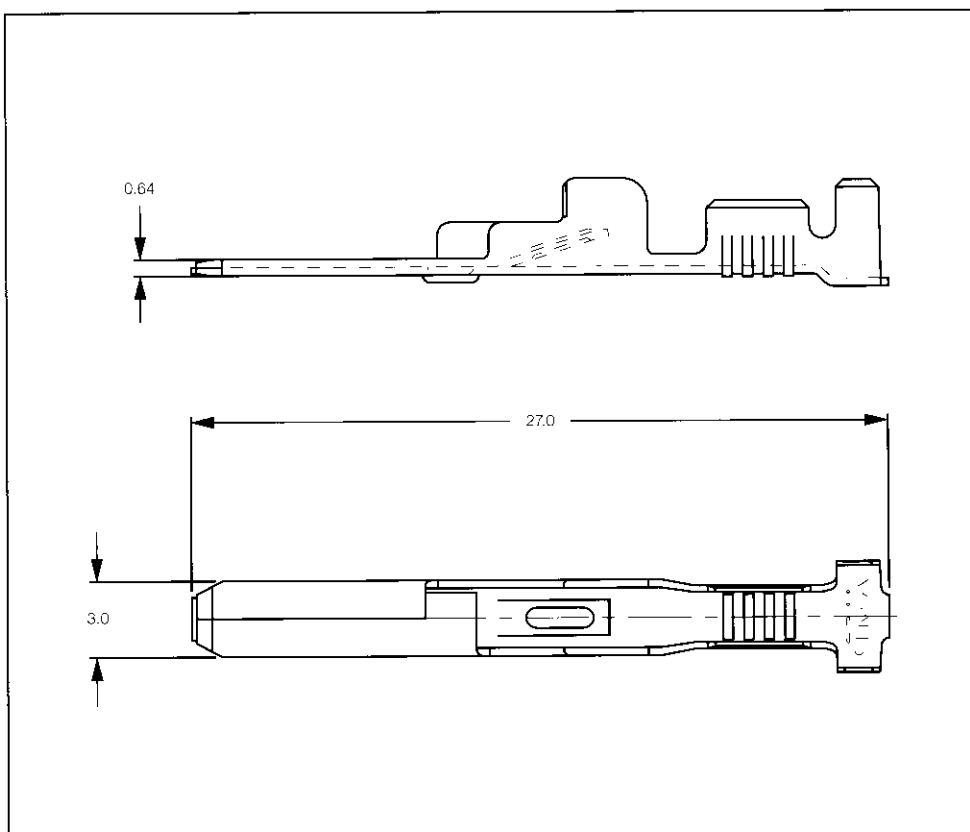

Tab Contacts

Wire Size Range mm ² (AWG)	Insulation Diameter		Material and Finish	Part Numbers				Applicator	Hand Tool
	FLK mm (Inch)	FLR mm (Inch)		Strip Form	Packaging Unit	Loose-Piece	Packaging Unit		
0.35-1.0 (22-17)	2.1 max. (.083 max.)	-	CuZn, pre-tin plated	142184-1	4,000	142315-1	100 or 1,000	1-482378-5	944032-1
			CuZn, gold plated	142184-5	4,000	142315-5	100 or 1,000		
1.0-3.0 (17-12)	3.3 max. (.130 max.)	-	CuZn, pre-tin plated	142186-1	3,000	142317-1	100 or 500	7-482378-0	944031-1

Additional finishes upon request