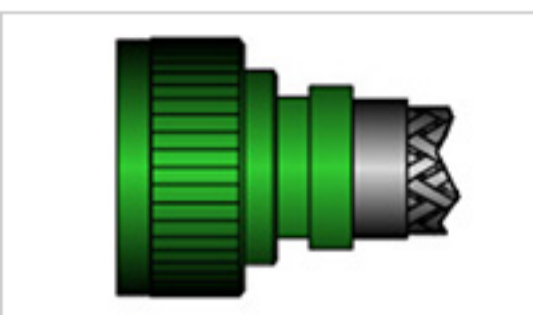


204M010-19B05-12 Product Details

[Share](#) | [Print](#) | [Email](#)


✓ Active

Braid, Fixed, Spin and Tinel Lock Adapters

204M010-19B05-12
204M010-19B05-12
 TE Internal Number: 040869-000

Product Highlights [View All](#)

- Applies To Cable
- Military Style Number = MIL-DTL-38999
- Style = Braided
- Connector Code = 41
- Straight

- [Pricing & Availability](#)
- [Request Sample](#)
- [Add to My Part List](#)
- [Buy Product through Distributor](#)

[Documents](#) | [Features](#) | [Compliance](#)

Related Products

Not quite the product you're looking for?
[Find Similar Products](#)

[View Part in Product Feature Selector](#)

[Check for Tooling](#)

Feedback

Please Note:
 Use the Product Drawing for all design activity

Product Type Features	
Style ?	Braided
Angle ?	Straight
Connector Shell Size	10
Finish	Cadmium Plating over Electroless Nickel
Color	Olive Drab

Industry Standards	
Government/Industry Qualification	No
Military Style Number	MIL-DTL-38999
RoHS/ELV Compliance ?	Not ELV/RoHS compliant
Lead Free Solder Processes ?	Not relevant for lead free process

Dimensions	
Boot Diameter (mm [in]) ?	13.10 [0.515]

Conditions for Usage	
Applies To	Cable

Body Features	
Connector Code ?	41
Entry Size	5
Material	Aluminum Alloy

Other	
Brand	Raychem
Comment	For Specific shell size information, refer to Harnware™ or Catalouge.; 12" Braid instead of standard 6" Braid.

- Corporate Information**
- [About TE](#)
 - [Investors](#)
 - [News Room](#)
 - [Supplier Portal](#)
 - [Careers](#)
 - [Terms & Conditions](#)
 - [Privacy Policy](#)
 - [Global Accessibility Statement](#)

- Quick Links**
- [Distributor Inventory](#)
 - [Product Cross Reference](#)
 - [Documents & Drawings](#)
 - [Product Compliance Support Center](#)
 - [Site Map](#)

- Customer Support**
- [Email or Chat With Us](#)
 - [Find a Phone Number](#)
 - [Knowledge Base](#)
 - [Manage Your Account](#)

Keep Me Informed