



Search by part # or keyword

[Products](#)

[Industries & Solutions](#)

[Resources](#)

[TE Store](#)


[Sign In](#)



[Harnessing](#) > [Heat Shrink Components](#) > [Feedthroughs & Cable Entry Seals](#)

207W256-3-01/42-0

207W256-3-01/42-0

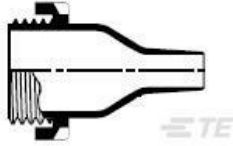

Raychem

TE Internal #: **878129-000**

TE Internal Description: **207W256-3-01/42-0**

Alias #: **3-1196833-5**

Product Type : **Cable Entry**

Seals/Feedthroughs

Threaded End Inside Diameter : **45 mm [1.77 in]**

Nut Type : **B**

Power Cable Accessory : **No**

Color : **Black**

[Similar Products](#)

Compatible Parts & Tooling

We are here to help!

Get in touch with our product experts.



[CHAT WITH US](#)



[EMAIL US](#)



[CALL US](#)

Feedback

Documents

Features

Product Compliance

Datasheets & Catalog Pages

1654025_Sec4_-3
[ENG_CS_1654025_Sec4_-3_0313.pdf](#) English

Product Environmental Compliance

- Safety Datasheet
[DUT_MSDS_RAY3143-EC-DUT_2014-06-11_3143ECN.pdf](#) Dutch
- Safety Datasheet
[ENG_MSDS_RAY3143-EC-ENG_2014-06-11_3143ECE.pdf](#) English
- Safety Datasheet
[FRE_MSDS_RAY3143-EC-FRE_2014-06-11_3143ECF.pdf](#) French
- Safety Datasheet
[GER_MSDS_RAY3143-EC-GER_2014-06-11_3143ECD.pdf](#) German
- Safety Datasheet
[ITA_MSDS_RAY3143-EC-ITA_2014-06-11_3143ECI.pdf](#) Italian
- Safety Datasheet
[SPA_MSDS_RAY3143-EC-SPA_2014-06-11_3143ECS.pdf](#) Spanish
- Safety Datasheet
[SWE_MSDS_RAY3143-EC-SWE_2014-06-11_3143ECW.pdf](#) Swedish
- Safety Datasheet
[ENG_MSDS_RAY3143-US-ENG_B.pdf](#) English
- Safety Datasheet

[FRE_MSDS_SDS0190-EC-FRE_2014-04-10.pdf](#)

French

Safety Datasheet

[ITA_MSDS_SDS0190-EC-ITA_2014-04-10.pdf](#)

Italian

Safety Datasheet

[NOR_MSDS_SDS0190-EC-NOR_2014-04-10.pdf](#)

Norwegian

Safety Datasheet

[DAN_MSDS_SDS0190-EC-DAN_2014-04-10.pdf](#)

Danish

Safety Datasheet

[ENG_MSDS_SDS0190-EC-ENG_2014-04-10.pdf](#)

English

Safety Datasheet

[GER_MSDS_SDS0190-EC-GER_2014-04-10.pdf](#)

German

Safety Datasheet

[SPA_MSDS_SDS0190-EC-SPA_2014-04-10.pdf](#)

Spanish

Safety Datasheet

[SWE_MSDS_SDS0190-EC-SWE_2014-02-21_SDS190ECW.pdf](#)

Swedish

Safety Datasheet

[DUT_MSDS_SDS0190-EC-DUT_2014-04-10.pdf](#)

Dutch

Please review product documents or [contact us](#) for the latest agency approval information.

Product Type
Features

Product Type : **Cable Entry Seals/Feedthroughs**

Size Code : **56**

Included O-Ring : **No**

Body Features

Material Code : **3**

Nut Type : **B**

Color : **Black**

Material : **Modified Polyolefin**

Pliancy : **Semi-Rigid**

Adhesive Pre-Coat : **Yes**

Mechanical
Attachment

Mounting Hole Diameter : **85.1 mm [3.35 in]**

Dimensions

Threaded End Inside Diameter : **45 mm [1.77 in]**

Expanded Inside Diameter (Min) : **62.5 mm [2.46 in]**

Recovered Inside Diameter (Max) : **30 mm [1.181 in]**

Recovered Wall Thickness (Nominal) : **3.05 mm [.12 in]**

Length : **122 mm [4.8 in]**

Usage Conditions

Resistant To : **Abrasion, Fluids, Mechanical Damage, Strain**

Resistance Properties : **Immersion Protection**

Operation/Application Power Cable Accessory : **No**

Industry Standards

Government Qualified : **No**

Other

Adhesive Type : **General Purpose Pre-Coat Adhesive**
Adhesive Code : **42**

EU RoHS Directive 2011/65/EU

This declaration covers EU Directive 2011/65/EU incl. Delegated Directive 2015/863/EU. The restrictions under 2015/863/EU apply as of 22 July 2021 for EEE categories 8 (medical devices) and 9 (monitoring and control equipment).

EU ELV Directive 2000/53/EC

China RoHS 2 Directive MIIT Order No 32, 2016

EU REACH Regulation (EC) No. 1907/2006

Current ECHA Candidate List: **JAN 2019 (197)**
Candidate List Declared Against: **JAN 2019 (197)**

Halogen Content

Solder Process Capability

Not applicable for solder process capability

Statement of Compliance

[Statement of Compliance pdf](#)

Compliance Documents

There may be Environmental Compliance related documents on the [DOCUMENTATION Tab](#)

Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU.

Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Products with Similar Specs

[View All Similar Products](#)


THIS PRODUCT

TOP RESULTS

FEEDTHROUGHS

207W256-3-01/42-0

207W256-3-01/42-0

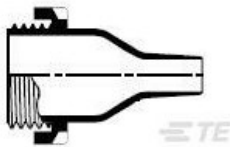

In-Stock

Product Type : **Cable Entry Seals/Feedthroughs**

Threaded End Inside Diameter : **45 mm**

Nut Type : **B**


Power Cable Accessory : **No**

Color : **Black**

FEEDTHROUGHS

207W256-3/42-0

207W256-3/42-0

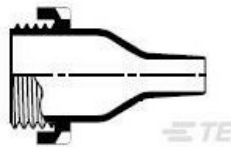

Non-Stocked

Product Type : **Cable Entry Seals/Feedthroughs**

Threaded End Inside Diameter : **45 mm**

Nut Type : **A**


Power Cable Accessory : **No**

Color : **Black**

FEEDTHROUGHS

207W256-25/225-0

207W256-25/225-0

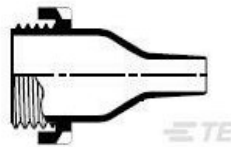

Non-Stocked

Product Type : **Cable Entry Seals/Feedthroughs**

Threaded End Inside Diameter : **45 mm**

Nut Type : **A**


Power Cable Accessory : **No**

Color : **Black**

FEEDTHROUGHS

207W256-3-01-0

207W256-3-01-0

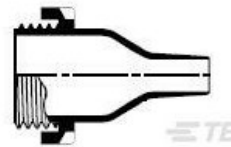

Non-Stocked

Product Type : **Cable Entry Seals/Feedthroughs**

Threaded End Inside Diameter : **68.1 mm**

Nut Type : **B**

Power Cable Accessory : **No**

Color : **Black**

[ABOUT TE CONNECTIVITY](#)

[FOR PARTNERS](#)

[SUPPORT](#)

[CALL US](#)

[LIVE CHAT](#)

[UNITED STATES \(EN\)](#)