


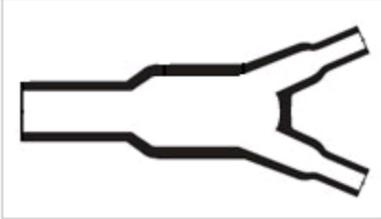

382A034-100/86-0 Product Details

[Share](#) [Print](#) [Email](#)


Active

Molded Parts

382A034-100/86-0

382A034-100/86-0

TE Internal Number: 245099-000

Product Highlights [View All](#)

- VG95343 Parts 29 and 30
- Molded Part Type = Transition
- Molded Part Shape = Y Shape
- Molded Part Lip = Without Lip
- Operating Temperature = -30 - 80 °C

[Pricing & Availability](#)

[Request Sample](#)

[Add to My Part List](#)

[Buy Product through Distributor](#)

Feedback

Documents

Features

Compliance

Please Note:

Use the Product Drawing for all design activity

Product Type Features		Configuration Features	
Molded Part Type	Transition	Material Code	100
Molded Part Shape	Y Shape	Number of Branches/Legs	2
Molded Part Lip	Without Lip	Industry Standards	
Angle	22.5°	Government/Industry Qualification	No
Adhesive Description	High Performance Pre-Coat Adhesive	Approved Standards	VG95343 Parts 29 and 30
Size	34	RoHS/ELV Compliance	RoHS compliant, ELV compliant
Family Name	382A0	Lead Free Solder Processes	Not relevant for lead free process
Color	Black	RoHS/ELV Compliance History	Always was RoHS compliant
Mechanical Attachment		Environmental	
Adhesive Pre-Coating	With	Operating Temperature (°C)	-30 - +80
Dimensions		Operation/Application	
Cable Diameter Range (mm [in])	18.00 - 38.60 [0.710 - 1.520]	Application	General Purpose
1st Branch/Leg Range (mm [in])	12.40 - 26.90 [0.488 - 1.059]	Purchasing Information	
2nd Branch/Leg Range (mm [in])	12.40 - 27.00 [0.488 - 1.063]	Adhesive Code	86
Expanded ID, Min. (mm [in])	38.50 [1.520]	Other	
Recovered ID, Max. (mm [in])	18.00 [0.710]	Brand	Raychem
Body Features			
Transition Type	Y Shape		
Material	Polyolefin Flexible Modified		
Housing Features			
Material Systems Code	100		
Max. Inside Diameter of Part (mm [in])	18.00 [0.710]		

Related Products

Not quite the product you're looking for?

[Find Similar Products](#)

[View Part in Product Feature Selector](#)

[Check for Tooling](#)

Corporate Information

- [About TE](#)
- [Investors](#)
- [News Room](#)
- [Supplier Portal](#)
- [Careers](#)
- [Terms & Conditions](#)
- [Privacy Policy](#)
- [Global Accessibility Statement](#)

Quick Links

- [Distributor Inventory](#)
- [Product Cross Reference](#)
- [Documents & Drawings](#)
- [Product Compliance Support Center](#)
- [Site Map](#)

Customer Support

- [Email or Chat With Us](#)
- [Find a Phone Number](#)
- [Knowledge Base](#)
- [Manage Your Account](#)

Keep Me Informed

