


D-602-0095 Product Details

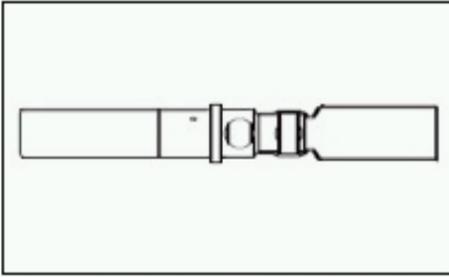

D-602-0095

TE Part Number: 601096-000

 [Active](#)

 [Add to Part List](#)

Contacts (SolderTact)

[Not EU RoHS or ELV Compliant](#)

Product Highlights:

- MIL-C-83723 Series
- Contact Size = 12
- Polarity = Socket
- Cable Type = Coaxial

[View all Features](#) |
 [Find Similar Products](#)

Quick Links

- ▶ [Check Pricing & Availability](#)
- ▶ [Search for Tooling](#)
- ▶ [Product Feature Selector](#)
- ▶ [Contact Us About This Product](#)
- ▶ [Request Samples](#)

NEW!

Documentation & Additional Information

Product Drawings:

- [Contact, Coaxial Socket](#) (PDF, English)

Catalog Pages/Data Sheets:

- [Wire and Cable, Harnessing and Protection Products](#) (PDF, English)

Product Specifications:

- None Available

Application Specifications:

- None Available

Instruction Sheets:

- None Available

CAD Files:

- None Available

Related Products:

- [Tooling](#)

[List all Documents](#)

Product Features (Please use the Product Drawing for all design activity)

Product Type Features:

- Connection Type = Solder
- Comment = M39029/73 QPL

Body Related Features:

- [Series](#) = MIL-C-83723
- [Polarity](#) = Socket

Contact Related Features:

- [Contact Size](#) = 12

Configuration Related Features:

- [Cable Type](#) = Coaxial

Industry Standards:

- Government/Industry Qualification = Yes
- Government/Industry Part Number = M39029/73-397
- [RoHS/ELV Compliance](#) = Not ELV/RoHS compliant
- [Lead Free Solder Processes](#) = Not relevant for lead free process

Conditions for Usage:

- Operating Temperature (Max.) (°C) = 150

Operation/Application:

- Application Type = Shielded contacts

Other:

- Brand = Raychem