


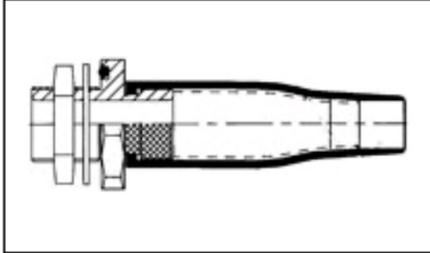

## TCFS-24-62C-020-100CH Product Details

[Share](#) | [Print](#) | [Email](#)


TCFS-24-62C-020-100CH

TE Internal Number: 486005-000

[Active](#)

### Heat Shrinkable Cable Kits and Assemblies

[Always EU RoHS/ELV Compliant \(Statement of Compliance\)](#)

#### Product Highlights:

- Heat Shrinkable Cable Feedthrough
- Mount Type = Bulkhead Feedthrough
- Thread Size = M24 x 1.5
- Stainless Steel Feedthrough Material
- Electroless Nickel Feedthrough Finish

[View all Features](#)

#### Quick Links

- ▶ [Check Pricing & Availability](#)
- ▶ [Search for Tooling](#)
- ▶ [Product Feature Selector](#)
- ▶ [Contact Us About This Product](#)

[Add to My Part List](#) [Request Sample](#) [Find Similar Products](#) [Buy Product](#)

### Documentation & Additional Information

#### Product Drawings:

- [Customer Drawing](#) (PDF, English)

#### Catalog Pages/Data Sheets:

- None Available

#### Product Specifications:

- None Available

#### Application Specifications:

- None Available

#### Instruction Sheets:

- None Available

#### CAD Files:

- None Available

#### Additional Information:

- [Product Line Information](#)

#### Related Products:

- [Tooling](#)

[List all Documents](#)

### Product Features (Please use the Product Drawing for all design activity)

#### Product Type Features:

- [Product Type](#) = Heat Shrinkable Cable Feedthrough
- [Thread Size](#) = M24 x 1.5
- [Material](#) = Low Fire Hazard Material
- [Angle](#) = Straight

#### Electrical Characteristics:

- Modification = None
- [Shielded](#) = Yes
- [Expanded ID, Min. \(mm \[in\]\)](#) = 16.50 [0.650]
- [Recovered ID, Max. \(mm \[in\]\)](#) = 8.50 [0.334]

#### Termination Features:

- [Adhesive](#) = S-1030 Holt Melt

#### Body Features:

- Mount Type = Bulkhead Feedthrough
- Feedthrough Material = Stainless Steel
- Feedthrough Finish = Electroless Nickel
- [Feedthrough Type](#) = Single-sided
- Thread Length (mm [in]) = 20.00 [0.787]
- [Feedthrough Inner Diameter, Max. \(mm \[in\]\)](#) = 19.2 [0.76]
- A/F Body Diameter (mm [in]) = 38 [1.5]
- A/F Nut (mm [in]) = 30 [1.18]
- Length of Molded Part/Flange (mm [in]) = 90 [3.543]
- Hole Diameter (mm [in]) = 25.00 [0.985]

#### Configuration Features:

- [Material Code](#) = 100

#### Industry Standards:

- [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- [Lead Free Solder Processes](#) = Not relevant for lead free process
- RoHS/ELV Compliance History = Always was RoHS compliant

#### Other:

- Brand = Raychem

#### Corporate Information

[Who We Are](#)  
[Investors](#)  
[News Room](#)  
[Supplier Portal](#)  
[Careers](#)

#### Quick Links

[Check Distributor Inventory](#)  
[Cross Reference](#)  
[Find Documents & Drawings](#)  
[Product Compliance Support Center](#)  
[Site Map](#)

#### Customer Support

[Email or Chat With Us](#)  
[Find a Phone Number](#)  
[Search Knowledge Base](#)  
[Manage your Account](#)

#### Keep Me Informed

Receive TE News, Events & Technology Updates

[▶](#)

