




HEAT SHRINK TUBING

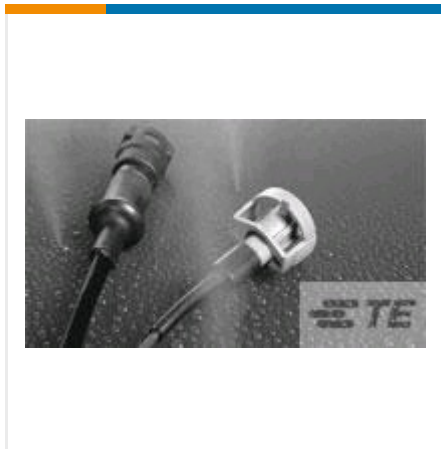

✓ Active

TE CONNECTIVITY (TE)

HTAT-12/3-0-STK

Raychem | HTAT

HTAT-12/3-0-STK

TE Internal Number: 7465232006

Alias ID: 7-1195823-7

EU RoHS Compliant

EU ELV Compliant

Wall Type Dual

Resistant To Fluids, Mechanical Damage, Strain

Low Outgassing No

Product Source Czech Republic

Packaging Method Stick

DOCUMENTATION

Catalog Pages/Data Sheets

HTAT Pages From 9-1773447-9

PDF

English

At-Application-Tooling-For-Raychem-Heat-Shrink-Product-2-1773452-8

PDF

English

Product Specifications

Product Specification

HTAT Sleeving

PDF

English

Product Environmental Compliance

Safety Data Sheet

Aliphatic Polyamide Based Adhesives.

PDF

English

Aliphatic Polyamide Based Adhesives.

PDF

Dutch

Aliphatic Polyamide Based Adhesives.

PDF

English

Aliphatic Polyamide Based Adhesives.

PDF

French

Aliphatic Polyamide Based Adhesives.

PDF

German

Aliphatic Polyamide Based Adhesives.

PDF

Italian

Aliphatic Polyamide Based Adhesives.

PDF

Spanish

Aliphatic Polyamide Based Adhesives.

PDF

Swedish

Instruction Sheets

Instruction Sheet (U.S.)

Global Dimensional Life For RAYCHEM Heat Shrink Tubing Standard Size Products (Customer Distribution)

PDF

English

FEATURES



Please review product documents or [contact us](#) for the latest agency approval information.

Product Type Features

Wall Type Dual

Product Family HTAT

Electrical Characteristics

Voltage (Max) (kV) .6

Body Features

Shrink Ratio 4:1

Color Black

Flexibility Semi-Flexible

Material Irradiated Modified Polyolefin

Fluid Type Diesel Fuel, Hydraulic Fluid, Lubricating Oil, Motor Oil, Water

Dimensions

Expanded Inside Diameter (Min) 12 mm [.472 in]

Recovered Wall Thickness (Nominal) 1.4 mm [.055 in]

Recovered Inside Diameter (Max) 3 mm [.118 in]

Recovered Wall Thickness (Tolerance) .3 mm [.012 in]

Cut Length 1220 mm [48.031 in]

Usage Conditions

Shrink Temperature (Min) (°C) 80

Resistant To Fluids, Mechanical Damage, Strain

Recovery Temperature (°C) 110

Operating Temperature Range (°C) -55 – 125

Flammability Flame-Retardant

Fluid Resistance Moisture/Spray Protection, Splash Protection

Product Availability

Applicable Region Global

Packaging Features

Packaging Method Stick

Other

Low Outgassing No

Product Source Czech Republic

PRODUCT COMPLIANCE



Statement of Compliance

Statement of Compliance

PDF
