


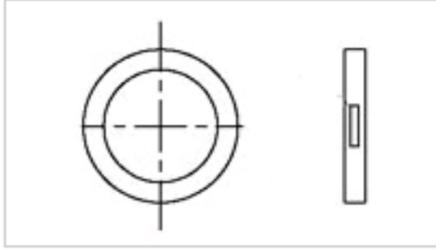

# TR10CI-TINEL-LOCK-RING Product Details

[Share](#) [Print](#) [Email](#)


Active

## Braid, Fixed, Spin and Tinel Lock Adapters

TR10CI-TINEL-LOCK-RING

**TR10CI-TINEL-LOCK-RING (7-1197921-6)**

TE Internal Number: 035342-000

### Product Highlights [View All](#)

- Applies To Cable
- Style = Tinel Ring
- All
- Entry Size = 10
- Boot Diameter = 23.49 mm

[Pricing & Availability](#)
[Request Sample](#)
[Add to My Part List](#)
[Buy Product through Distributor](#)
[Feedback](#)
[Documents](#)
[Features](#)
[Compliance](#)

### Please Note:

Use the Product Drawing for all design activity

#### Product Type Features

Style	Tinel Ring
Angle	All
Color	Gray

#### Dimensions

Boot Diameter (mm [in])	23.49 [0.925]
Cable Diameter Range (mm [in])	8.00 - 15.00 [0.320 - 0.590]

#### Body Features

Entry Size	10
------------	----

#### Industry Standards

Government/Industry Qualification	No
RoHS/ELV Compliance	RoHS compliant, ELV compliant
Lead Free Solder Processes	Not relevant for lead free process
RoHS/ELV Compliance History	Always was RoHS compliant

#### Conditions for Usage

Applies To	Cable
------------	-------

#### Other

Brand	Raychem
Comment	For specific shell size information, refer to "Hardware" or Catalog.

### Related Products

Not quite the product you're looking for?

[Find Similar Products](#)

[View Part in Product Feature Selector](#)

[Check for Tooling](#)

### Corporate Information

- [About TE](#)
- [Investors](#)
- [News Room](#)
- [Supplier Portal](#)
- [Careers](#)
- [Terms & Conditions](#)
- [Privacy Policy](#)
- [Global Accessibility Statement](#)

### Quick Links

- [Distributor Inventory](#)
- [Product Cross Reference](#)
- [Documents & Drawings](#)
- [Product Compliance Support Center](#)
- [Site Map](#)

### Customer Support

- [Email or Chat With Us](#)
- [Find a Phone Number](#)
- [Knowledge Base](#)
- [Manage Your Account](#)

### Keep Me Informed

