


[+ HARNESSING](#)

HEAT-SHRINK BOOTS

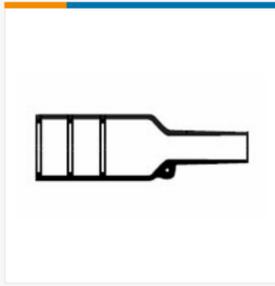

✓ Active

↓ **PRODUCT DRAWING**
English

> [See All Documentation](#)

TE CONNECTIVITY
202K232-25-01/225-0

202K232-25-01/225-0
 TE Internal Number: 975754-000
 Alias ID: 2-1197540-1

Always EU RoHS/ELV Compliant

Lipped **Yes**

Operating Temperature Range(°C) **-75 – 175**

Material Systems Code **25**

Adhesive Pre-Coat **Yes**

> [See All Features](#)

North America ▼

Inventory does exist through Waldom (TE's master distributor) but is only available for purchase through a TE authorized distributor. Please contact your preferred authorized distributor for purchasing options.

FIND AUTHORIZED DISTRIBUTORS >

SAVE TO LIST	
CHECK FOR TOOLING	
FIND SIMILAR PRODUCTS	

DOCUMENTATION FEATURES

Please review product documents or [contact us](#) for the latest agency approval information. Please Note: Use the Product Drawing for all design activity.

Product Type Features	Molded Part Type	Molded Boot
Configuration Features	Lipped	Yes
Body Features	Material Systems Code	25
	Adhesive Pre-Coat	Yes
	Material	Modified Elastomer
Dimensions	Inside Diameter as Supplied	25mm[.98in]
Usage Conditions	Operating Temperature Range(°C)	-75 – 175
Operation/Application	Power Cable Accessory	No
Industry Standards	Approved Standards	VG95343 Parts 6,7,8 and 9
	Government Qualified	No
Other	Adhesive Type	Unicure Pre-Coated Epoxy Adhesive
Product Compliance	Statement of Compliance PDF VIEW ALL PRODUCT COMPLIANCE	

COMPATIBLE

No compatible products found for 202K232-25-01/225-0

Feedback