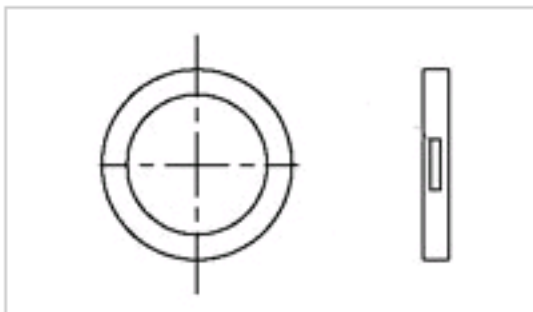


TR14BI-TINEL-LOCK-RING Product Details

[Share](#) [Print](#) [Email](#)


✓ Active

Braid, Fixed, Spin and Tinel Lock Adapters

TR14BI-TINEL-LOCK-RING

TR14BI-TINEL-LOCK-RING 

TE Internal Number: 234245-000

Product Highlights [View All](#)

- Applies To Cable
- Style = Tinel Ring
- All
- Entry Size = 14
- Boot Diameter = 29.84 mm

[Pricing & Availability](#)
[Request Sample](#)
[Add to My Part List](#)
[Buy Product through Distributor](#)
[Feedback](#)
[Documents](#)
[Features](#)
[Compliance](#)

Please Note:

Use the Product Drawing for all design activity

Product Type Features

Style 	Tinel Ring
Angle 	All
Color	Gray

Dimensions

Boot Diameter (mm [in]) 	29.84 [1.175]
Cable Diameter Range (mm [in])	11.00 - 21.40 [0.430 - 0.840]

Body Features

Entry Size	14
------------	----

Configuration Features

Braid 	Double 36 AWG Braid
---	---------------------

Industry Standards

RoHS/ELV Compliance 	RoHS compliant, ELV compliant
Lead Free Solder Processes 	Not relevant for lead free process
RoHS/ELV Compliance History	Always was RoHS compliant

Conditions for Usage

Applies To	Cable
------------	-------

Other

Brand	Raychem
Comment	For specific shell size information, refer to "Hardware" or Catalog.

Related Products

Not quite the product you're looking for?

[Find Similar Products](#)

[View Part in Product Feature Selector](#)

[Check for Tooling](#)

Corporate Information

[About TE](#)
[Investors](#)
[News Room](#)
[Supplier Portal](#)
[Careers](#)
[Terms & Conditions](#)
[Privacy Policy](#)
[Global Accessibility Statement](#)

Quick Links

[Distributor Inventory](#)
[Product Cross Reference](#)
[Documents & Drawings](#)
[Product Compliance Support Center](#)
[Site Map](#)

Customer Support

[Email or Chat With Us](#)
[Find a Phone Number](#)
[Knowledge Base](#)
[Manage Your Account](#)

Keep Me Informed

