




Terminals & Splices > Automotive Terminals > ROUND CONNECTOR SYSTEM, PIN AND SOCKET

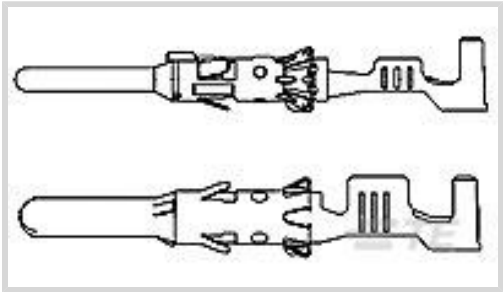

Terminal Type: Pin
Mating Pin Diameter: 1.5 mm [.059 in]
Terminal Transmits: 25 – 40 A (Power)
Wire Size: 1 – 2.5 mm²

[All Round Connector System, Pin and Socket \(74\)](#)

Features

Product Type Features

Receptacle Style	180°
Sealable	Yes
Primary Locking Feature	Locking Lance

Body Features

Terminal Seal Type	Single Wire Seal (SWS)
--------------------	------------------------

Contact Features

Contact Size	1.5mm
Contact Fabrication	Stamped & Formed
Typical Current Rating	34 A
Crimp Type	F-Crimp
Terminal Type	Pin
Mating Pin Diameter	1.5 mm[.059 in]
Interface Plating	Tin (Sn)

Termination Features

Termination Method to Wire & Cable	Crimp
Product Terminates To	Wire

Dimensions

--



Wire Size	1 – 2.5 mm²
Wire Size Search	13 AWG, 14 AWG, 15 AWG, 16 AWG, 17 AWG
Wire Insulation Diameter	2.2 – 3 mm[.087 – .118 in]

Usage Conditions

Insulation Option	Uninsulated
Operating Temperature (Max)	80 °C, 85 °C, 90 °C, 100 °C, 105 °C, 110 °C, 120 °C, 125 °C, 130 °C[176 °F][185 °F][194 °F][212 °F][221 °F][230 °F][248 °F][257 °F][266 °F]
Operating Temperature Range	-40 – 130 °C[-40 – 266 °F]

Operation/Application

Compatible With Wire Base Material	Copper
------------------------------------	--------

Packaging Features

Packaging Method	Reel
Packaging Quantity	3500

Other

Terminal Transmits	25 – 40 A (Power)
--------------------	-------------------

Product Compliance

For compliance documentation, visit the product page on TE.com>

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JUNE 2022 (224) Candidate List Declared Against: JUNE 2022 (224) Does not contain REACH SVHC
Halogen Content	Low Halogen - Br, Cl, F, I < 900 ppm per homogenous material. Also BFR/CFR/PVC Free
Solder Process Capability	Not applicable for solder process capability


Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent



chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts

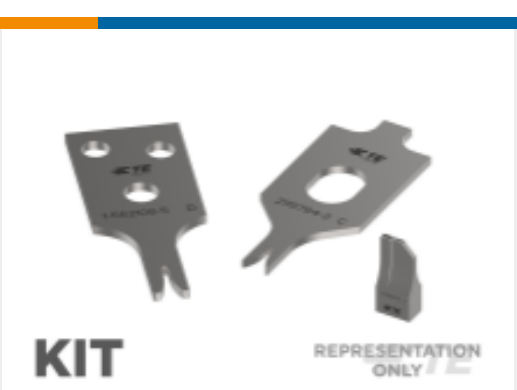 TE Part # CAT-C4962-CH8172 CIRCULAR DIN HOUSINGS	 TE Part # 3-1579007-7 EXTRACTION TOOL	 TE Part # 58606-1 PROCIMP 1.5 & 2.5MM PIN/SEAL	 TE Part # 1718230-1 1,5MM PIN HSG 5-7 POS ASSY
 TE Part # 2305570-1 Strip Terminal Cutter-Side Feed-No Crimp	 TE Part # 1544676-1 1.5 MM PIN HSG 7W SEALED	 TE Part # 2-2151345-1 OCEAN_2.0_APPLICATOR-S-100F1700	 TE Part # 2-2151345-2 OCEAN_2.0_APPLICATOR-S-100F1700
 TE Part # 2151345-1 OCEAN_2.0_APPLICATOR-S-100F1700	 TE Part # 2151345-2 OCEAN_2.0_APPLICATOR-S-100F1700	 TE Part # 5-2151345-1 OCEAN_2.0_APPLICATOR-S-100F1700	 TE Part # 5-2151345-2 OCEAN_2.0_APPLICATOR-S-100F1700
 TE Part # 58606-2 PC DIE 1.5 & 2.5 PIN W/S	 TE Part # 7-2151345-1 OCEAN_2.0_APPLICATOR-S-100F1700	 TE Part # 7-2151345-2 OCEAN_2.0_APPLICATOR-S-100F1700	 TE Part # 7-2151345-7 OCEAN_2.0_SPARE_PART_KIT-100F1700





KIT

REPRESENTATION ONLY

TE Part # 7-2266057-7
OC-100F1700-752-
CRIMPTOOLINGKIT



TE Part # 1544677-1
1.5 MM PIN HSG 7P SEALED

Also in the Series | Round Connector System



Automotive Connector Caps & Covers
(5)



Automotive Housings(16)



Automotive Seals & Cavity Plugs(3)



Automotive Terminals(74)



Insertion & Extraction Tools(8)

Documents

Product Drawings

DIA 1.5MM CONTACT PIN,ASSY

German

CAD Files

Customer View Model

ENG_CVM_1703014-1_A3.3d_stp.zip

English

Customer View Model

ENG_CVM_1703014-1_A3.2d_dxf.zip

English

Customer View Model

ENG_CVM_1703014-1_A3.3d_igs.zip

English

3D PDF

English



By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Product Specifications

Application Specification

English

Application Specification

English