

1-1579007-1 ✓ ACTIVE

AMP | AMP MCP Connector System, Timer Connector System

TE Internal #: 1-1579007-1

Insertion & Extraction Tools, Contact Extraction, Contact-to-Wire,  
AMP MCP Connector System

[View on TE.com >](#)



Application Tooling > Insertion & Extraction Tools



Insertion & Extraction Tool Type: **Contact Extraction**

Insertion & Extraction Tool Application: **Contact-to-Wire**

## Features

### Product Type Features

|   |                    |
|---|--------------------|
| Insertion & Extraction Tool Type        | Contact Extraction |
| Insertion & Extraction Tool Application | Contact-to-Wire    |

## Product Compliance

[For compliance documentation, visit the product page on TE.com>](#)

|   |   |
|---|---|
| EU RoHS Directive 2011/65/EU                  | Not Compliant   |
| EU ELV Directive 2000/53/EC                   | Out of Scope  |
| China RoHS 2 Directive MIIT Order No 32, 2016 | Restricted Materials Above Threshold  |
| EU REACH Regulation (EC) No. 1907/2006        | Current ECHA Candidate List: JUNE 2022 (224)<br>Candidate List Declared Against: JUNE 2022 (224)<br>SVHC > Threshold:<br>Pb (1.84% in Component Part)<br><b>Article Safe Usage Statements:</b><br>Do not eat, drink or smoke when using this product. Wash thoroughly after handling. Recycle if possible and dispose of the article by following all applicable governmental regulations relevant to your geographic location. |
| Halogen Content                               | Low Halogen - Br, Cl, F, I < 900 ppm per homogenous material. Also BFR/CFR/PVC Free   |
| Solder Process Capability                     | Not applicable for solder process capability  |

### Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products

will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

## Compatible Parts




TE Part # 1-1703543-0  
2POS, TAB 2.8X0.8, TAB HSG, ASSY



TE Part # CAT-AM705-T273  
AMP MCP, RECEPTACLE AND TAB



TE Part # 1-1718484-4  
CARRIER FOR RECEPTACLE INSERTS

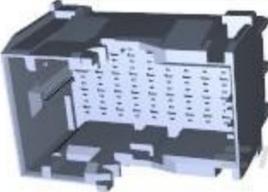


TE Part # 1-1718492-4  
1.5MM TAB HSG 36 POS ASSY




TE Part # CAT-H3399-CH8172  
Heavy Duty Sealed Connector Series Housings




TE Part # 1-1718492-3  
1.5MM TAB HSG 36 POS ASSY

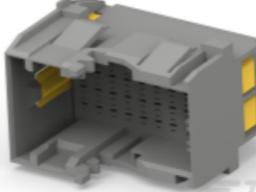

TE Part # 1-1718492-5  
1.5MM TAB HSG 36 POS ASSY

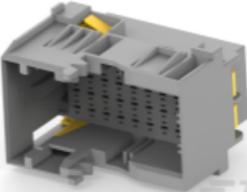

TE Part # 1-2112891-5  
36POS, TAB 1.5X0.6, TAB HSG, ASSY

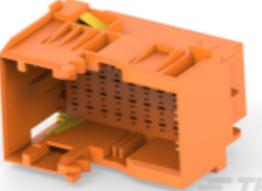

TE Part # 1-2112891-6  
36POS, TAB 1.5X0.6, TAB HSG, ASSY



TE Part # 1-2141847-4  
CARRIER, RECEPTACLE HSG, 36POS, ASSY



TE Part # 9-2348786-1  
HD MATEnet 2+6 REC HSG ASSY, GRP E



TE Part # 9-2348786-2  
HD MATEnet 2+6 REC HSG ASSY, GRP E



TE Part # 2350440-1  
AMP MCP 1.5K, CONTACT, SWS



TE Part # 1241375-1  
AMP MCP 1.5K, CONTACT, (LP)









TE Part # 1241381-1  
AMP MCP 1.5K, CONTACT, SWS, (LP)






TE Part # 1418885-1  
AMP MCP 1.5K, CONTACT, SWS, (LP)



### Also in the Series | AMP MCP Connector System

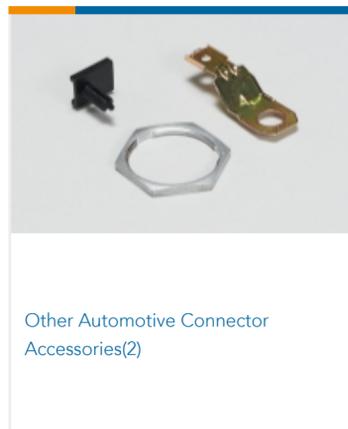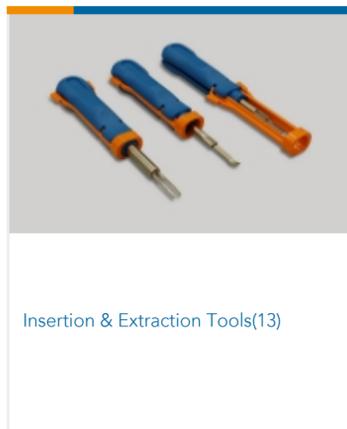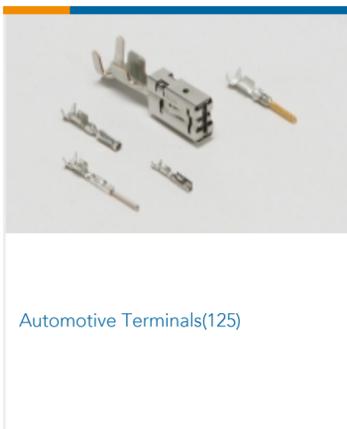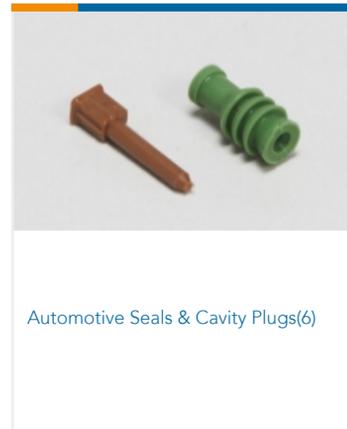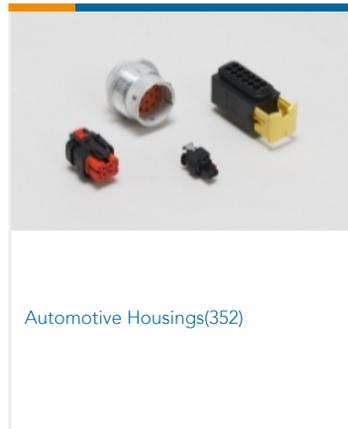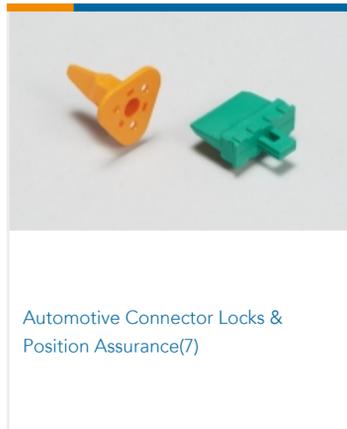

### Also in the Series | Timer Connector System

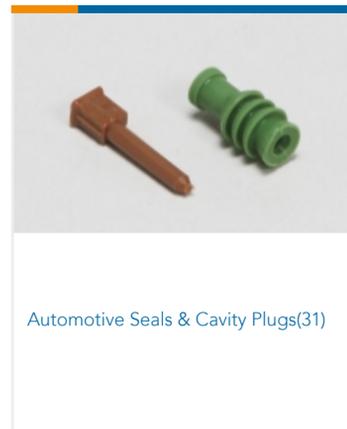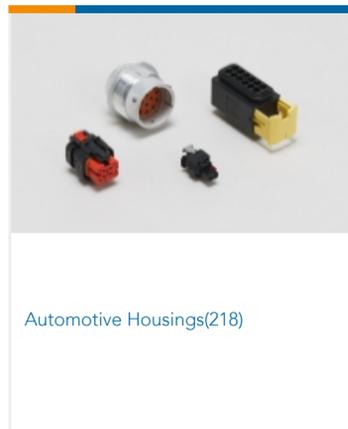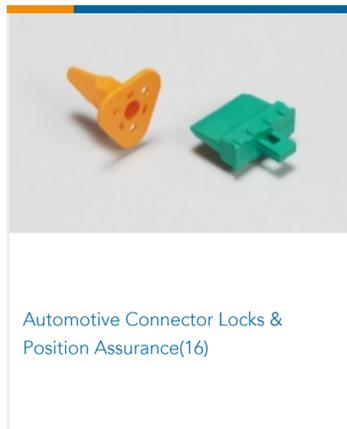




Automotive Terminals(130)



Crimp Terminal Housings(13)



Insertion & Extraction Tools(20)

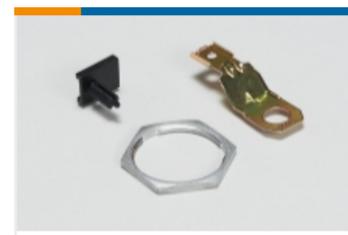

Other Automotive Connector Accessories(1)



PCB Headers & Receptacles(78)



Quick Disconnects(4)

## Documents

### Product Drawings

[EXTRACTION TOOL](#)

English

### Datasheets & Catalog Pages

[HDSCS Catalog](#)

English

[CONNECTOR SELECTOR](#)

English