

2-180930-0 ✓ ACTIVE

FASTON | FASTON 250


TE Internal #: 2-180930-0

Crimp Terminal Housings, Receptacle, Receptacle, 1 Position,  
Straight, Natural, Polyethylene, Carton, -40 – 105 °C [-40 – 221 °F],  
FASTON 250

[View on TE.com >](#)



Terminals & Splices > Terminal Housings, Insulation Sleeves & Blocks > Crimp Terminal Housings

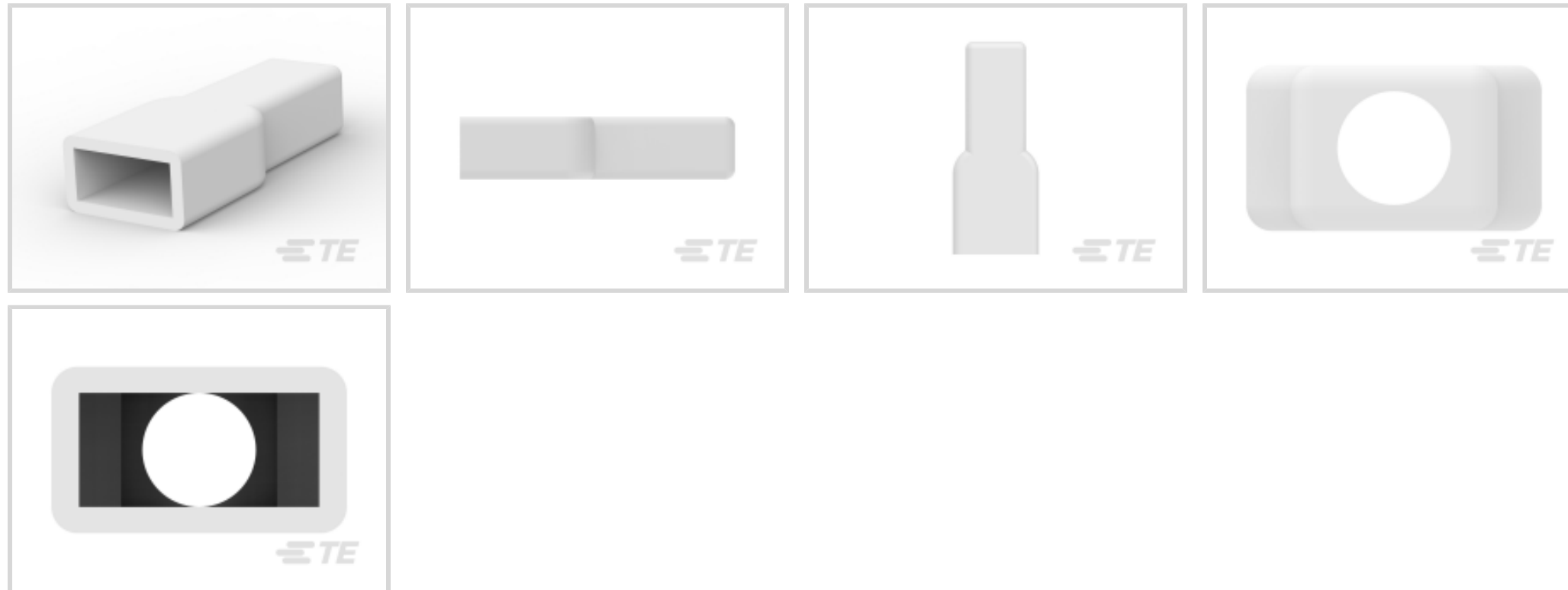

Terminal Type: **Receptacle**

Housing Type: **Receptacle**

Number of Positions: **1**

Terminal Orientation: **Straight**

Primary Product Color: **Natural**

## Features

### Product Type Features

Terminates To	Wire & Cable
Product Type	Insulation Boot
Sealable	No
Housing Type	Receptacle
Insulated	No

### Configuration Features

Number of Positions	1
---------------------	---

### Body Features

Primary Product Color	Natural
-----------------------	---------

### Contact Features

Terminal Type	Receptacle
Terminal Orientation	Straight
Contact Mating Retention	Without

### Mechanical Attachment

Mating Alignment Type	None
Mating Alignment	Without

### Housing Features

Housing Material	Polyethylene
------------------	--------------

### Dimensions

Length	22.5 mm [.885 in]
--------	-------------------

### Usage Conditions

Operating Temperature Range	-40 – 105 °C [-40 – 221 °F]
-----------------------------	-----------------------------

### Operation/Application

For Use With	FASTON Terminals
--------------	------------------

### Packaging Features

Packaging Method	Carton
------------------	--------

## Product Compliance

[For compliance documentation, visit the product page on TE.com>](#)

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JUNE 2022 (224) Candidate List Declared Against: JUNE 2022 (224) Does not contain REACH SVHC
Halogen Content	Not Low Halogen - contains Br or Cl > 900 ppm.
Solder Process Capability	Not applicable for solder process capability

#### Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides

on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

## Compatible Parts



TE Part # 1-925017-0  
250 FASTON HSG.,REC.,1 POS,  
NATURAL



TE Part # 280232-8  
250 FASTON POST INS.,REC.,1 POS,  
NATURAL



TE Part # 2-180930-1  
250 FASTON HSG.,REC.,1 POS,RED



TE Part # 2-180984-0  
FASTON BOOT 250 FLAG NYLON  
NAT



TE Part # 1-180984-2  
FASTON 250 BOOT NYLON BLK



TE Part # 8-180984-1  
250 FASTON BOOT FLAG REC. 1P  
BLACK



TE Part # 2-180930-5  
250 FASTON HSG.,REC.,1 POS,BLACK



TE Part # 180984  
FASTON 250 BOOT FLAG NYLON  
NAT




TE Part # 180460  
INSULATING BOOT POLYAMIDE  
NATURAL




TE Part # 7-180984-0  
250 FASTON BOOT FLAG REC. 1P  
NATURAL


## Also in the Series | FASTON 250



Compression Connectors(4)

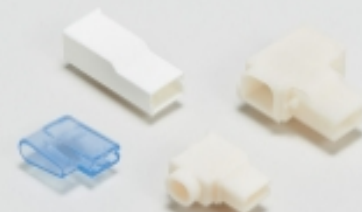

Crimp Terminal Housings(143)




Insertion & Extraction Tools(6)



Magnet Wire Terminals(1)



PCB Terminals(144)

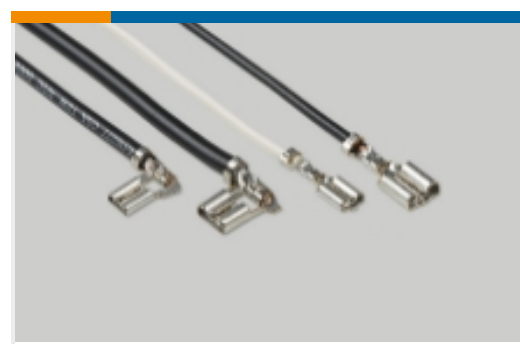

Quick Disconnects(455)



Splices(4)

## Documents

### Product Drawings

250 FASTON HSG.,REC.,1 POS,NATRUAL

English

### CAD Files

3D PDF

English

Customer View Model

[ENG\\_CVM\\_2-180930-0\\_G1.3d\\_igs.zip](#)

English

Customer View Model

[ENG\\_CVM\\_2-180930-0\\_G1.3d\\_stp.zip](#)

English

Customer View Model

[ENG\\_CVM\\_2-180930-0\\_G1.2d\\_dxf.zip](#)

English

3D PDF

3D

Customer View Model

[ENG\\_CVM\\_CVM\\_2-180930-0\\_G.2d\\_dxf.zip](#)

English

Customer View Model

[ENG\\_CVM\\_CVM\\_2-180930-0\\_G.3d\\_igs.zip](#)

English

Customer View Model

[ENG\\_CVM\\_CVM\\_2-180930-0\\_G.3d\\_stp.zip](#)

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

### Datasheets & Catalog Pages

1654742\_HOUSEHOLD\_APPLIANCES\_RAST5

English

### Product Specifications

Product Specification



English

---

**Product Environmental Compliance**

**Product Compliance**

English

**Product Compliance**

English