

61668-2 ✓ ACTIVE

AMPMODU | UTILUX CR


TE Internal #: 61668-2

Connector Contact, Hermaphroditic, Wire-to-Board, Tin, 24 – 18 AWG Wire Size, .2 – .8 mm² Wire Size, Straight, Wire & Cable, 6 A, Signal, UTILUX CR

[View on TE.com >](#)



Connectors > PCB Connectors > Board-to-Board Connectors > Board-to-Board Connector Contacts

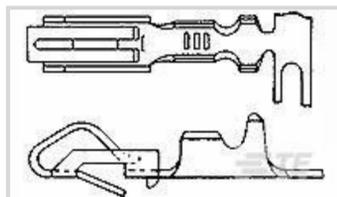

Contact Type: **Hermaphroditic**

Connector System: **Wire-to-Board**

Contact Mating Area Plating Material: **Tin**

Wire Size: **.2 – .8 mm²**

Features

Product Type Features

Connector System	Wire-to-Board
Connector & Contact Terminates To	Wire & Cable

Contact Features

PCB Contact Termination Area Plating Material	Pre-Tin
Contact Base Material	Phosphor Bronze
Contact Type	Hermaphroditic
Contact Mating Area Plating Material	Tin
Contact Orientation	Straight
Contact Current Rating (Max)	6 A

Termination Features

Termination Method to Wire & Cable	Crimp
------------------------------------	-------

Mechanical Attachment

Contact Retention Type Within Housing	Snap-In
Wire Insulation Support	With
PCB Mount Retention	Without
Connector Mounting Type	Board Mount

Dimensions

Accepts Wire Insulation Diameter Range	2.79 mm[.11 in]
Wire Size	.2 – .8 mm ²

Usage Conditions

Operating Temperature Range	-55 – 105 °C[-55 – 105 °F]
-----------------------------	----------------------------

Operation/Application

Circuit Application	Signal
---------------------	--------

Packaging Features

Packaging Quantity	6000
Packaging Method	Box

Product Compliance

[For compliance documentation, visit the product page on TE.com>](#)

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JUNE 2022 (224) Candidate List Declared Against: JUNE 2022 (224) Does not contain REACH SVHC
Halogen Content	Low Halogen - Br, Cl, F, I < 900 ppm per homogenous material. Also BFR/CFR/PVC Free
Solder Process Capability	Not applicable for solder process capability

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts

TE Part # 640136-2
02P EDGE CONN HSG, BIF-LEAF

TE Part # 58614-1
PROCrimp, HT&D SL156

TE Part # 2305570-1
Strip Terminal Cutter-Side Feed-No Crimp

KIT
REPRESENTATION ONLY

TE Part # 7-2151033-7
OCEAN_2.0_SPARE_PART_KIT-070F100F

TE Part # 2151033-1
OCEAN-2.0-APPLICATOR-S-070F100F

TE Part # 58614-2
PROCrimp, DIE, SL156

TE Part # 91597-1
CCII SL-156 REC 24-18 ASSY

TE Part # 2-2151033-1
OCEAN-2.0-APPLICATOR-S-070F100F

TE Part # 2-2151033-2
OCEAN-2.0-APPLICATOR-S-070F100FA

TE Part # 2151033-2
OCEAN-2.0-APPLICATOR-S-070F100FA

TE Part # 5-2151033-1
OCEAN-2.0-APPLICATOR-S-070F100F

TE Part # 5-2151033-2
OCEAN-2.0-APPLICATOR-S-070F100FA

TE Part # 693597-2
EXTRACTION TOOL

TE Part # 7-2151033-1
OCEAN-2.0-APPLICATOR-S-070F100F

TE Part # 7-2151033-2
OCEAN-2.0-APPLICATOR-S-070F100FA

KIT
REPRESENTATION ONLY

TE Part # 7-2266602-7
OCEAN_2.0_SPARE_PART_KIT-070F100F


Also in the Series | UTILUX CR

Board-to-Board Connector Contacts(4)

Card Edge Connector Housings(1)

Compression Connectors(7)

Insertion & Extraction Tools(1)

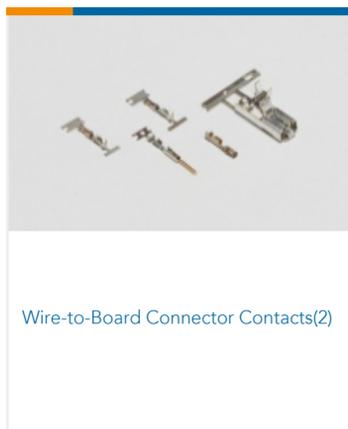

Documents

Product Drawings

[BIF-LEAF CONT CR/SNAP PTPPHBZ](#)

English

CAD Files

Customer View Model

[ENG_CVM_61668-2_AS.3d_igs.zip](#)

English

Customer View Model

[ENG_CVM_61668-2_AS.3d_stp.zip](#)

English

Customer View Model

[ENG_CVM_61668-2_AS.2d_dxf.zip](#)

English

[3D PDF](#)

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Product Specifications

[Bifurcated Leaf Contact](#)

English

[Application Specification](#)

English