

786585-2 ✓ ACTIVE

AMPLIMITE | AMPLIMITE 0.50 Series

TE Internal #: 786585-2

D-Sub Locking & Mounting, Female Screwlocks, Screw Length 9.02 mm [.355 in], AMPLIMITE 0.50 Series

[View on TE.com >](#)



Connectors > D-Shaped Connectors > D-Sub Accessories > Locking & Mounting



D-Shaped Connector Accessories: **Female Screwlocks**

Screw Length: **9.02 mm [.355 in]**

Features

Product Type Features

Product Type	Accessory
D-Shaped Connector Accessories	Female Screwlocks

Mechanical Attachment

Screwlock Style	Screwlock Only
Screw & Hole Thread Size	2-56 UNC
Screw Length	9.02 mm [.355 in]

Dimensions

Thread Length	5.21 mm [.205 in]
---------------	-------------------

Packaging Features

Packaging Quantity	2
Packaging Method	Individual

Product Compliance

[For compliance documentation, visit the product page on TE.com>](#)

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant



China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JUNE 2022 (224) Candidate List Declared Against: JUNE 2022 (224) Does not contain REACH SVHC
Halogen Content	Low Halogen - Br, Cl, F, I < 900 ppm per homogenous material. Also BFR/CFR/PVC Free
Solder Process Capability	Not applicable for solder process capability


Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts

 <p>TE Part # CAT-020-ADRV127 AMPLIMITE D-Sub Receptacle Assembly: Vertical, 1.27mm</p>	 <p>TE Part # CAT-020-DRAVAP127 D-Sub Receptacle Assembly: Vertical, Action Pin, 1.27mm</p>	 <p>TE Part # CAT-018-DRARA127 D-Sub Receptacle Assembly: Right Angle, 1.27mm</p>	 <p>TE Part # CAT-AM7-436507 IDC D-Sub: Receptacle Assembly, Panel Mount, Signal, 1.27 mm</p>
 <p>TE Part # 750831-1 .050SR FEM SCRLCK KIT,SLIM LN</p>	 <p>TE Part # 5-749878-7 68 50SR PNL MNT PLUG ASSY, ROHS</p>	 <p>TE Part # CAT-AM7-4365072 IDC D-Sub: Receptacle Kit, Panel Mount, Signal, 1.27 mm</p>	

Also in the Series | **AMPLIMITE 0.50 Series**

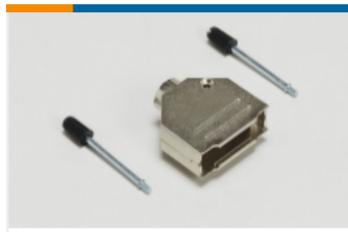

D-Sub Backshells & Clamps(31)



D-Sub Covers(20)



D-Sub Locking & Mounting(8)



IDC D-Sub Connectors(76)



Insertion & Extraction Tools(1)



PCB D-Sub Connectors(191)

Documents

Product Drawings

50SR SCREWLOCK KIT,FEMALE

English

CAD Files

Customer View Model

[ENG_CVM_CVM_786585-2_B.2d_dxf.zip](#)

English

3D PDF

3D

Customer View Model

[ENG_CVM_CVM_786585-2_B.3d_igs.zip](#)

English

Customer View Model

[ENG_CVM_CVM_786585-2_B.3d_stp.zip](#)

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Datasheets & Catalog Pages

AMPLIMITE Subminiature D Connectors - .050 Series Connector

English

AMPLIMITE .050 Series D-sub Connectors QRG

English

Product Specifications

Application Specification

English



Product Environmental Compliance

[MD_786585-2_04222014213_dmtec](#)

English

[MD_786585-2_04222014213_dmtec](#)

English

Instruction Sheets

[Instruction Sheet \(U.S.\)](#)

English

[Instruction Sheet \(U.S.\)](#)

English

[Instruction Sheet \(U.S.\)](#)

English

[Instruction Sheet \(U.S.\)](#)

English