

Fixture Type: \_\_\_\_\_

Catalog Number: \_\_\_\_\_

Project: \_\_\_\_\_

Location: \_\_\_\_\_

## Rondelle Bathroom Sconce 3000K

Model & Size	Color Temp & CRI	Watt	LED Lumens	Delivered Lumens	Finish
WS-42505 5"	3000K 90	8.5W	230	220	AB Aged Brass PN Polished Nickel

Example: **WS-42505-AB**

- For 277V special order, add an "F" before the finish: WS-42524F-PN

### DESCRIPTION

Inspired by collectible antique pole-top insulators, now illuminated as nostalgic lighting fixtures.

### FEATURES


- Solid cast glass shades
- Driver located in standard 4" junction box
- 120-277V input for AB finish
- Driver installed within the Junction Box, driver dimension: 2.76" x 1.26" x 1.18"
- 5 Year warranty

### SPECIFICATIONS

<b>Color Temp:</b>	3000K
<b>Input:</b>	120 VAC, 50/60Hz
<b>CRI:</b>	90
<b>Dimming:</b>	ELV: 100-10%
<b>Rated Life:</b>	60000 Hours
<b>Standards:</b>	ETL, cETL Damp Location Listed
<b>Construction:</b>	Aluminum hardware with glass diffuser, Steel hardware with glass diffuser




### FINISHES

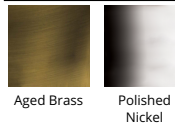

Aged Brass

Polished Nickel

### LINE DRAWING

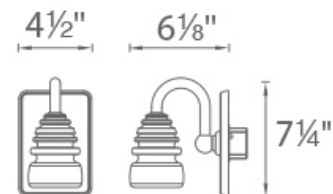

Fixture Type: \_\_\_\_\_

Catalog Number: \_\_\_\_\_

Project: \_\_\_\_\_

Location: \_\_\_\_\_

## Rondelle Bathroom Sconce 3000K

Model & Size	Color Temp & CRI	Watt	LED Lumens	Delivered Lumens	Finish
WS-42514 14"	3000K 90	16W	518	490	AB Aged Brass PN Polished Nickel

Example: **WS-42514-AB**

- For 277V special order, add an "F" before the finish: WS-42524F-PN

### DESCRIPTION

Inspired by collectible antique pole-top insulators, now illuminated as nostalgic lighting fixtures.

### FEATURES


- Solid cast glass shades
- Driver located in standard 4" junction box
- 120-277V input for AB finish
- Driver installed within the Junction Box, driver dimension: 2.76" x 1.26" x 1.18"
- 5 Year warranty

### SPECIFICATIONS


<b>Color Temp:</b>	3000K
<b>Input:</b>	120 VAC, 50/60Hz
<b>CRI:</b>	90
<b>Dimming:</b>	ELV: 100-10%
<b>Rated Life:</b>	60000 Hours
<b>Standards:</b>	ETL, cETL Damp Location Listed
<b>Construction:</b>	Aluminum hardware with glass diffuser, Steel hardware with glass diffuser



### FINISHES

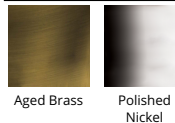

### LINE DRAWING

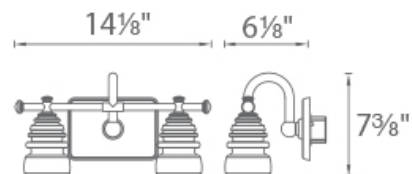

Fixture Type: \_\_\_\_\_

Catalog Number: \_\_\_\_\_

Project: \_\_\_\_\_

Location: \_\_\_\_\_

## Rondelle Bathroom Sconce 3000K

Model & Size	Color Temp & CRI	Watt	LED Lumens	Delivered Lumens	Finish
WS-42524 24"	3000K 90	24.5W	865	805	AB Aged Brass PN Polished Nickel

Example: **WS-42524-AB**

- For 277V special order, add an "F" before the finish: WS-42524F-PN

### DESCRIPTION

Inspired by collectible antique pole-top insulators, now illuminated as nostalgic lighting fixtures.

### FEATURES


- Solid cast glass shades
- Driver located in standard 4" junction box
- 120-277V input for AB finish
- Driver installed within the Junction Box, driver dimension: 2.76" x 1.26" x 1.18"
- 5 Year warranty

### SPECIFICATIONS

<b>Color Temp:</b>	3000K
<b>Input:</b>	120 VAC, 50/60Hz
<b>CRI:</b>	90
<b>Dimming:</b>	ELV: 100-10%
<b>Rated Life:</b>	60000 Hours
<b>Standards:</b>	ETL, cETL Damp Location Listed
<b>Construction:</b>	Aluminum hardware with glass diffuser, Steel hardware with glass diffuser



### FINISHES

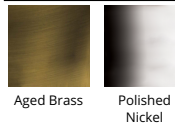

Aged Brass

Polished Nickel

### LINE DRAWING

