

Model: 6942XXXX



#### FEATURES

- Surface Mounting
- Energy Efficient and Long-Lasting LED Lighting
- Aluminum Frame
- Double-side Mirror Door with Built-in 6" Dia. LED Lit Cosmetic Mirror
- 170° Soft-closing Hinges
- Two Adjustable Tempered Glass Shelves
- Mirror Front Touch Switch Control
- 3-prong 120V Electrical Outlet (x2)
- USB Outlet (x2)
- Mirrored Interior
- Dimmable LED Lighting
- Copper-free Mirror

#### LIGHTING


- Lighting in Front and Back of Mirror Door
- Average Bulb Life of 50,000 hours
- CRI: 85+
- Dual-Color Temperatures: 3000K/6000K
- Brightness & Power Consumption: see page 2
- Power Requirements: 110-130V AC, 60Hz

#### SAFETY

- IP44 Rated
- UL Listed

#### OVERVIEW

**innoci-usa** does not cut corners and only uses the highest quality components and bulbs to make sure that the mirror will be maintenance free and function like the day you purchased for average 50,000 hours of use. **innoci-usa** prides itself on providing unmatched price vs quality for all of our products. All mirrors come with a 5-year limited warranty.

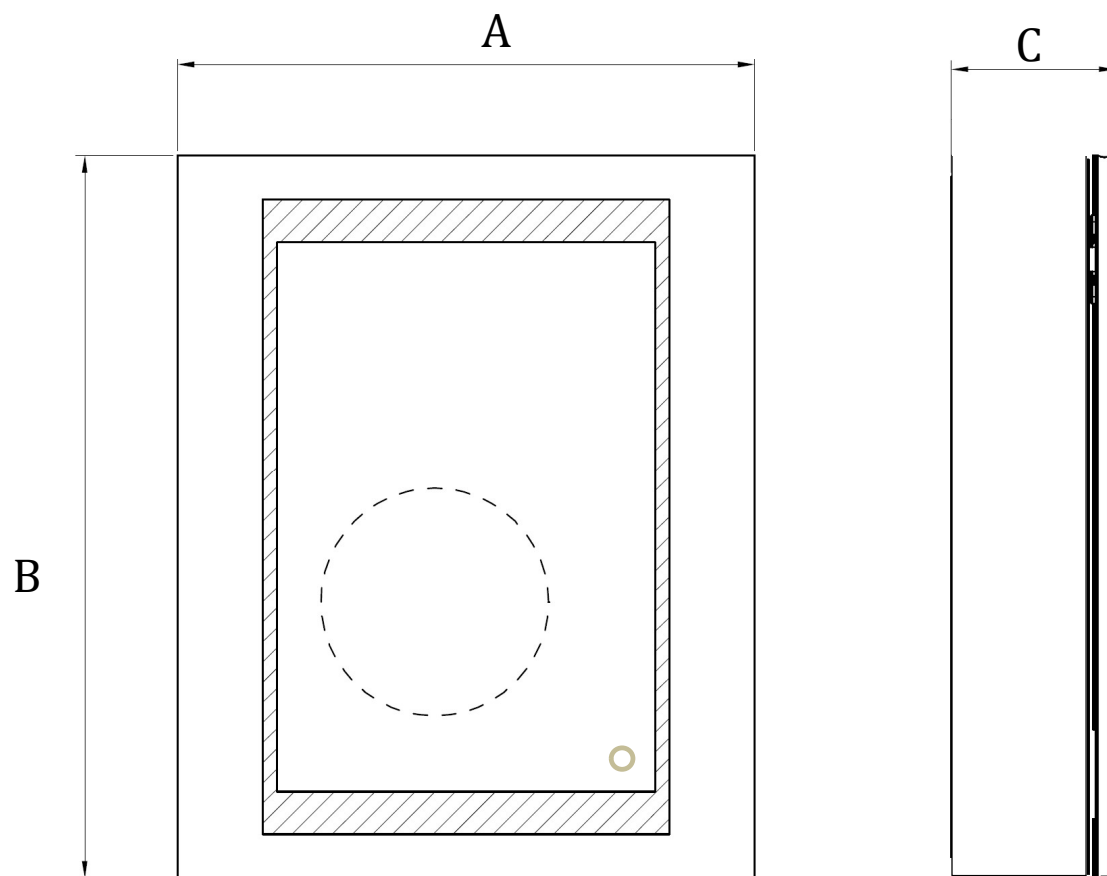

Model #	Overall Dimensions			Brightness (Lumen)	Power Consumption (Watt)
	A	B	C		
69422426	24	26	5-1/4	1365	22

innoci-usa Inc.  
Santa Fe Springs, CA 90670

[www.innoci-usa.com](http://www.innoci-usa.com)  
(866) 479-8076

[customerservice@innoci-usa.com](mailto:customerservice@innoci-usa.com)

**innociusa**  
L I F E S T Y L E

Rev6.5