

Low Profile Louvered Floor Rack

Innovative solution for limited spaces!

- Convenience and strength of a louvered panel and the utility of a low profile rack
- Use in spaces where other racks cannot fit




UP TO
1250
LBS.


Go Mobile!




30606DOLLYGY for 30606GY and 30607GY
Dolly: 53"L x 27.5" W x 5 7/8" H

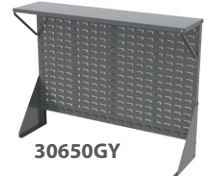


30650GY

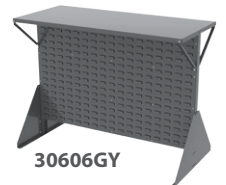

30606GY

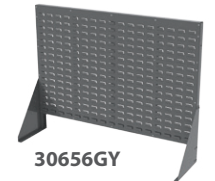

30656GY

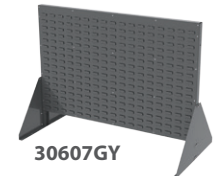

30607GY

- Work height shelf provides additional flexibility
- Heavy-duty 16-gauge, cold-rolled steel for strength and durability
- Capacity - Louvered rack per side: 500 lbs.; Top shelf: 250 lbs.
- The rack can be secured to a wall or floor



Low Profile Floor Rack – Single-Sided		Rack Dimensions (In.)				Bin Dimensions (In.)				
Model No.	Description	W	H	D	Bin Model No.	L	W	H	Bin Qty.	Colors
30650GY	Low Profile Floor Rack	52 1/2	40	13 1/2	–	–	–	–	–	–
30650GY240	Low Profile Floor Rack	52 1/2	40	13 1/2	30240	14 1/4	8 1/4	7	24	B, R, Y, SC
30650GY250	Low Profile Floor Rack	52 1/2	40	13 1/2	30250	14 1/4	16 1/2	7	12	B, R, Y, SC
30650GYASST	Low Profile Floor Rack	52 1/2	40	13 1/2	30240 / 30250	See Above			12/6	B, R, Y, SC
30656GY	Low Profile Floor Rack no Shelf	52 1/2	39 1/2	13 1/2	–	–	–	–	–	B, R, Y, SC
30656GY240	Low Profile Floor Rack no Shelf	52 1/2	39 1/2	13 1/2	30240	14 1/4	8 1/4	7	24	B, R, Y, SC
30656GY250	Low Profile Floor Rack no Shelf	52 1/2	39 1/2	13 1/2	30250	14 1/4	16 1/2	7	12	B, R, Y, SC
30656GYASST	Low Profile Floor Rack no Shelf	52 1/2	39 1/2	13 1/2	30240 / 30250	See Above			12/6	B, R, Y, SC

Specify color of bins when ordering. B=Blue, R=Red, Y=Yellow, SC=Clear.

Low Profile Floor Rack – Double-Sided		Rack Dimensions (In.)				Bin Dimensions (In.)				
Model No.	Description	W	H	D	Bin Model No.	L	W	H	Bin Qty.	Colors
30606GY	Low Profile Floor Rack	52 1/2	40	27	–	–	–	–	–	–
30606GY240	Low Profile Floor Rack	52 1/2	40	27	30240	14 1/4	8 1/4	7	48	B, R, Y, SC
30606GY250	Low Profile Floor Rack	52 1/2	40	27	30250	14 1/4	16 1/2	7	24	B, R, Y, SC
30606GYASST	Low Profile Floor Rack	52 1/2	40	27	30240 / 30250	See Above			24/12	B, R, Y, SC
30607GY	Low Profile Floor Rack no Shelf	52 1/2	39 1/2	27	–	–	–	–	–	B, R, Y, SC
30607GY240	Low Profile Floor Rack no Shelf	52 1/2	39 1/2	27	30240	14 1/4	8 1/4	7	48	B, R, Y, SC
30607GY250	Low Profile Floor Rack no Shelf	52 1/2	39 1/2	27	30250	14 1/4	16 1/2	7	24	B, R, Y, SC
30607GYASST	Low Profile Floor Rack no Shelf	52 1/2	39 1/2	27	30240 / 30250	See Above			24/12	B, R, Y, SC

Specify color of bins when ordering. B=Blue, R=Red, Y=Yellow, SC=Clear.



akro-mils.com

1293 South Main Street, Akron, Ohio 44301 • Tel: 800.253.2467 • Fax: 330.761.6348 • sales@akro-mils.com
In Canada: Ak-West, Inc. • Tel: 877.979.8940 • Fax: 403.225.1696 • sales@ak-westinc.com • ak-westinc.com