


GATEWAY REAR-EXIT FORWARD DESCENT STEEL ROLLING LADDER

The first ever rolling ladder with an rear-exit gate that allows you to exit the ladder onto an elevated surface!

Features:

- Large 27" deep top platform
- 50° Forward descent incline
- 450 lb. rated capacity
- Perforated or Grip Strut tread
- Ships unassembled
- 1-1/16" Tubular steel construction
- Powder coat gray finish
- Step Lock standard on all models
- Complies with applicable OSHA & ANSI standards

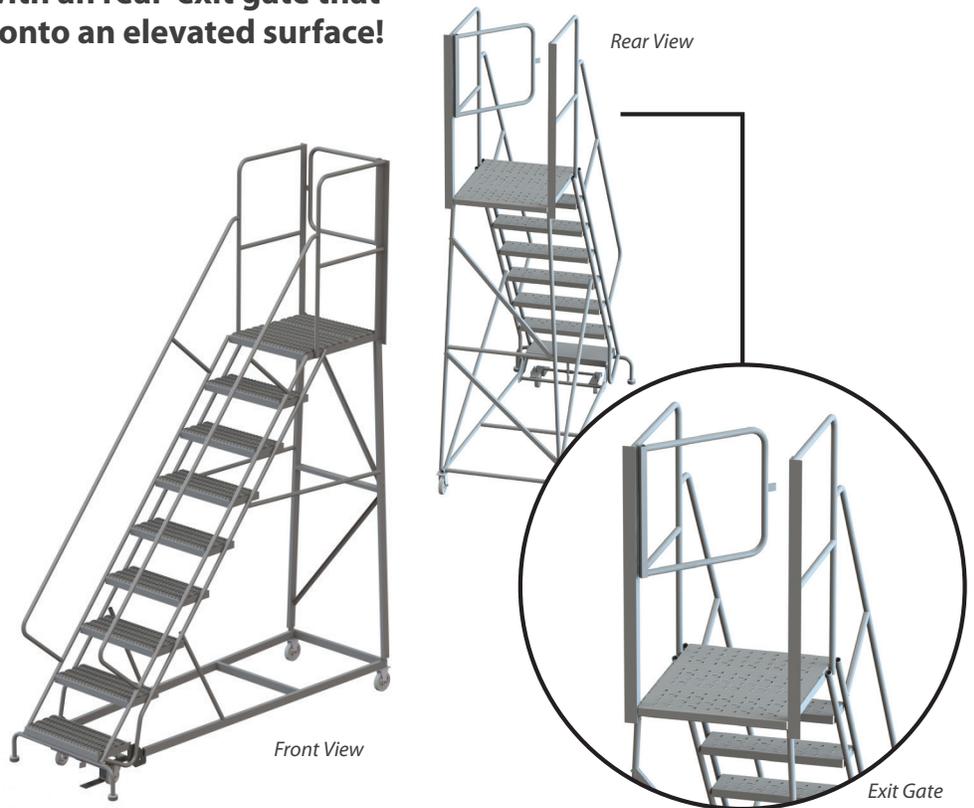

GATEWAY REAR-EXIT FORWARD DESCENT STEEL ROLLING LADDER

PERFORATED		GRIP STRUT		# of Steps	Step Width	Platform Height	Overall Height	Platform W x L	Base W x D
Grainger Stock #	Tri-Arc Model #	Grainger Stock #	Tri-Arc Model #						
WITH HANDRAILS									
45FF75	RWEC106246-XR	45FF85	RWEC106242-XR	6	24"	60"	102"	24" x 27"	35" x 76"
45FF76	RWEC107246-XR	45FF86	RWEC107242-XR	7	24"	70"	112"	24" x 27"	35" x 84"
45FF77	RWEC108246-XR	45FF87	RWEC108242-XR	8	24"	80"	122"	24" x 27"	35" x 92"
45FF78	RWEC109246-XR	45FF88	RWEC109242-XR	9	24"	90"	132"	24" x 27"	35" x 101"
45FF79	RWEC110246-XR	45FF89	RWEC110242-XR	10	24"	100"	142"	24" x 27"	35" x 109"
45FF80	RWEC111246-XR	45FF90	RWEC111242-XR	11	24"	110"	152"	24" x 27"	35" x 117"
45FF81	RWEC112246-XR	45FF91	RWEC112242-XR	12	24"	120"	162"	24" x 27"	35" x 126"
45FF82	RWEC113246-XR	45FF92	RWEC113242-XR	13	24"	130"	172"	24" x 27"	40" x 134"
45FF83	RWEC114246-XR	45FF93	RWEC114242-XR	14	24"	140"	182"	24" x 27"	40" x 142"
45FF84	RWEC115246-XR	45FF94	RWEC115242-XR	15	24"	150"	192"	24" x 27"	40" x 151"



THE EXPERTS IN CLIMBING AND ACCESS

For more information, please contact your Grainger Representative or visit Grainger.com®

