

Toilet Augers

With Heavy Duty Cable

The RIDGID® toilet augers are the professional's choice for quickly opening clogged toilets. They are suitable for both standard and water conserving toilets and are available in 3' and 6' lengths, each provides you with:

- Strong tri-wrap cable with three separate wrappings around the central core to power through and clear tough blockages.
- Vinyl guard to protect toilet bowl.
- Corrosion resistant tube.



K-3 - 3' Toilet Auger

3' of cable completely reaches through the toilet.



K-6 - 6' Toilet Auger

A quick lock adjustment extends the cable reach to 6', clearing beyond the toilet.



Ordering Information

Catalog No.	Model No.	Description	Weight		Std. Pack
			lbs.	kg	
59787	K-3	3' Toilet Auger w/Bulb Head	4.4	2.0	6
59797	K-6	6' Toilet Auger w/Bulb Head	5.5	2.5	6
59802	K-6DH	6' Toilet Auger w/Drop Head	5.5	2.5	6



Snap & Learn! Get The Free Reader
At RIDGID.com/snapandlearn

Hand Spinners

The **K-26** Hand Spinner is a mid-priced tool ideal for users seeking excellent performance and value.

Features include:

- Slip-resistant collet chuck that grips/releases cable quickly and easily.
- $\frac{5}{16}$ " x 25' hollow core cable with bulb head auger.
- Rotary molded plastic drum that won't rust or dent – cleans easily.
- Open drum design that permits access to cable and allows application of Cable Rust Inhibiter.




Ordering Information

Catalog No.	Model No.	Description	in. x ft.	mm x m	lbs.	kg
59812	K-26	Hand Spinner w/C-1 Bulb Head Cable	$\frac{5}{16}$ " x 25'	8 x 7.6	6	2,7

The Professional's Choice, the **K-25** Hand Spinner offers premium quality and a dependable tool for the user who demands the best.

Features include:

- Premium-quality, precision machined, 3-jaw chuck to firmly secure cable. Release cable with a flick-of-the-wrist.
- Cast aluminum ribbed hand grip that won't slip in your hand.
- Rotary molded plastic drum that won't dent or rust – cleans easily.
- Available in bulb head and drop head models. $\frac{5}{16}$ " x 25' vinyl wrapped inner core kink resistant cables.
- Well balanced for comfortable operation.
- Capacity for $\frac{5}{16}$ " x 35' cable.

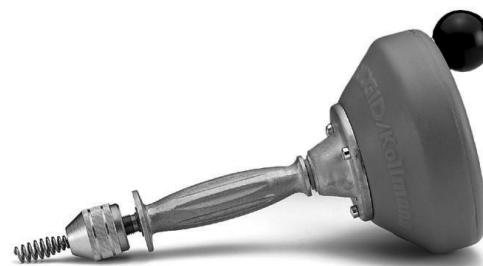

Ordering Information

Catalog No.	Model No.	Description	in. x ft.	mm x m	lbs.	kg
58890	K-25-BP	Hand Spinner w/C-11C Bulb Auger Cable	$\frac{5}{16}$ " x 25'	8 x 7.6	8	3,6
58895	K-25-DH	Hand Spinner w/C-21C Drop Head Cable	$\frac{5}{16}$ " x 25'	8 x 7.6	8	3,6

Distributor

For the complete selection of the RIDGID product line, please refer to the Ridge Tool Catalog or www.RIDGID.com.