


5YL92 - 5YL93 - 5YL94 - 5YL95 - 5YL96 - 5YL97 - 2VE84 - 2VE85 - 2VE86 - 2VE87 - 2VE88
 NON-RATED FLUSH DOOR WITH 1" FLANGE FOR ALL SURFACES

INSTALLATION

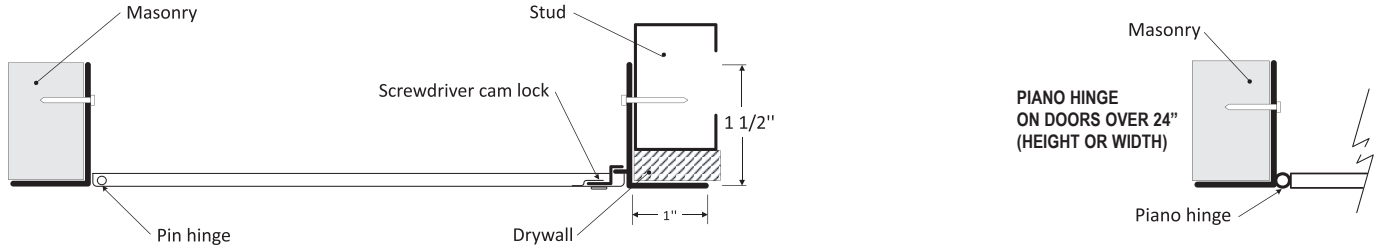


DIMENSION AND APPEARANCE

LEED ready: This product contributes to LEED® credits.

Your odd sizes:
Made in 5 days

DOOR SIZE W x H inches (MM)	NUMBER OF LOCKS	WEIGHT LBS	KG	MODEL
6 x 6 (152 x 152)	1	2	0.9	5YL92
8 x 8 (203 x 203)	1	3	1.4	5YL93
8 x 12 (203 x 304)	1	4	1.8	5YL94
10 x 10 (254 x 254)	1	4	1.8	5YL94
12 x 12 (304 x 304)	1	5	2.3	5YL94
12 x 16 (304 x 406)	1	6.2	2.8	5YL94
12 x 18 (304 x 457)	1	7	3.2	5YL94
12 x 24 (304 x 609)	1	8	3.6	5YL94
14 x 14 (356 x 356)	1	7	3.2	5YL95
16 x 16 (406 x 406)	1	8	3.6	5YL96
18 x 18 (457 x 457)	1	9	4.1	2VE85
18 x 24 (457 x 609)	1	13	5.9	2VE86
20 x 20 (508 x 508)	1	11	5	5YL97
22 x 22 (558 x 558)	1	13	5.9	2VE87
* 22 x 30 (558 x 762)	2	17	7.7	2VE87
* 22 x 36 (558 x 914)	2	19	8.6	2VE87
* 24 x 24 (609 x 609)	1	15	6.8	2VE87
* 24 x 30 (609 x 762)	2	20	9.1	2VE87
* 24 x 36 (609 x 914)	2	22	10	2VE87
* 24 x 48 (609 x 1219)	2	28	12.7	2VE87
* 30 x 30 (762 x 762)	4	23	12.7	2VE88
* 36 x 36 (914 x 914)	4	31	14.1	2VE88

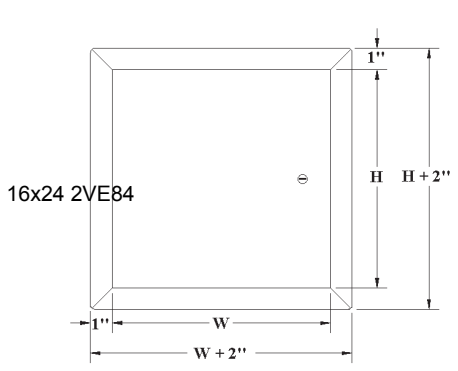

Rough wall opening is door size + 1/4" or + 6mm
 *Piano hinge on doors over 24 inches (height or width)

DESCRIPTION AND MATERIAL SPECIFICATION

Material: 16 gauge cold rolled steel
Hinge: hidden pin hinge
 continuous piano type on doors
 over 24" (height or width)
Lock / latch: screwdriver operated cam latch
Finish: DuPont® high quality grey powder coat
Packaging: individually wrapped, 1 per box

POPULAR OPTIONS
Lock / latch: key operated cylinder cam latch,
 hex head cam latch, pinned hex
 head cam latch, handle operated cam latch,
 mortise preparation for cylinder.
Material: stainless steel 304 #4 (brushed finish)
Finish: DuPont® high quality white powder coat
Gasketing: neoprene gasket



PROJECT DATA

PROJECT NAME:	QTY	W	H	OPTIONS
ARCHITECT:				
DEALER:				
CONTRACTOR:				
LOCATION:	SPECIAL INSTRUCTIONS:			
DATE:				
TAGGING INSTRUCTIONS:	SUBMITTAL APPROVAL: (signature or stamp)			