


CAT-5e PRETERMINATED CABLE

SPECIFICATIONS

350MHz
 4 Pair 24 AWG Wire
 ROHS Complaint
 TIA/EIA-568-B.2 Wired
 UL
 ETL
 Plenum Rated

OVERVIEW

Utilizing pre-terminated **CAT-5e** cables is a great way to reduce labor costs. These **CAT-5e** patch cables are pre-terminated with RJ45 style connectors on both ends. All cables are plenum rated and conform to the T568B pin-pair specification. The RJ-45 terminations are unbooted (i.e. no molded strain relief) which allows for easier connection to nLight devices. Cables are available in several lengths for convenience. All cables are white and labeled "Acuity Brands Controls".

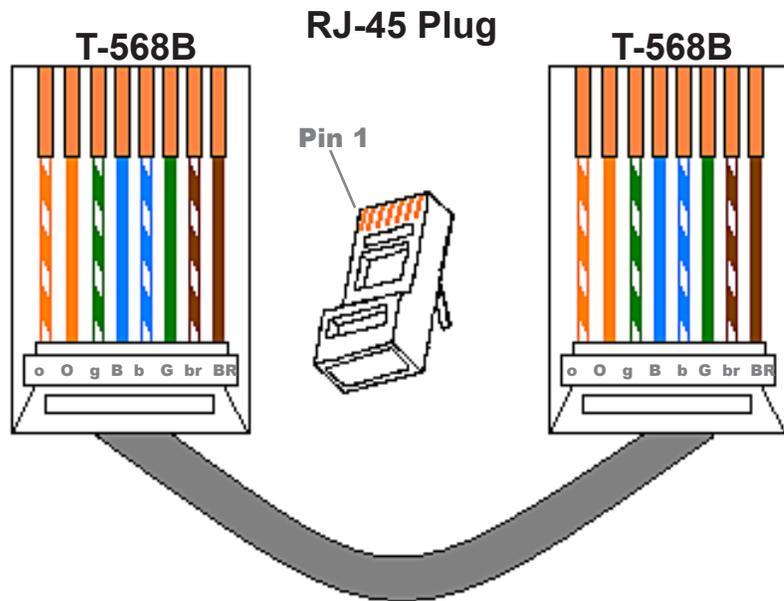

ORDERING INFO

CAT5 6IN J1 = 6 in Cable
 CAT5 1FT Y = 1 ft Male to Female Y Splitters (10 Count)
 CAT5 2FT J1 = 2 ft Cable
 CAT5 5FT J1 = 5 ft Cable
 CAT5 10FT J1 = 10 ft Cable

CAT5 15FT J1 = 15 ft Cable
 CAT5 30FT J1 = 30 ft Cable
 CAT5 50FT J1 = 50 ft Cable
 CAT5 Y = All Female Y Splitters (10 Count)



WARRANTY: Sensor Switch, Inc. warrants these products to be free of defects in manufacture and workmanship for a period of 60 months. Sensor Switch, Inc., upon prompt notice of such defect, will, at its option, provide a Returned Material Authorization number and repair or replace returned product.

LIMITATIONS AND EXCLUSIONS: This Warranty is in full lieu of all other representation and expressed and implied warranties (including the implied warranties of merchantability and fitness for use) and under no circumstances shall Sensor Switch, Inc. be liable for any incidental or consequential property damages or losses.