

ALBION[®]

CASTERS AND WHEELS

Low Profile Casters

- Double Row Swivel Raceways
- 3/8" Diameter Nut & Bolt Axle
- Heat Treated and Factory Lubricated Raceways

Applications:

Electronic Equipment,
Business Machines,
Store Fixtures, Laboratory
Equipment



Matches Up With the ER Wagner 500 Series

Wheel Dia. (In.)	Tread Width (In.)	Load Rating (Lb.)	Wheel Bearing	Overall Height (In.)	Plate Type Number	Swivel Part Number	Swivel W/Brake Part Number	Rigid Part Number
------------------	-------------------	-------------------	---------------	----------------------	-------------------	--------------------	----------------------------	-------------------

PLATE CASTERS

Hard Rubber Wheel (Delrin Bearing)

2	13/16 (dual)	200	Delrin	2-7/8	A	202RN02052S003	202RN02X52S002	202RN02052R001
2	13/16 (dual)	200	Delrin	2-7/8	B	202RN02052S004	NA	202RN02052R002
2-1/2	13/16 (dual)	300	Delrin	3-1/2	A	202RN02X052S001	202RN02X52S001	202RN02X52R001
3	13/16 (dual)	350	Delrin	3-7/8	A	202RN03052S002	NA	202RN03052R001
3	13/16 (dual)	350	Delrin	3-7/8	B	202RN03052S003	NA	202RN03052R002

Polyurethane Wheel (Precision Ball Bearing)

3	1-3/4	450	Ball	3-7/8	A	20IX03227S001	20IX03227S002	20IX03227R001
---	-------	-----	------	-------	---	---------------	---------------	---------------

Polyolefin Wheel (Plain Bearing)

3	1-3/4	350	Plain	3-7/8	A	20IB03241S001	20IB03241S002	20IB03241R001
---	-------	-----	-------	-------	---	---------------	---------------	---------------

Phenolic Wheel (Roller Bearing)

3	1-3/4	500	Roller	3-7/8	B	20TM03201S008	20TM03201S007	20TM03201R006
---	-------	-----	--------	-------	---	---------------	---------------	---------------

Wheel Dia. (In.)	Tread Width (In.)	Load Rating (Lb.)	Wheel Bearing	Overall Height (In.)	Stem Type	Stem Dimensions (In.)	Swivel Part Number
------------------	-------------------	-------------------	---------------	----------------------	-----------	-----------------------	--------------------

STEM CASTERS

Hard Rubber Wheel (Delrin Bearing)

2	13/16 (dual)	200	Delrin	2-3/4	Leveling w/Nut	1/2-13 x 2-1/2	202RN02052S002
2	13/16 (dual)	200	Delrin	2-3/4	Threaded	1/2-13 x 1-1/2	202RN02052S001
2	13/16 (dual)	200	Delrin	2-3/4	Friction Ring	7/16 x 1-3/8	202RN02052S-S21
3	13/16 (dual)	350	Delrin	3-3/4	Leveling w/Nut	1/2-13 x 2-1/2	202RN03052S001
3	13/16 (dual)	350	Delrin	3-3/4	Threaded	1/2-13 x 1-1/2	202RN03052S-S30

 
Polyolefin Wheel (Plain Bearing)

3	1-3/4	350	Delrin	3-3/4	Threaded	1/2-13 x 3/4	DCIB03141S-S32
3	1-3/4	350	Plain	3-3/4	Threaded	3/4-10 x 1	DCIB03141S-S50

Phenolic Wheel (Roller Bearing)


3	1-3/4	350	Roller	3-3/4	Leveling w/Nut	1/2-13 x 2-1/2	DCIT03101S001
---	-------	-----	--------	-------	----------------	----------------	---------------

A Plate



Overall Size: 3-1/8" x 4-1/8"
Hole Soacing: 1-3/4" x 3 slotted to 2-3/8" x 3-3/8"
Bolt Dia.: 5/16"

B Plate

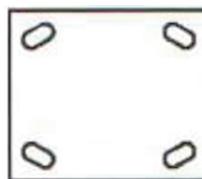

Overall Size: 3-3/4" x 4-5/8"
Hole Soacing: 2-5/8" x 3-5/8" slotted to 3" x 3"
Bolt Dia.: 5/16"