

ALBION®


CASTERS AND WHEELS

08 Series Casters

- Double Row Swivel Raceways
- 3/8" Diameter Nut & Bolt Axle
- Heat Treated and Factory Lubricated Raceways
- Zinc Finish
- Roller Bearings
- Thread Guards

Applications:


Dollies, Warehouse Trucks,
Floor Trucks, Shop Carts,
Toolboxes

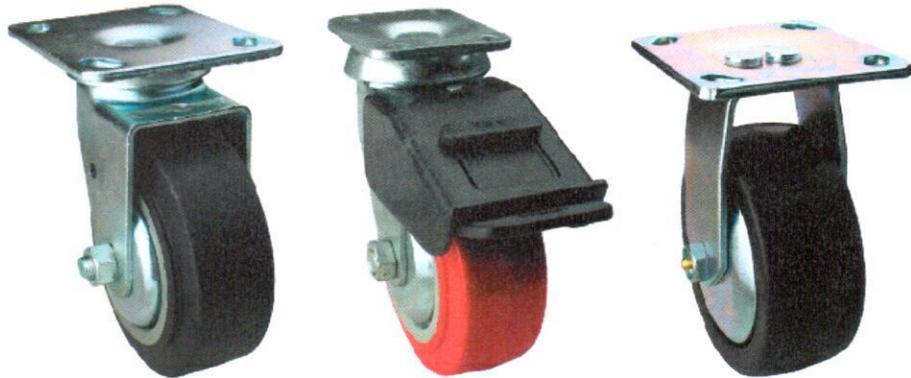

Matches Up With the ER Wagner 700# Series

Wheel Dia. (In.)	Tread Width (In.)	Load Rating (Lb.)	Overall Height (In.)	Plate Type Number	Swivel Part Number	Total-Lock Part Number	Directional-Lock Part Number	Rigid Part Number
Black Thermoplastic Rubber Wheel (Roller Bearing)								
4	2	300	5-5/8	A	08IS04201S001	08IS04201S002	08IS04201S003	08IS04201R001
5	2	350	6-1/2	A	08IS05201S003	08IS05201S004	08IS05201S005	08IS05201R002
6	2	400	7-1/2	A	08IS06201S001	08IS06201S002	08IS06201S003	08IS06201R001
Red Polyurethane Wheel (Roller Bearing)								
4	2	600	5-5/8	B	08IX04201S004	08IX04201S005	08IX04201S006	08IX04201R004
5	2	650	6-1/2	B	08IX05201S001	08IX05201S002	08IX05201S004	08IX05201R002
6	2	700	7-1/2	B	08IX06201S002	08IX06201S004	08IX06201S006	08IX06201R002
Red Polyurethane Wheel (Roller Bearing)								
4	2	600	5-5/8	A	08IX04201S001	08IX04201S002	08IX04201S003	08IX04201R001
5	2	650	6-1/2	A	08IX05201S005	08IX05201S006	08IX05201S003	08IX05201R001
6	2	700	7-1/2	A	08IX06201S001	08IX06201S003	08IX06201S005	08IX06201R001
Black Polyolefin Wheel (Roller Bearing)								
4	2	600	5-5/8	A	08IB04201S001	08IB04201S002	08IB04201S003	08IB04201R001
5	2	650	6-1/2	A	08IB05201S001	08IB05201S002	08IB05201S003	08IB05201R001
6	2	700	7-1/2	A	08IB06201S001	08IB06201S002	08IB06201S003	08IB06201R001
Black Phenolic Wheel (Roller Bearing)								
4	2	600	5-5/8	A	08IT04201S001	08IT04201S002	08IT04201S003	08IT04201R001
5	2	650	6-1/2	A	08IT05201S001	08IT05201S002	08IT05201S003	08IT05201R001
6	2	700	7-1/2	A	08IT06201S001	08IT06201S002	08IT06201S003	08IT06201R001
Gray Pneumatic Wheel (Ball Bearing)								
6	2	200	7-1/2	A	08SG06227S	08SG06227ST	NA	08SG06227R
6	2	200	7-1/2	B	08SG06227S001	08SG06227S002	NA	08SG06227R001

A Plate

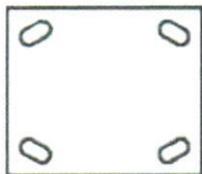

Overall Size: 3-3/4" x 4-5/8"
Hole Soacing: 2-5/8" x 3-5/8"
slotted to 3" x 3"
Bolt Dia.: 3/8"

B Plate



Overall Size: 2-3/4" x 3-3/4"
Hole Soacing: 1-3/4" x 2-7/8"
slotted to 3"
Bolt Dia.: 5/16"

www.albioninc.com Tel: 800-835-8911 Fax: 517-680-7010

