

YES! ✓ WE CAN!



AQUAMAX SOLID PLASTIC LOCKERS

A complete line of plastic lockers specifically manufactured to meet demanding industry needs where maximum protection against rust and corrosion is essential.

FEATURES:

- BODY CONSTRUCTION:** Corrosion Proof High Density (HDPE) Polyethylene, 1/2" thick door with 3/8" thick body panels
- BODY STYLES:** Single, double, triple, six and Z-tiers
- DOOR (wardrobe & box):** Plain with perimeter ventilation
- HINGES:** Continuous aluminum hinge is powder coated
- HANDLE (wardrobe):** Projecting solid plastic handle with lift-type latching
- HANDLE (box):** Single-point thru-the-door padlock hasp with projecting pull handle
- SHELVES:** Upper and lower shelf included in single tier lockers
- HOOKS:** Two single hooks are included in single and double tier




Single tier
1-wide
1 opening

Double tier
1-wide
2 openings

Triple tier
1-wide
3 openings

Six tier
1-wide
6 openings

"Z" tier
1-wide
2 openings

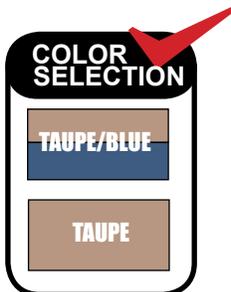

Locker Type	Overall Dimensions (in.)			Opening Dimensions (in.)			Fully-Assembled TAUPE Item No.	Fully-Assembled TAUPE/BLUE Item No.	Shpg Wt
	W	H	D	W	H	D			
SINGLE TIER									
1 wide, 1 opening	12	72	18	11-1/4	71-1/4	17	16X108	16X110	67
3 wide, 3 openings	36	72	18	11-1/4	71-1/4	17	16X109	16X111	173
DOUBLE TIER									
1 wide, 2 openings	12	72	18	11-1/4	35-3/8	17	16X112	16X114	68
3 wide, 6 openings	36	72	18	11-1/4	35-3/8	17	16X113	16X115	176
TRIPLE TIER									
1 wide, 3 openings	12	72	18	11-1/4	24-1/2	17	16X116	16X118	68
3 wide, 9 openings	36	72	18	11-1/4	24-1/2	17	16X117	16X119	176
SIX TIER									
1 wide, 6 openings	12	72	18	11-1/4	11-1/4	17	16X120	16X122	87
3 wide, 18 openings	36	72	18	11-1/4	11-1/4	17	16X121	16X123	233
Z TIER									
1 wide, 2 openings	12	72	18	11-1/4	47-1/4	17	16X124	16X126	73
3 wide, 6 openings	36	72	18	11-1/4	47-1/4	17	16X125	16X127	191
SPACE CUBE									
1 wide, 1 openings	12	12	18	11-1/4	11-1/4	17	16X128	---	