



www.BradyID.com/bmp21

Meet The Newest Member Of Your Crew.

BMP®21 LABEL PRINTER

Simple to operate and quick to print, the BMP®21 label printer is the economical, must-have labeling tool for voice/data comm, electrical and general industrial crews. With this thermal transfer printer, you can create your labels just once - knowing they'll stay stuck and stay legible for the years ahead.

"I would gladly put this labeler in my travel tool kit. Combined with a few different media cartridges it would cover nearly any telecom and network labeling I conceivably encounter in the field"

Ty King,
Forest Oil Corporation



Faster, More Efficient Labeling

- Magnet and pole/wrist-strap for one-handed operation
- Automated serialized printing
- Built-in symbols
- Industrial-strength dual cutter that holds labels until you need them



Durable, Made-to-Last Labels

- Wide array of label types and sizes
- Labels withstand extreme temperatures, irregular surfaces, and chemicals
- Vinyl material lasts up to 5 years in extreme outdoor conditions




All-in-One Industrial Labeling Tool

- Crystal clear thermal transfer printing
- On demand labels for organizing & identifying

Learn more and view our demo video:
www.BradyID.com/bmp21

BMP[®]21 LABEL PRINTER

Part Numbers

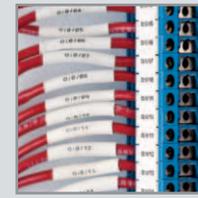

SELF-LAMINATING VINYL*



PROPERTIES:

- Self Extinguishing
- Excellent water & oil resistance
- Excellent abrasion resistance

	0.75" x 14.0'	1.0" x 14.0'	1.25" x 14.0'	1.5" x 14.0'
Black on White	M21-750-427*	M21-1000-427*	M21-1250-427*	M21-1500-427*

*Not compatible with the ID Pal™ Printer.

NYLON CLOTH




IDEAL FOR:

- Wire & Cable
- Patch Panels
- Terminal Blocks
- Face Plates

	0.375" x 16.0'	0.5" x 16.0'	0.75" x 16.0'
Black on White	M21-375-499	M21-500-499	M21-750-499
Terminal Block	M21-375-499-TB	M21-500-499-TB	

PERMASLEEVE[®] WIRE MARKER SLEEVES

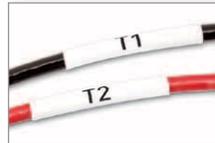


PROPERTIES:

- Heat-Shrinkable
- Self Extinguishing
- Meets MIL-M-81531; MIL-STD-202F; method 215 and UL 224

	0.125" x 7.0'	0.187" x 7.0'	0.250" x 7.0'	0.375" x 7.0'
Black on White	M21-125-C-342*	M21-187-C-342*	M21-250-C-342*	M21-375-C-342*

*Not compatible with the ID Pal™ Printer.

POLYESTER

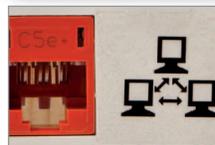

IDEAL FOR:

- Components
- Instruments
- Racks & Bins

	0.375" x 21.0'	0.5" x 21.0'	0.75" x 21.0'
Black on White	M21-375-423	M21-500-423	M21-750-423
Black on Clear	M21-375-430	M21-500-430	M21-750-430

INDOOR/OUTDOOR VINYL FILM



PROPERTIES:

- Adheres to irregular, curved or rough surfaces
- Stands up to grease, oil and most industrial chemicals
- 5 year average outdoor durability in temperatures from -40°F to 180°F

IDEAL FOR:

- Pipes
- Round Surfaces
- Tools
- Containers
- Bins
- Components
- Instruments
- Panels

	0.375" x 21.0'	0.5" x 21.0'	0.75" x 21.0'
Black on White	M21-375-595-WT	M21-500-595-WT	M21-750-595-WT
Black on Yellow	M21-375-595-YL	M21-500-595-YL	M21-750-595-YL
Black on Orange	M21-375-595-OR	M21-500-595-OR	M21-750-595-OR
White on Red	M21-375-595-RD	M21-500-595-RD	M21-750-595-RD
White on Blue	M21-375-595-BL	M21-500-595-BL	M21-750-595-BL
White on Green	M21-375-595-GN	M21-500-595-GN	M21-750-595-GN

PRINTER & ACCESSORIES



Part Number	Description
BMP21	BMP21 Label Printer
BMP21-TOOL	Multi-Functional Tool (magnet, flashlight, pole-strap, stand)
BMP21-MAGNET	Magnet Only Accessory
BMP21-HC	Hard Carrying Case for BMP21 Printer
BMP21-AC	AC Adapter for BMP21 Printer

* Printer purchase included 1 year Limited Warranty.

**Tool Accessory includes magnet, flashlight, polestrap, stand and beltloop.
U.S. Patent No. 8,322,936

! Cross Compatible

BMP[®]21 and ID Pal™ label cartridges can be used in either the BMP[®]21 Label Printer or the ID Pal™ Printer except for those denoted by an asterisk(*).

USA

Customer Service: 1-888-272-3946
Inside Sales: 1-888-311-0775
www.BradyID.com

Canada

Customer Service: 1-800-263-6179
www.BradyCanada.ca

Mexico

Customer Service: 1-800-262-7777
Inside Sales: 1-800-262-7777 ext 177
www.BradyLatinAmerica.com

Learn more and view our demo video:
www.BradyID.com/bmp21

BRADY[®]
WHEN PERFORMANCE MATTERS MOST™