



FEATURES


- Die formed steel housing with knockouts for stems or chain hangers
- Die embossed reflector with ribs
- Most models available with 5% uplight
- Individual or continuous row mounting
- Channel ends double as joiners
- All painted parts are treated with a five stage phosphate bonding process and finished with a baked white enamel
- UL listed 1598, cUL or CSA. Damp Location standard

ORDERING INFORMATION

CSR						
MODEL	NO. OF LAMPS	REFLECTOR TYPE	VOLTAGE	OPTIONS		
CSR Industrial	<ol style="list-style-type: none"> One Two Three (T8 or T5) See Product Availability table below.	ST Solid Top Reflector U Apertured Reflector for 5% Uplight (Standard) (Solid Reflector not recommended with HO units) LSRU Apertured Alum. Reflector with Specular Silver Finish LSRST Solid Top Alum. Reflector with Specular Silver Finish M4RU Apertured Alum. Reflector with 95% Reflective Specular Silver Finish M4ST Solid Top Alum. Reflector with 95% Reflective Specular Silver Finish	U 120V-277V 347 347V	BC1 Branch Circuit Wiring Single Circuit (For more branch circuit wiring options see page 113.) EL Emergency Battery Pack GLR Fast Blow Fuse GMF Slow Blow Fuse PAF Paint After Fabrication NYC NYC Compliant NYCU NYC Compliant, Union Label		
SIZE	LAMP TYPE	BALLAST	ACCESSORIES (ORDER SEPARATELY)			
4 4' 8 8' 16 16' (Two housings)	28 4', T5: 28 Watt 32 4', T8: 32, 30, 28 or 25 Watt 48 4', T12 48HO 4', T12: 60 Watt 54 4', T5HO: 54 or 51 Watt 96 8', T12: 75 or 60 Watt 96T8 8', T8: 59 Watt 96HO 8', T12: 110 or 95 Watt 96T8HO 8', T8: 86 Watt	NOTE: See Technical Section for other ballast options. E Electronic, Instant Start 3E 3-Lamp Electronic T8 (32W), Instant Start 4E 4-Lamp Electronic T8 (32W), Instant Start 24E (1) 2-Lamp and (1) 4-Lamp Electronic T8 (32W), Instant Start EP Electronic, Programmed Start 3EP 3-Lamp Electronic T5HO or T8, Programmed Start 4EP 4-Lamp Electronic T5HO (N/A 347V) or T8, Programmed Start Instant Start ballasts available for 32, 96, and 96T8. Programmed Start ballasts available for all except 96 and 96T8.	CSRWG Wireguard CSHC Chain Hanger (pair) CSTH Slide Tong Hanger (pair) OS1360K Occupancy/Daylight sensor kit, 120/277/347V, one relay, 360 Lens, snap on drop down adaptor, quick connect wiring ¹			

¹Use programmed start ballast. Not recommended for use with instant start. For more occupancy/daylight harvesting sensor accessories see the Industrial and Striplight Accessories page in the Technical section.

For more options see pages 96-112.
For more accessories see Technical section.

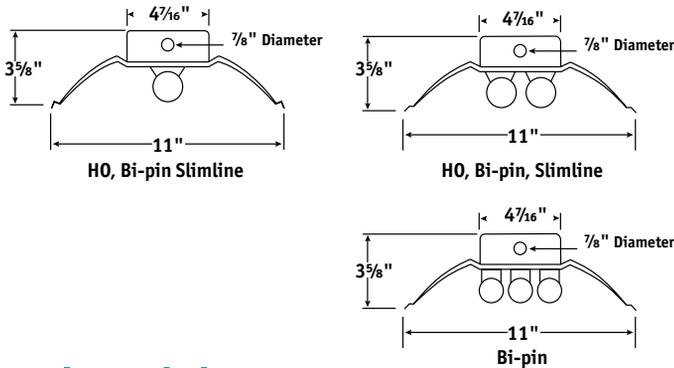

PRODUCT AVAILABILITY

SIZE	NO. OF LAMPS IN CROSS SECTION	NO. OF LAMPS IN FIXTURE	LAMP TYPE	WIDTH	LENGTH	HEIGHT
4'	1	1	28, 32	11"	48"	3 5/8"
	2	2	28, 32	11"	48"	3 5/8"
	1	1	48, 48HO, 54	11"	48"	3 5/8"
	2	2	48, 48HO, 54	11"	48"	4 1/2"
	3	3	28, 32, 54	11"	48"	3 5/8"
8'	1	2	28, 32, 54	11"	96"	3 5/8"
	2	4	28, 32, 54	11"	96"	3 5/8"
	1	2	96, 96T8	11"	96"	3 5/8"
	2	2	96, 96T8	11"	96"	3 5/8"
	2	2	96HO, 96T8HO	11"	96"	4 1/2"
	3	6	28, 32	11"	96"	3 5/8"
	16' (Two housings)	2	8	28, 32, 54	11"	192"
2		4	96, 96T8	11"	192"	3 5/8"
2		4	96HO, 96T8HO	11"	192"	4 1/2"