


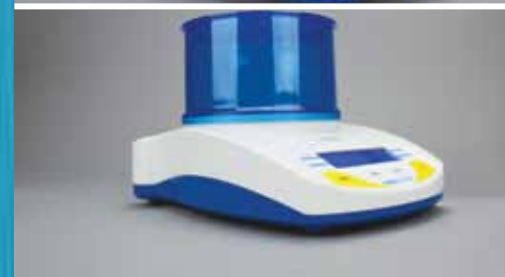

Core[®] *Compact Portable Balances*

Compact and easy to use, no other comparable balance rivals the Core[®] for value and features. The Core operates smoothly and looks sleek, but it's created for utility. The ABS housing withstands field, classroom and laboratory environments, and the stainless steel pan is removable, making it simple to clean. ShockProtect[®] safeguards the load cell, so it can handle overloads without damage. To help prevent theft, a built-in security slot accommodates an optional Kensington-type lock and cable. Portability is not an issue with the Core, as the balance operates by battery or AC adapter. A convenient weigh-below hook facilitates below-balance weighing for density and specific gravity measurements.



Core® Compact Portable Balances


Features

- Vivid, backlit LCD easily visible in any lighting conditions
- Programmable backlight can be set to “always on”, “always off” or “light only when weighing”
- Balances stack efficiently and safely to save space (120mm pan size only)
- Color-coded keys facilitate quick recognition of the most frequently used buttons
- Dual tare keys facilitate left- or right-handed operation
- Security slot for optional Kensington-type lock and cable to help prevent theft
- Large, type 304 stainless steel pan allows swift cleaning

- Rugged construction stands up to industrial use
- Three-point ShockProtect® feature helps prevent overload damage to internal components
- Auto power-off to save energy
- Audible overload alarm warns when capacity has been exceeded
- External calibration allows for verification and adjustment with weights
- Zero-tracking feature ensures display returns to zero reading
- Operates with AC adapter (included) or batteries (not included)

Applications

- Weighing

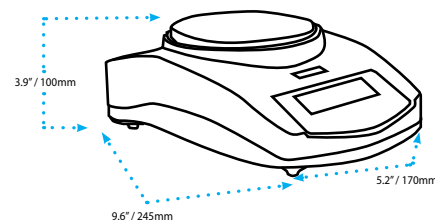

Model	CQT 202	CQT 251	CQT 601	CQT 1501	CQT 2000	CQT 2601	CQT 5000
Capacity	200g	250g	600g	1500g	2000g	2600g	5000g
Readability	0.01g	0.1g	0.1g	0.1g	1g	0.1g	1g
Repeatability (S.D.)	0.02g	0.1g	0.1g	0.1g	1g	0.1g	1g
Linearity (+/-)	0.02g	0.1g	0.1g	0.2g	1g	0.2g	1g
Pan Size	4.7" ø / 120mm ø				5.7" ø / 145mm ø		
Weighing Units	g, kg, lb, oz, N, GN, ct, dr, tl.T						
Stabilization Time (sec)	3	2		3			2
Calibration	External calibration						
Display	Backlit LCD with 0.7" / 18mm-high digits						
Power Supply	12VAC 150mA adapter / 6 x AA batteries						
Operating Temperature	0° to 40°C / 32° to 104°F						
Housing	ABS						
Draft Shield	Round 5.1" ø x 3.5" / 130mm ø x 90mm				N/A		
Overall Dim.	6.7"x9.8"x3.1" / 171x250x80mm						
Net Weight	1.98lb / 0.90kg						

For more than 40 years, professionals worldwide have relied on Adam Equipment for an extensive selection of dependable and affordable weighing equipment. Adam provides the right balance of speed, performance and value.

ACCESSORIES

- | | |
|-----------|--------------------------------|
| 308002042 | Hard carrying case w/ lock |
| 308232033 | In-use wet cover |
| 308232036 | In-use wet cover (pack of 5) |
| 308232037 | In-use wet cover (pack of 10) |
| 700100046 | Kensington type lock and cable |

Supplied by: