

KEY DIMENSIONS	
Case Width:	30"
Case Depth:	18"
Case Height:	
Standard Height	28"
Universal Height	27-1/4"

Features:

Flagship File Centers are available in multiple configurations. The personal file center with a box, box, file and lateral drawer configuration ships with the file drawer on the left and box drawers on the right, but can be reconfigured in the field to move the file drawer to the right side and box drawers to the left. Other configurations include a storage unit with or without doors and one centered adjustable shelf; a bottom lateral drawer with a full width fixed shelf; a two box drawer, one file drawer and a storage area with one shelf on the opposite side; or two file drawers with storage area with one shelf on the opposite side. Lateral drawers accommodate letter, legal and A4 sized filing. All models are available in the standard 28" height, and the box, box, file with a lateral drawer models are also available in a universal 27-1/4" height.

The storage area adjustable shelves adjust in 2" increments utilizing two 11-5/16" front to back shelf brackets per shelf.

Construction:

Cold rolled steel construction features bends and forming throughout components to add strength where needed for a robust construction.

- Welded case construction with welded top and bottom front corners and a fully enclosed bottom.
- Front and rear vertical uprights are welded into case.
- Storage area doors have welded stiffeners for added rigidity.
- Knockouts are present in top of cabinets for ganging units side to side or back to back, 1 per side and 2 on the back. 4 knockouts are provided on the top surface for work surface mounting. Hardware is provided.

Counterweight:

Included on models with extendible drawers to meet ANSI/BIFMA stability requirements.

Finish:

Steel parts are finished with a baked enamel over a rust-inhibiting phosphate pre-treatment.

Drawer suspension:

Heavy-duty ball bearing slides with full drawer extension on all drawers.

Locks:

A polished chrome face cam lock is core removable with the ability to key alike. Lock activates a steel rod that in turn operates a lockbar on both sides of the lateral drawer and one side of box and file drawers, where offered. Storage doors do not lock. Two keys per lock are supplied.

Glides:

Four leveling glides constructed of black nylon with 5 threads per inch are accessible from inside the cabinet, adjustable with a 3/8" 6-point socket wrench. There is 1-1/8" adjustment and glides are shipped installed.

QUICK REFERENCE TABLE - Exterior Dimensions

Model Types	Standard Height	Universal Height
Case Depth x Width	18" x 30"	18" x 30"
Case Height	28"	27-1/4"
Full Door Height	23-5/8"	N/A
Half Door Height	11-13/16"	N/A
Top Height	1-3/8"	1-3/8"
File/Lateral Drawer Front Ht	11-3/4"	11-3/4"
Box Drawer Front Height	5-13/16"	5-13/16"
Kickplate Height	2-3/4"	2"

The HON Company
200 Oak Street
Muscatine, IA 52761
800-833-3964
hon.com

Hardware:

Three pull styles are available:

- 'A' – Satin Chrome Arch Pull
- 'N' – Full Integral Pull
- 'R' – Full Radius Pull

Magnetic label holder, one per lateral drawer and one 8-1/2" x 11 sheet of 10 paper inserts.

File drawers include plastic follower and cross rail.
Box drawers include plastic snap-in divider.

Storage door hinges provide a 110° swing, nickel plated.
Storage doors have rubber closing bumpers, top and bottom.
Ganging hardware is provided, which consists of two 1/4-20 x 1/2" screws and two 1/4-20 nuts.
Adjustable hangrails are provided in lateral drawers for side-to-side filing (2 per drawer).


Shipping Information:

File Centers ship assembled in a stretch wrapped package with innerpack for protection. 'A' style arch pulls are installed by end user using a phillips head screwdriver.

Compliance:


Meets or exceeds applicable ANSI/BIFMA and ISTA Standards. Certified SCS Indoor Advantage™ Gold

Lateral Drawer Filing Options:

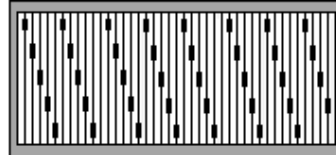

Side-to-side filing:

30" wide files: 27" of filing with letter or legal.

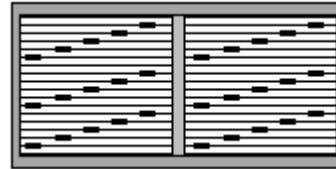

Front-to-back filing:

30" wide files: 30 1/2" of filing with letter/letter rows.
Requires H919491 or H919492 optional hangrails.

QUICK REFERENCE TABLE - Interior Dimensions

	Inside Drawer (W-D-H)	Weight Capacity per drawer
Lateral Drawers	27-1/4" x 15-5/8" x 11-1/4"	85 lbs.
Box Drawers	12-3/16" x 14-15/16" x 4-5/8"	14 lbs.
File Drawers	12-3/16" x 14-15/16" x 10-9/16"	32 lbs.
Full Width Storage Shelf	28-3/4" x 17" x 11-5/8"	84 lbs.
Half Width Storage Shelf	13-11/16" x 17" x 11-5/8"	42 lbs.



Flagship® File Centers Technical Specifications

Models:	Description:
HFC16730A	Universal Height Box, Box and File with Lateral Drawer
HFC16730N	Universal Height Box, Box and File with Lateral Drawer
HFC16730R	Universal Height Box, Box and File with Lateral Drawer
HFC1830BDA	Standard Height Box, Box and File Drawers with Right Door Storage
HFC1830BDN	Standard Height Box, Box and File Drawers with Right Door Storage
HFC1830BDR	Standard Height Box, Box and File Drawers with Right Door Storage
HFC1830DBA	Standard Height Box, Box and File Drawers with Left Door Storage
HFC1830DBN	Standard Height Box, Box and File Drawers with Left Door Storage
HFC1830DBR	Standard Height Box, Box and File Drawers with Left Door Storage
HFC1830DDA	Standard Height Bookcase with doors
HFC1830DDN	Standard Height Bookcase with doors
HFC1830DDR	Standard Height Bookcase with doors
HFC1830DFA	Standard Height File, File Drawers with Left Door Storage
HFC1830DFN	Standard Height File, File Drawers with Left Door Storage
HFC1830DFR	Standard Height File, File Drawers with Left Door Storage
HFC1830DLFA	Standard Height Lateral Drawer with Shelf and Doors
HFC1830DLFN	Standard Height Lateral Drawer with Shelf and Doors
HFC1830DLFR	Standard Height Lateral Drawer with Shelf and Doors
HFC1830FDA	Standard Height File, File Drawers with Right Door Storage
HFC1830FDN	Standard Height File, File Drawers with Right Door Storage
HFC1830FDR	Standard Height File, File Drawers with Right Door Storage
HFC1830NLFA	Standard Height Lateral Drawer with Open Shelf
HFC1830NLFN	Standard Height Lateral Drawer with Open Shelf
HFC1830NLFR	Standard Height Lateral Drawer with Open Shelf
HFC1830NN	Standard Height Bookcase without doors
HFC18730A	Standard Height Box, Box and File with Lateral Drawer
HFC18730N	Standard Height Box, Box and File with Lateral Drawer
HFC18730R	Standard Height Box, Box and File with Lateral Drawer

The HON Company
200 Oak Street
Muscatine, IA 52761
800-833-3964
hon.com