

The bright white radiance of GE's LED A-Line lamps is not just something you see, it's something you feel.

# LED A-Line general purpose bulb


## PERFORMANCE DATA

### A-Line Lamps


Bulb Shape	Base Type	Watts	Order Code	Description	Volts	Case Qty	MOL (in)	Lumens Initial	Initial Color Temp	CBCP	CRI	Wattage Equivalent	*Rated Life L70 (Hrs)	Dimmable	ENERGY STAR® Status	#Location Rating	Additional Information
<b>A-15</b>																	
	MED	3	63011	LED3A15/W/TP	120	3	3.5	120	3000	80	-	15,000	-	-	-	Dry	White
			63012	LED3A15/C/TP	120	3	3.5	120	3000	80	-	15,000	-	-	-	Dry	Clear
	MED	4.5	68173	LED4DA15-W/TP	120	3	3.5	270	2700	82	25W	15,000	Yes	-	-	Damp	White
			68174	LED4DA15-C/TP	120	3	3.5	270	2700	82	25W	15,000	Yes	-	-	Damp	Clear
			14644	LED4.5DA15-C/827	120	6	3.5	300	2700	80	40W	15,000	Yes	-	-	Damp	Clear
<b>A-19</b>																	
	MED	7	14063	LED7DAV3/827W	120	6	4.6	470	2700	80	40W	25,000	Yes	-	-	Damp	White, Semi-Omni
			95928	LED7DAV3/5K	120	6	4.6	500	5000	80	40W	25,000	Yes	-	-	Damp	White, Semi-Omni
			11332	LED7DA19/827	120	6	4.4	450	2700	80	40W	25,000	Yes	★	-	Damp	White, Omnidirectional
			71208	LED7DA19/830	120	6	4.4	450	3000	80	40W	25,000	Yes	★	-	Damp	White, Omnidirectional
	11	11328	LED11DA19/827	120	6	4.4	800	2700	80	60W	25,000	Yes	★	-	Damp	White, Omnidirectional	
		71209	LED11DA19/830	120	6	4.4	800	3000	80	60W	25,000	Yes	★	-	Damp	White, Omnidirectional	
		13791	LED11DAV3/827W	120	6	4.6	800	2700	80	60W	15,000	Yes	-	-	Damp	White, Semi-Omni	
		95927	LED11DAV3/5K	120	6	4.4	800	5000	80	60W	15,000	Yes	-	-	Damp	White, Semi-Omni	
<b>A-Line Reveal</b>																	
	MED	8	69220	LED8DA19RVL/TP	120	3	4.4	430	2700	90	40W	25,000	Yes	-	-	Damp	White, Semi-Omni
		11	69204	LED11DA19RVL/TP	120	3	4.4	680	2700	90	60W	15,000	Yes	-	-	Damp	White, Semi-Omni
<b>A-21</b>																	
	MED	13	14075	LED13DA21/827	120	6	5.3	1100	2700	80	75W	25,000	Yes	★	-	Damp	White, Omnidirectional
		14	94936	LED14DA21/827W	120	6	5.3	1100	2700	80	75W	15,000	Yes	-	-	Damp	White, Semi-Omni
		16	14074	LED16DA21/827	120	6	5.3	1600	2700	80	100W	25,000	Yes	★	-	Damp	White, Omnidirectional
		34236	LED16DA21/830	120	6	5.3	1600	3000	80	100W	25,000	Yes	★	-	Damp	White, Omnidirectional	
		17	16113	LED17DA21/827	120	6	5.3	1600	2700	78	100W	15,000	Yes	-	-	Damp	White, Semi-Omni
<b>Locking Device</b>																	
			62182	LED A19 LOCK DEV <sup>2</sup>													White, Kit

For additional product and application information, please consult GE's website: [gelighting.com/ThinkLED](http://gelighting.com/ThinkLED)

## CHROMATICITY DIAGRAM

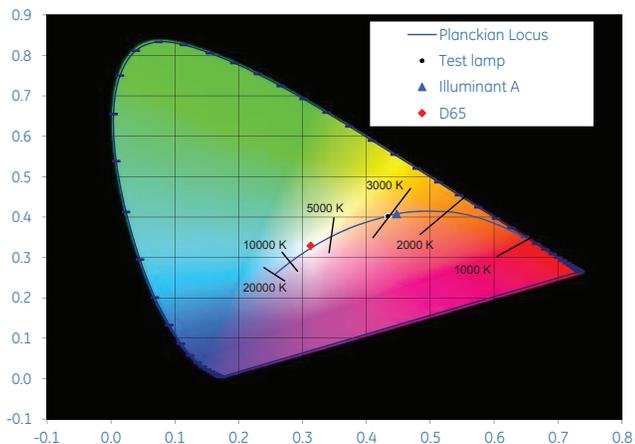

## SPECTRAL POWER DISTRIBUTION

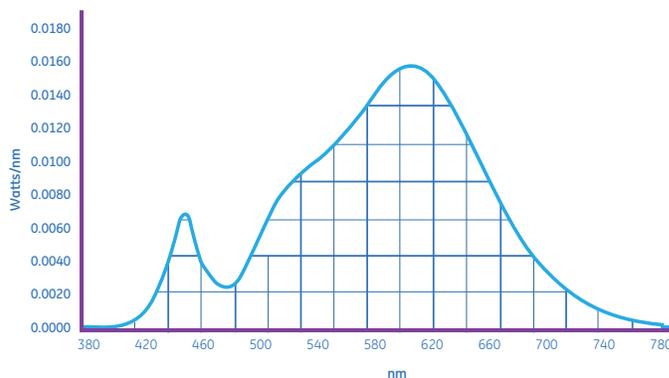

For additional product and application information, visit [www.gelighting.com/ThinkLED](http://www.gelighting.com/ThinkLED)



ecomagination<sup>SM</sup>

Product is compliant with material restriction requirements of RoHS

ENERGY STAR<sup>®</sup> and the ENERGY STAR<sup>®</sup> logo are registered U.S. marks



[www.gelighting.com](http://www.gelighting.com)

GE and the GE Monogram are trademarks of the General Electric Company. All other trademarks are the property of their respective owners. Information provided is subject to change without notice. All values are design or typical values when measured under laboratory conditions. GE Lighting and GE Lighting Solutions, LLC are businesses of the General Electric Company. © 2015 GE.

69170 (Rev 3/24/15)