

## Speaker: Portable Multi-Conductor



### Features & Benefits

- Easy-to-Handle Round Construction
- Low Loss
- Extra Flexible
- Heavy-Gauge Conductors
- All-Weather TPE Master Jacket

### Applications

- Speaker-to-Amplifier Interconnect
- Portable Speaker Cables
- Ideal for Use with Neutrik® speakON® Connectors


In a flexible and portable round construction, the Gepco® Brand multi-conductor, low-loss speaker cable features densely stranded 13 AWG conductors that achieve low series resistance and excellent flex-life. Multiple conductors allow for bi-amping or multiple speaker cabinets to be interconnected by one cable. Durable and flexible in low temperatures, the all-weather TPE jacket makes this series well suited for sound reinforcement applications or use in hostile environments. This series is ideal for termination with Neutrik® speakON® type connectors.

Mechanical Specifications (Series)				
Conductors	Insulation	Jacket (Type, Colors)		
13 AWG (52x30) Stranded BC	PVC, 0.024" (0.610 mm)	TPE, Black		
Mechanical Specifications (Individual)				
Part #	# of Cond.	Nominal OD	Conductor Color Code	Approx. Weight
GSC132	2	0.350" (8.89 mm)	White & Black	85 lbs/Mft (127 kg/km)
GSC134	4	0.420" (10.67 mm)	White, Black, Green, Red	130 lbs/Mft (194 kg/km)
GSC138	8	0.580" (14.73 mm)	White, Black, Green, Red, Brown, Blue, Orange, Yellow	259 lbs/Mft (386 kg/km)
Electrical Specifications				
<b>Cond. DCR</b>				
2.2 Ω/Mft				

### 1/4" Speaker



### SpeakON® Speaker

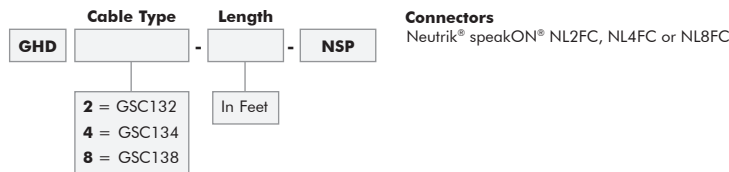

Neutrik and speakON are registered trademarks of Neutrik AG. Switchcraft is a registered trademark of Switchcraft, Inc.