

COMMERCIAL ANCHOR POINTS

Part#	Description	Weight
00250	Standing Seam Roof Clamp	33.50
00255	Screw-Down Metal Roof Anchor	14.75
10600	Two-Way Universal Standing Seam Clamp	5.00
10975	Retractable Swivel Adaptor	2.00



10975



00255

Screw-Down Metal Roof Anchor (00255) ↘

- Designed for use with retractable lifelines*
- 10" x 12" base plate with 7½" post
- Reusable, temporary anchor point
- Mounts to flat wood or metal roofs
- Allows retractable to rotate 360° degrees
- Fits most retractable lifelines up to 50'
- Wood/Metal fasteners provided
- If using 50' or 65' SRL, must be used with the Retractable Swivel Adaptor (10975)

Two-Way Universal Standing Seam Clamp (10600) ↘


- Lightweight, reusable, easy to use
- Durable, all steel construction with zinc electroplate finish
- Unique, reversible design allows for seams up to 1" wide
- MR-24, VSR or similar profiles can be covered with one clamp



10600

Standing Seam Roof Clamp (00250) ↘

- Designed for use with retractable lifelines*
- Reusable temporary anchor point
- Pinch mounts to standing seams
- Legs adjust 24"– 36" to fit seam spacing
- Fits most retractable lifelines up to 50'
- Allows retractable to rotate 360° degrees

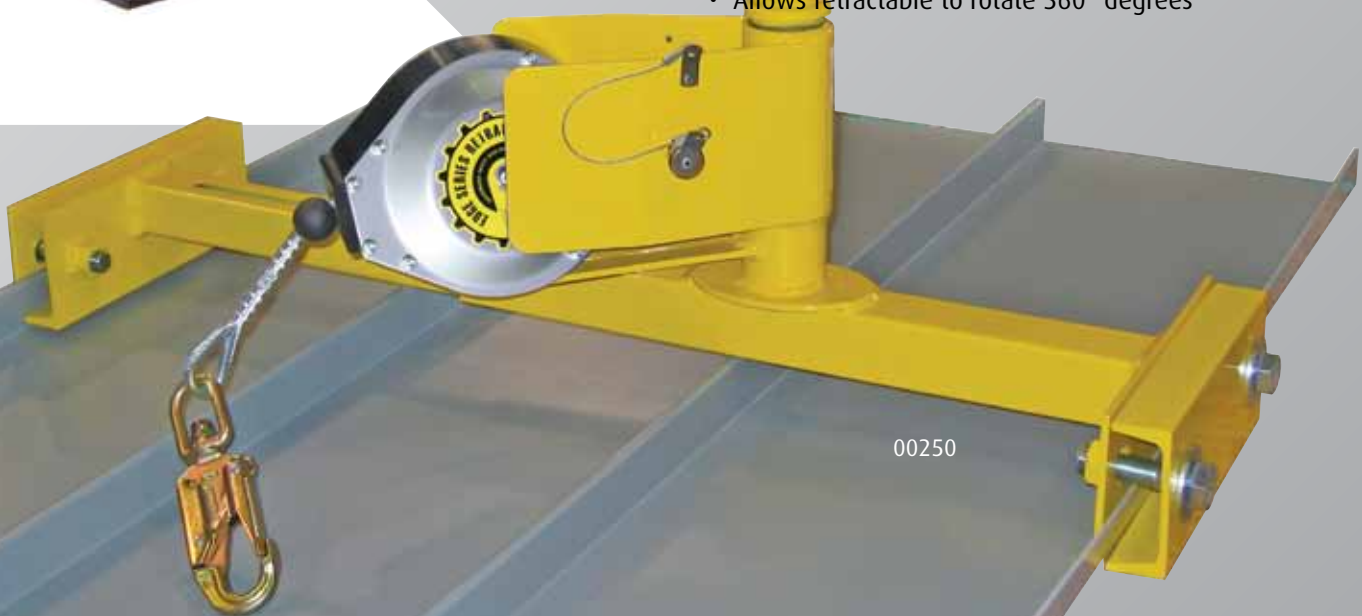

00250