

- Compact size measuring only 6.7" x 9.6" x 4.5"
- Wide flood NEMA 6 x 6 distribution for general purpose flood and facade lighting
- Traditional 1/2" x 14 NPS threaded adjustable knuckle mounting
- 120-277V operation (PC version 120V only)
- Rugged die-cast aluminum housing with dark bronze finish
- DesignLights Consortium (DLC) qualified
- High impact UV stabilized acrylic outer lens protects LEDs and allows for cleaning and debris removal
- IP65, listed to UL1598 for use in wet locations
- Four color multi-language merchandising carton with application details
- Visor and vandal shield available
- Vented housing isolates LED module from driver maximizing product life and performance



### ORDERING INFORMATION

Catalog Number	Mount	Beam Pattern	Wattage	Drive Current	Voltage	Color Temperature	Lumens	LPW	Weight lbs. (kg)
<b>FML-14</b>	1/2" thread	Wide	53	1050mA	120-277V	5100K	4285	81	8.5 (3.8)
<b>FML-14-PC1</b>	1/2" thread	Wide	53	1050mA	120V	5100K	4285	81	8.5 (3.8)

### PERFORMANCE INFORMATION


Series Number	Equivalency			Delivered Lumens	System Watts	Lumens Per Watt	Max Candle Power	Beam Pattern	CCT	Voltage	Drivers/Current
	MH	HPS	CFL								
<b>FML-14</b>	150w	150w	2x42w	4285	53	81	2805	Wide	5100K	120-277V	1@1050mA
<b>FML-14-PC1</b>											

### ACCESSORIES/REPLACEMENT PARTS - Order Separately

Catalog Number	Description
<b>FML-SPC</b>	Polycarbonate shield/lens (Replaces existing acrylic lens)
<b>FML-VISOR-XX<sup>1</sup></b>	Top/Bottom visor (Tap holes in lens frame to field install)
<b>93047961AC</b>	Acrylic lens w/ gasket
<b>93047971</b>	50w, 120-277V Dimming driver, 1040mA
<b>20750110264</b>	Knuckle mount Dark Bronze finish; Contact factory for additional finishes
<b>S-302</b>	Slipfits 1 1/2" or 2" pipe (1.9" OD or 2 3/8" OD) with 1/2" N.P.S.M. hub; Gray
<b>S-302-M51</b>	Slipfits 1 1/2" or 2" pipe (1.9" OD or 2 3/8" OD) with 1/2" N.P.S.M. hub; Bronze
<b>S-302-M52</b>	Slipfits 1 1/2" or 2" pipe (1.9" OD or 2 3/8" OD) with 1/2" N.P.S.M. hub; White

<sup>1</sup> Specify finish color to match fixture, e.g. DB - Bronze.

### DIMENSIONS

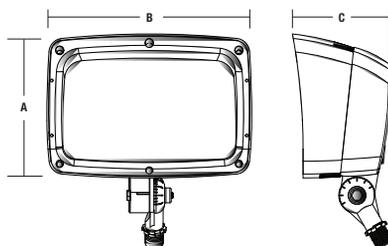

A	B	C
6.7"	9.6"	4.5"
169 mm	244 mm	115 mm

