


NRG® 300B

Perimeter Wallpack

- Full polycarbonate front provides vandal resistance and efficient spread; Lateral coverage on HID units is 5 times the typical mounting height up to 10 feet; Internally painted bronze finish for lasting appearance; Fluorescent photocontrol version available in white
- New 12LED unit provides long-life with low energy consumption, a perfect upgrade for older units
- Motion controlled unit has 180° detection range – saves energy by providing illumination only when needed
- Lamp included
- Rugged cast aluminum back housing for rigid mounting; Bottom 1/2" conduit knockout for surface conduit wiring (except on 'MS' unit); Back hub allows access to recessed wiring boxes; Two point mounting
- Units available with or without 120V button photocontrol, see ordering information
- Listed to UL 1598 for use in wet locations
- Tamper resistant center pin Torx hardware included

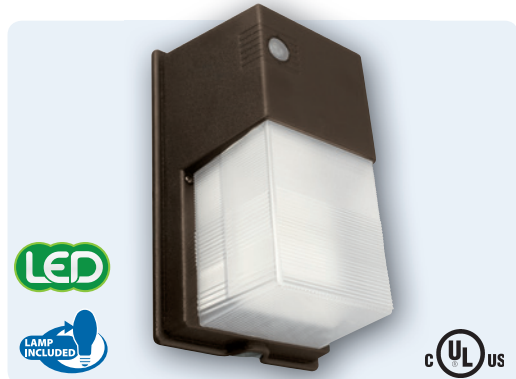

WALLPACKS

ORDERING INFORMATION

Catalog Number ¹		Wattage	Voltage	Color	Weight lbs. (kg)
Without Photocontrol	With Photocontrol				
High Pressure Sodium					
NRG-301B	NRG-301B-PC^{2,3}	50w	120V	Bronze	5 (2.3)
NRG-307B	NRG-307B-PC^{2,3}	70w	120V	Bronze	5 (2.3)
Pulse Start Metal Halide					
NRG-350B	NRG-350B-PC^{2,3}	50w	120V	Bronze	6.5 (2.9)
Electronic Fluorescent⁴					
–	NRG-306B-PCW²	26w	120-277V (-PC120)	White	4.2 (1.9)
NRG-306B	NRG-306B-PC²	26w	120-277V (-PC120)	Bronze	4.2 (1.9)
–	NRG-304B-PCW²	42w	120-277V (-PC120)	White	4.2 (1.9)
NRG-304B	NRG-304B-PC²	42w	120-277V (-PC120)	Bronze	4.2 (1.9)
Motion Controlled Electronic Fluorescent⁴					
–	NRG-304B-MS⁵	42w	120V	Bronze	6 (2.7)
12 LED – 1204 Lumens – 5000K – 73 CRI - 50Hz					
NRG-312LU-5K-BZ⁶	NRG-312LU-5K-BZ-PC^{2,6}	19w	120-277V (-PC120)	Bronze	6 (2.7)

- 1 Lamp included
- 2 120V only when ordered with photocontrol
- 3 120V NPF ballast for HID
- 4 CFL lamps are 4-Pin, 3500K, GX24q-4
- 5 Motion sensor has 180° detection range, adjustable time-on and sensitivity settings
- 6 LED units feature five year limited warranty

ACCESSORIES - Order Separately


Catalog Number	Description
PBT-1	Button photocontrol, 120V
PBT-234	Button photocontrol, 208, 240, 277V

REPLACEMENT PART

Catalog Number	Description
SM352-COVER	Polycarbonate front cover, Bronze



NRG-304B-MS

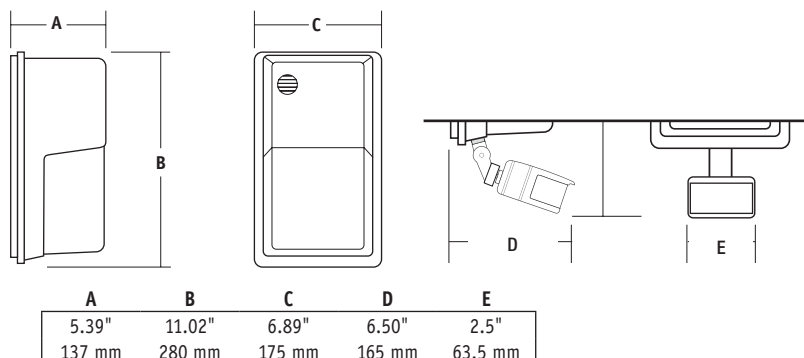

Ridgeline Battery Fixture for 42w CFL egress unit with battery back-up (See Dual-Lite page 945)