



Outdoor Lighting

LED NRG-312LU Perimeter Wallpack

Energy Efficient 19w LED Perimeter Wallpack

Hubbell Outdoor Lighting's new LED addition to the NRG family features a polycarbonate refractor wallpack that delivers 1204 lumens with 5000K CCT and provides ambient lighting for safety and security to any facility. The vandal resistant design makes it perfect for non-supervised applications where energy savings, low maintenance and rugged construction are desired. Also available with a factory installed 120V photocontrol option.



FEATURES & BENEFITS

- Higher output plus increased lumens per watt!
- 3X the mounting height lateral spacing
- 19w – 1204 lumens - 63 LPW, saves energy!
- 5000K high CRI LEDs provide optimal color recognition
- Five times the rated life of CFL
- Universal voltage – 120-277V
(120V on photo-controlled version)
- Non-cutoff refractor fills surrounding area with safety/security illumination
- 1/2" bottom knockout for surface conduit wiring
- Vandal proof construction
 - Rigid cast aluminum back housing
 - One-piece polycarbonate front
 - Tamper proof hardware included
- Dark Bronze architectural finish
- Listed to UL1598 for use in wet locations
- Five year limited warranty




Due to our continued efforts to improve our products, product specifications are subject to change without notice.

ORDERING INFORMATION



CATALOG NUMBER	WATTAGE	VOLTAGE ¹	LUMENS	REPORTED LUMEN MAINTENANCE ²	CCT	WEIGHT LBS. (KG)
NRG-312LU-5K-BZ¹	19w	120-277V	1204	L94(10k) > 60,500hrs	5000K	6.0 (2.7)
NRG-312LU-5K-BZ-PC	19w	120V	1204	L94(10k) > 60,500hrs	5000K	6.0 (2.7)

- 1 LED units feature five year limited warranty
- 2 Lumen maintenance performance references IESNA LM-80 data based on 10,000 hrs testing and projected per IESNA TM-21-11

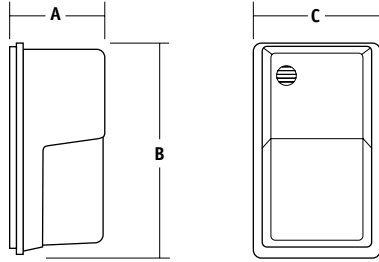

A	B	C
5.39"	11.02"	6.89"
137 mm	280 mm	175 mm

Due to our continued efforts to improve our products, product specifications are subject to change without notice.