


HVL643XX

Guest chair with sled base,
Loop arms

CHAIR SPECIFICATIONS

Max. Width..... 24-1/2
 Max. Depth..... 28-1/4
 Max. Height..... 34-1/2
 Seat Size
 Width..... 19
 Usable Depth..... 19-1/2
 Height from Floor.... 19-1/2
 Back Size
 Width..... 21-1/4
 Height from Seat..... 18
 Arm Size
 Width..... 3
 Distance Between
 Arms..... 18-1/2
 Height from Seat..... 7

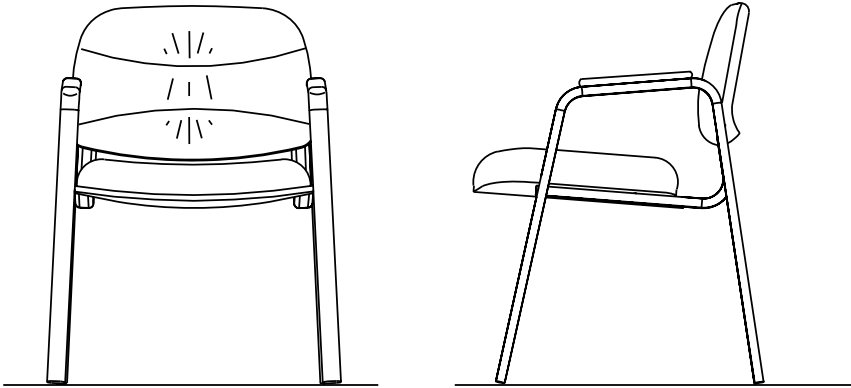

CONSTRUCTION

Base..... Black oval tube sled base, 13 ga. 1-5/8" wide by 13/16" high.
 Seat..... Upholstered in black leather, 5 ply, 1/2 thick plywood, 3-1/2 thick foam, seat deflects 1/4" when 50 lbs applied.
 Back..... Upholstered in black leather, 5 ply, 1/2 thick plywood, 3-1/2 thick foam.
 Arm..... Urethane arm pad durometer reading 35 shore A.
 Chair Weight..... 28 pounds.
 Shipping Weight..... 36 pounds.
 Shipped..... Assembly required..
 Shipping Size..... 22-5/8" wide x 27" deep x 12-13/16" high (4.5 cubic feet) UPSable.
 Flammability Rating..... Furnished upon request by THE HON Company Customer Service.
 Note..... All measurements are per ANSI/BIFMA procedures.

| | |
|--------------|-------------|
| Issue Date: | 21-SEP-2010 |
| Part Number: | 53-9285 |

