

# Miniliter® V MHS

## Compact Wide Beam Floodlight

- Sign, facade, area, accent and general security lighting
- Die-cast housing and door, rugged but lightweight
- Tempered glass lens
- Tool-free entry for lamping or maintenance, silicone gasket provides seal
- Steel yoke (MHS-Y) or cast aluminum 2 3/8" knuckle slipfitter (MHS-K) mounting
- Lamp included
- HPF ballastry in Quad-Tap®, and 480V
- Wide, uniform beam for illumination of signs, facades and large areas; coverage is four times set back distance; lamp included
- UST fixtures are built in Christiansburg, VA and meet ARRA level 2 requirements
- Available in dark bronze powder paint finish
- Listed to UL1598 for use in wet locations, CSA 22.2 No. 250.0-00, suitable for wet locations
- U.S. Patent No. 6,461,026



MHS-Y (Yoke Mount)  
LAMP INCLUDED  
UL LISTED  
CSA LISTED

FLOODLIGHTING

### ORDERING INFORMATION – STOCK

Catalog Number	Lamp Type/Wattage <sup>1</sup>	Voltage	Weight lbs. (kg)
<b>Pulse Start Metal Halide Yoke Mount</b>			
MHS-Y400P8	400W PS ED37	Quad-Tap® (120, 208, 240, 277V)	26 (11.8)
MHS-Y400P5	400W PS ED37	480V	26 (11.8)
MHS-Y250P8	250W PS ED28	Quad-Tap® (120, 208, 240, 277V)	22 (10.0)
MHS-Y150P8	150W MH ED28	Quad-Tap® (120, 208, 240, 277V)	21 (9.5)
<b>Pulse Start Metal Halide Knuckle Mount</b>			
MHS-K400P8	400W PS ED37	Quad-Tap® (120, 208, 240, 277V)	31 (14.1)
MHS-K250P8	250W PS ED28	Quad-Tap® (120, 208, 240, 277V)	27 (12.2)
<b>High Pressure Sodium Yoke Mount</b>			
MHS-Y400S8	400W HPS E18	Quad-Tap® (120, 208, 240, 277V)	28 (12.7)
MHS-Y400S5	400W HPS E18	480V	28 (12.7)
MHS-Y250S8	250W HPS E18	Quad-Tap® (120, 208, 240, 277V)	24 (10.9)
MHS-Y150S8	150W HPS ED28	Quad-Tap® (120, 208, 240, 277V)	23 (10.4)


<sup>1</sup> All fixtures have dark bronze powder finish and are shipped with mogul base lamp; NOTE: EPA is 1.4 sq. ft.

### ACCESSORIES - Order Separately


Catalog Number	Description
PBT-1	Photocontrol, button type, 120V
PBT-234	Photocontrol, button type, 208, 240, 277V
MHS4-SPC	Polycarbonate shield (for independent use only)
MHS4-G	Wire guard, 2" square grid (for independent use only)
4024C	Steel slipfitter for 2" pipe, 2 3/8" OD yoke mount, bronze finish
MHS4-GS	Glare shield, black finish (for independent use only)
MHS4-VGS	Vertical glare shield, black finish (for independent use only)
MHS4-HGS	Horizontal glare shield, black finish (for independent use only)
MHS-21	Two light bracket, bolt on yoke mount, slipfits 2 3/8" OD tenons, bronze finish
SSB-21-M51	Two light bracket, knuckle mount units, slipfits 2 3/8" OD tenons, bronze finish
TWK-11	Steel wall bracket with 2 3/8" tenon, bronze finish (use with MHS-K)

### ORDERING INFORMATION – UST

SERIES	MOUNTING	WATTAGE/SOURCE	VOLTS	FINISH	UST	OPTIONS
MHS Miniliter V Series	Y Yoke K Knuckle	<b>PULSE START METAL HALIDE</b> 150P 150w PSMH 250P 250w PSMH 320P 320w PSMH 400P 400w PSMH <b>HIGH PRESSURE SODIUM</b> 150S 150w HPS 250S 250w HPS 400S 400w HPS	5 480V 6 347V 8 Quad Tap® (120, 208, 240, 277V)	BZ Bronze BL Black WH White GR Gray PS Platinum CC Custom Color	UST U.S. transformed, ARRA level 2	QST Quartz standby Skt/Relay EM Quartz Skt C3 3ft. 16/3 SO C6 3ft. 16/3 SO PR(X) NEMA Photo cell receptacle (replace X with voltage: 1=120V, 2=208V, 3=240V, 4=277V, 5=480V, 6=347V) F(X) Fusing (replace X with voltage: 1-120V, 2-208V, 3-240V, 4-277V, 5-480V, 6-347V)

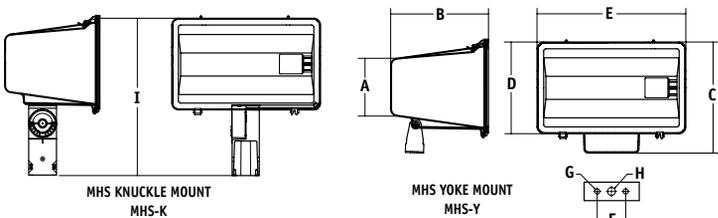

A	B	C	D	E	F	G	H	I
6 1/2"	14 1/2"	12"	9 7/8"	16 1/4"	3 1/8"	17/32"	7/8"	17"
165 mm	368 mm	305 mm	251 mm	413 mm	79 mm	14 mm	22 mm	432 mm

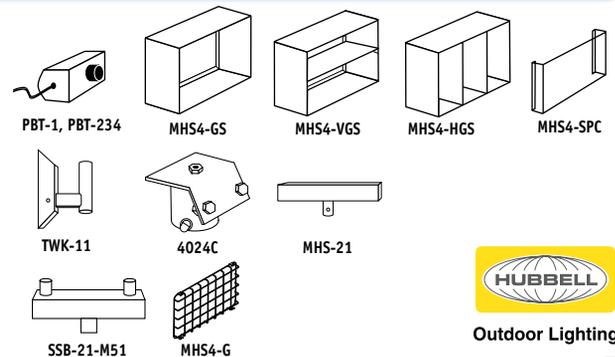

**HUBBELL**  
Outdoor Lighting