

Microliter® MIC

Medium Beam Compact Floodlight

FLOODLIGHTING



- Die-cast aluminum housing is light weight, yet rugged
- Cast door frame hinges and is removable for servicing, two screw closure
- Tempered, impact resistant glass lens, silicone gasket provides seal
- Large 1/2" universal aiming swivel knuckle (1/2 x 14 NPS)
- Rotatable optics for best beam utilization, medium base lamp included
- Medium and spot distributions available from 150w Pulse Start source; Standard medium distribution covers two times set back distance
- HPF Quad-Tap® and NPF 120V systems available, consult ordering information
- Bronze powder coat protective finish
- Lamp included
- Listed to UL1598 for use in wet locations

ORDERING INFORMATION

Catalog Number ¹	Wattage	Photometry NEMA/IES H° x V°	Lamp Type	Voltage	Weight lbs. (kg)	EPA ft² (m²)	Ballast Type ²
Normal Power Factor, High Pressure Sodium							
MIC-0070S-651	70	5 (90°) x 6 (102°)	Coated	120 NPF	9 (4.1)	0.71 (0.1)	RX
High Power Factor, High Pressure Sodium							
MIC-0150S-258 ³	150	5 (71°) x 3 (34°)	Clear	120/208/240/277	14 (6.4)	0.71 (0.1)	AL
High Power Factor, Pulse Start Metal Halide							
MIC-0070H-358 ³	70	5 (81°) x 4 (60°)	Clear	120/208/240/277	11 (5)	0.71 (0.1)	AL
MIC-0100H-358 ³	100	5 (86°) x 4 (62°)	Clear	120/208/240/277	13 (5.9)	0.71 (0.1)	AL
MIC-0150P-338 ³	150	3 (32°) x 3 (36°)	Clear	120/208/240/277	14 (6.4)	0.71 (0.1)	PLA
MIC-0150P-358 ³	150	6 (103°) x 5 (81°)	Clear	120/208/240/277	14 (6.4)	0.71 (0.1)	PLA
Less Ballast - Medium Base Socket							
MIC-XXXX-XXX	Less Ballast	Varies	150 max	None	6 (2.7)	0.71 (0.1)	None

- 1 Lamp included
 2 Ballasts are Class H, -40°F starting (HPS), -20°F starting (PSMH)
 3 Quad-Tap® luminaires are shipped wired for 277V, easily changed to other voltages in the field

 
ACCESSORIES - Order Separately

Catalog Number	Description
MIC-GS-2	Glare shield (360°) bronze
MIC-SPC-2	Polycarbonate shield assembly
S-302-M51	Pole-top slipfitter for 1/2" knuckle, slipfits 2 3/8" OD pipe, bronze finish
PBT-1	Photocontrol, button type, 120V
TRN-XX ¹	Trunnion adaptor for 1/2" threaded knuckle mount

- 1 Specify color, eg. DB - Dark Bronze

REPLACEMENT PARTS

Catalog Number	Description
264-0292-9903	Lens
800-2827-0100	Bronze lens/door assembly
207-5011-0264	Bronze knuckle




MIC-GS-2



MIC-SPC-2



 
S-302-M51



PBT-1



TRN-XX

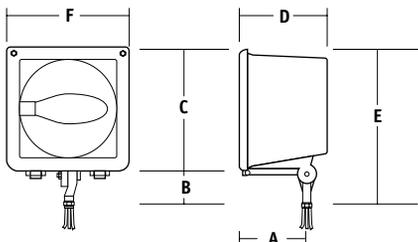

A	B	C	D	E	F
4 7/8"	2 1/2"	9 1/4"	7 3/8"	12 1/8"	9 1/4"
124 mm	64 mm	235 mm	187 mm	308 mm	235 mm