

# INCANDESCENT LAMPHOLDERS

103-7/308/309/306/103

Cat.#

Job

Type



**HUBBELL**  
Outdoor Lighting

Approvals

### APPLICATIONS

- Ideal for a wide variety of industrial and commercial applications as accent and general lighting

### SPECIFICATIONS 308/309

- Die cast bullet series 175 watt maximum
- Open 308 Series is used indoors or aimed down outdoors. Provides shielding of PAR 38 lamps
- 309 Series has extension ring and weathertight lens. Improves shielding and allows universal aiming in wet locations
- 15 watt 120-277V LED unit available saves energy and maintenance - Bronze finish 50,000 hour typical life. 3,500K/253 lumens



- Multiple powder paint finishes

### SPECIFICATIONS 306

- Cast aluminum housing with decorative "visor" styling. Designed for maximum heat dissipation for long lamp life
- Lens is thermal shock and impact resistant and mounted to cast door for easy service
- High temperature silicone gaskets seal housing and cushion lamp for all-weather protection
- Universal adjustable 1/2" NSPM threaded mounting arm with lock nut. Relamp without disturbing original aiming. Floating-end prong porcelain socket
- Factory wired for fast, easy installation
- Gray powder paint finish

### LISTINGS

- Listed to UL1598 for use in wet locations

### SPECIFICATIONS 103-7





- Cast aluminum lamp housing with 1/2" NSPM male swivel mounting arm. For all-weather protection
- Universal aiming with PAR 38 lamps
- Factory wired for fast, easy installation
- Gray, green and black powder paint finishes

### LISTINGS

- Listed to UL1598 for use in wet locations

### SPECIFICATIONS 103

- Industrial grade with silicone "O" ring gasket for 150 watt maximum PAR or R lamps
- Large 1/2" knuckle provides firm mounting
- Natural aluminum finish

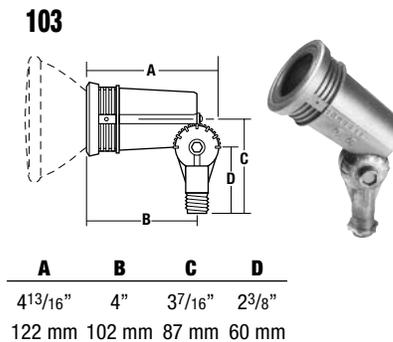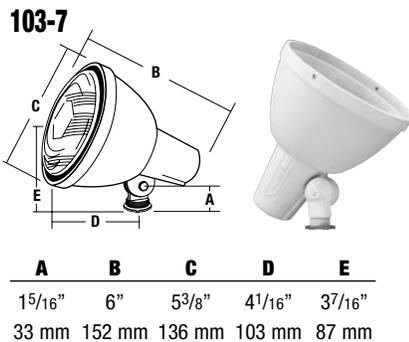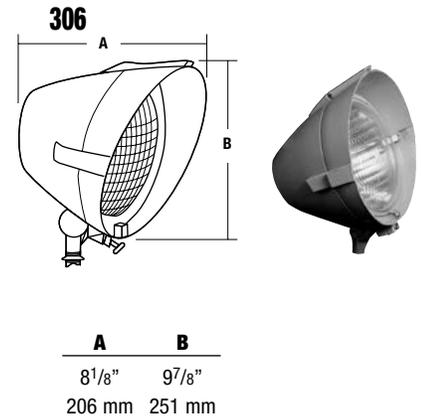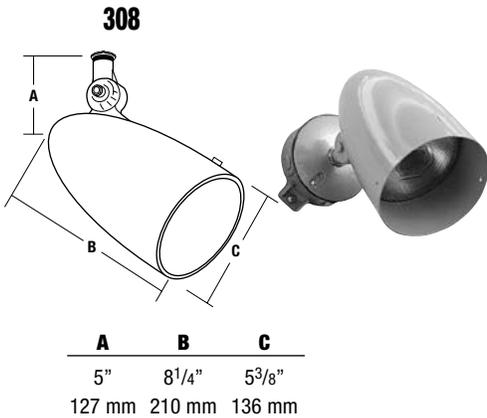

## ORDERING INFORMATION

see back



**HUBBELL**  
Outdoor Lighting

Hubbell Outdoor Lighting • 701 Millennium Boulevard • Greenville, SC 29607 • Phone: 864-678-1000

Due to our continued efforts to improve our products, product specifications are subject to change without notice.

© 2015 HUBBELL OUTDOOR LIGHTING, All Rights Reserved • For more information visit our website: [www.hubbelloutdoor.com](http://www.hubbelloutdoor.com) • Printed in USA

LAMP HOLDERS-SPEC 6/15

## ORDERING INFORMATION

103

| Catalog Number | Description           | Gasket   | Finish           | Weight lbs. (kg) |
|----------------|-----------------------|----------|------------------|------------------|
| 103            | Unshielded, full size | Silicone | Natural Aluminum | .75 (.3)         |

### 103-7 Series

| Catalog Number | Description          | Gasket   | Finish | Weight lbs. (kg) |
|----------------|----------------------|----------|--------|------------------|
| 103-7          | Shielded, bell shape | Silicone | Gray   | 1.25 (0.6)       |
| 103-71         | Shielded, bell shape | Silicone | Bronze | 1.25 (0.6)       |
| 103-72         | Shielded, bell shape | Silicone | Black  | 1.25 (0.6)       |
| 103-73         | Shielded, bell shape | Silicone | Green  | 1.25 (0.6)       |
| 103-74         | Shielded, bell shape | Silicone | White  | 1.25 (0.6)       |

306

| Catalog Number | Description  | Finish | Weight lbs. (kg) |
|----------------|--|--------|------------------|
| 306            | 1/2" Swivel knuckle mount, 12" leads, hinged door and lens | Gray   | 3.375 (1.7)      |

### 306 REPLACEMENT PARTS

| Catalog Number | Description    |
|----------------|----------------|
| 1306C          | Lens & Gasket  |
| 207-5011-0264  | Bronze knuckle |

Note PAR 56 lampholders for 300w (maximum) incandescent or 500w quartz; Lamp not included

### ACCESSORIES - Order Separately

| Catalog Number | Description   |
|----------------|---|
| S-307          | Wire guard for PAR and R lamps, for use with 103 fixture    |
| 1324           | Wire guard for PAR lamps, for use with 103-7 Series         |
| 1308           | Plated wire guard for 306 (0.2lbs (.09kg))                  |
| 1031-3         | Ground spike with splice box and 6' cord set - 1/2" top hub |
| S329B          | 4" Round wet location outlet box with cover - 1/2" hubs     |



1324



1031-3

## ORDERING INFORMATION

306

| Catalog Number  | Description | Finish       | Weight lbs. (kg) |
|---|-------------|--------------|------------------|
| <b>Damp Location Listed - Aim Down Outdoors<sup>1</sup></b> |             |              |                  |
| <b>308-M</b>  | 8 1/4" long | Gray         | 2.25 (1)         |
| <b>308-13-M</b>   | 8 1/4" long | Garden Green | 2.25 (1)         |
| <b>308-14-M</b>   | 8 1/4" long | Matte Black  | 2.25 (1)         |
| <b>Wet Location Listed - Universal Aiming<sup>2</sup></b>   |             |              |                  |
| <b>309-ML</b>   | 9 7/8" long | Gray         | 3 (1.4)          |
| <b>309-13-ML</b>  | 9 7/8" long | Garden Green | 3 (1.4)          |
| <b>309-14-ML</b>  | 9 7/8" long | Matte Black  | 3 (1.4)          |
| <b>309-VG-ML</b>  | 9 7/8" long | Verdi        | 3 (1.4)          |
| <b>309-M51-ML</b>   | 9 7/8" long | Dark Bronze  | 3 (1.4)          |
| <b>309-M54-ML</b>   | 9 7/8" long | White        | 3 (1.4)          |
| <b>LED - Wet Location Listed - Universal Aiming - 15w</b>   |             |              |                  |
| <b>30910LEDML</b>   | 9 7/8" long | Bronze       | 5 (2.2)          |

1 Use medium base PAR 38 lamps or smaller, 150w maximum

2 Use PAR 38 or BR40 lamps, 150w maximum

### ACCESSORIES - Order Separately

| Catalog Number            | Description  | Weight lbs. (kg) |
|---------------------------|--|------------------|
| <b>264 0097 9702</b>      | Clear lens   | .5 (0.2)         |
| <b>1324</b>               | Zinc-plated wire guard   | .25 (0.1)        |
| <b>309-S</b>              | Shield, 7" X 45°, black  | 1.7 (0.8)        |
| <b>C-5</b>                | Wall or tree box, 3 mounting lugs in body; 2 1/2" hubs in "L" shape layout, side access plate  | .25 (.11)        |
| <b>S-329-B</b>            | Cast round box, 4", 6-sided 1/2" back hub (wall or ceiling)  | .75 (.3)         |
| <b>NM-BC</b>              | Non-metallic high impact phenolic weatherproof box & cover, box is drilled at 180° for two burial cable connectors (included), allowing feed-through capability; gasketed cover has weathertight 1/2" hub; brass cover with screws; gray |                  |
| <b>1414-BOX</b>           | Cast iron box - two side hubs, one top (1/2"); heavy-duty; gray  | .8 (.4)          |
| <b>1031-3</b>             | Cast spike with internal splice box, 1/2" NPSM hub for fixture & 6' #18/3 grounded cord set; gray  | 1.75 (.8)        |
| <b>TRN-XX<sup>1</sup></b> | Trunnion adaptor for 1/2" threaded knuckle mount   | .5 (.23)         |

1 Specify finish, e.g. Dark Bronze - DB



1324



309-S



1031-3



NM-BC



TRN-XX



**HUBBELL**  
Outdoor Lighting

Hubbell Outdoor Lighting • 701 Millennium Boulevard • Greenville, SC 29607 • Phone: 864-678-1000

Due to our continued efforts to improve our products, product specifications are subject to change without notice.

© 2015 HUBBELL OUTDOOR LIGHTING, All Rights Reserved • For more information visit our website: [www.hubbelloutdoor.com](http://www.hubbelloutdoor.com) • Printed in USA

LANPHOLDERS-SPEC 6/15