

308/309 Series

Bullet Lampholders

LANDSCAPE



- PAR/BR Lampholders, 150w max.
- Energy-saving 10 LED/15w, nominal 315 lumens, 3500K
- Decorative finishes vary
- Die-cast aluminum housing (and doors)
- Tempered glass lens
- Large 1/2" swivel knuckle, 308 down aim outdoors, 309 is universal aim
- Medium base porcelain socket (150w max) for PAR/BR models
- Available in Gray, Black, Green, Bronze, White and Verdi finishes; See ordering information
- CSA certified to UL 1598, CSA 22.2 No. 250.0-00, Suitable for wet locations
- Deep shield, louver, wire guard accessories vary

ORDERING INFORMATION

Catalog Number	Description	Finish	Weight lbs. (kg)
Damp Location Listed - Aim Down Outdoors¹			
308-13-M	8 1/4" long	Garden Green	2.25 (1)
Wet Location Listed - Universal Aiming²			
309-ML	9 7/8" long	Gray	3 (1.4)
309-13-ML	9 7/8" long	Garden Green	3 (1.4)
309-14-ML	9 7/8" long	Matte Black	3 (1.4)
309-VG-ML	9 7/8" long	Verdi	3 (1.4)
309-M51-ML	9 7/8" long	Dark Bronze	3 (1.4)
309-M54-ML	9 7/8" long	White	3 (1.4)
LED - Wet Location Listed - Universal Aiming - 15w			
30910LEDML	9 7/8" long	Bronze	5 (2.2)


1 Use medium base PAR 38 lamps or smaller, 150w maximum

2 Use PAR 38 or BR40 lamps, 150w maximum


ACCESSORIES - Order Separately

Catalog Number	Description	Weight lbs. (kg)
264 0097 9702	Clear lens	.5 (0.2)
1324	Zinc-plated wire guard	.25 (0.1)
309-S	Shield, 7" X 45°, black	1.7 (0.8)
C-5	Wall or tree box, 3 mounting lugs in body; 2 1/2" hubs in "L" shape layout, side access plate	.25 (.11)
S-329-B	Cast round box, 4", 6-sided 1/2" back hub (wall or ceiling)	.75 (.3)
NM-BC	Non-metallic high impact phenolic weatherproof box & cover, box is drilled at 180° for two burial cable connectors (included), allowing feed-through capability; gasketed cover has weathertight 1/2" hub; brass cover with screws; gray	
1414-BOX	Cast iron box - two side hubs, one top (1/2"); heavy-duty; gray	.8 (.4)
1031-3	Cast spike with internal splice box, 1/2" NPSM hub for fixture & 6' #18/3 grounded cord set; gray	1.75 (.8)
TRN-XX ¹	Trunnion adaptor for 1/2" threaded knuckle mount	.5 (.23)

1 Specify finish, e.g. Dark Bronze - DB

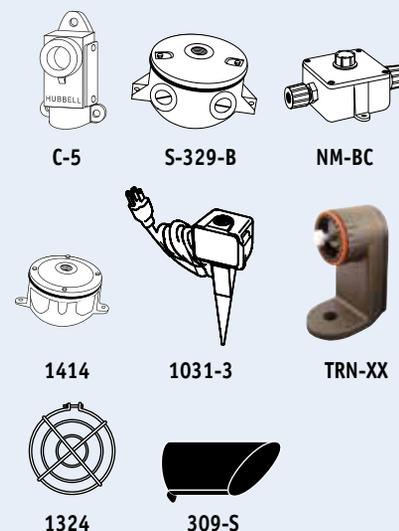


308 Series

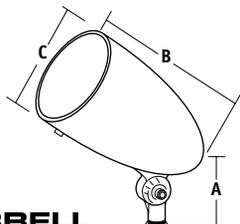

A	B	C
5"	8 1/4"	5 3/8"
127 mm	210 mm	137 mm

309 Series

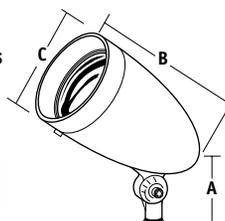

A	B	C
5"	9 7/8"	5 3/8"
127 mm	251 mm	137 mm



HUBBELL
Outdoor Lighting