

Architectural LED Floodlight/Wall Mount



- ALF is excellent for small floodlighting applications such as signs, façade, landscape accent or small area illumination
- The compact, low profile size allows the flood to be easily hidden or blend into the landscape environment
- Knuckle mount: Universal 1/2" swivel knuckle has serrated teeth for sure aiming
- Wall mount: Cast aluminum cover/quick mount plate and universal adapter allows easy installation to 3 1/2" or 4" standard junction boxes; Tilt for increased forward throw
- Universal voltage driver is 120-277V, 50/60Hz, with 11 or 22 input watts
- Impact resistant tempered glass lens seals to housing with silicone gaskets
- Dark bronze durable powder paint finish
- Six or twelve LEDs produce 905 or 1913 lumens at 5100K
- Wide 6x5 NEMA beam spread covers three times the set back distance with uniform light
- Listed to UL 1598 for use in wet locations
ALF-6: IP65, ALF12: IP64w

ORDERING INFORMATION

Catalog Number	Wattage	Number of LEDs	Voltage ¹	Lumens	TM-21-11 L70	Kelvin	Weight lbs. (kg)
1/2" Knuckle Mount							
ALF-6LU-5K-BZ	10.1w	6	120-277V	905	60,000hrs	5000K	4.0 (1.8)
ALF-12LU-5K-BZ	21.4w	12	120-277V	1913	60,000hrs	5000K	8.0 (3.6)
Wall Mount							
ALFW-6LU-5K-BZ	10.7w	6	120-277V	510	60,000hrs	5000K	4.5 (2.0)
ALFW-6LU-5K-BZ-PC	10.7w	6	120V	510	60,000hrs	5000K	4.5 (2.0)

¹ Unit should not be used above 240V in Canada



PERFORMANCE INFORMATION – ALF 6 & 12 FLOODS

Series Number	Equivalency			Delivered Lumens	System Watts	Lumens Per Watt	Max Candle Power	Beam Pattern	CCT	Voltage	Drivers/Current
	MH	HPS	CFL								
 ALF-6LU	70w	70w	26w	905	10.1	90	667	6 X 5	5000K	120-277V	1@470mA
 ALF-12LU	100w	100w	42w	1913	21.4	89	1395	6 X 5	5000K	120-277V	2@470mA

PERFORMANCE INFORMATION – ALF 6 WALLMOUNT

Series Number	Equivalency			Delivered Lumens	System Watts	Lumens Per Watt	Mounting Height	CCT	Voltage	Drivers/Current
	MH	HPS	CFL							
 ALFW-6LU	70w	70w	26w	510	10.7	48	Up to 10 ft.	5000K	120-277V	1@470mA

DIMENSIONS

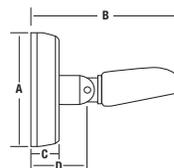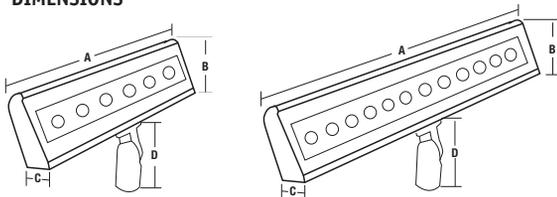

A	B	C	D
12/24"	3 1/2"	1 1/2"	3 1/2"
305/609.6 mm	89 mm	38 mm	89 mm

A	B	C	D
5 1/2"	6 1/2"	1 1/8"	2 1/8"
139 mm	165 mm	28 mm	54 mm