


H5905 ComforTask H5905FC Technical Specifications Task Stool, Pneumatic, Back Height, Swivel, Adjustable Height Footring

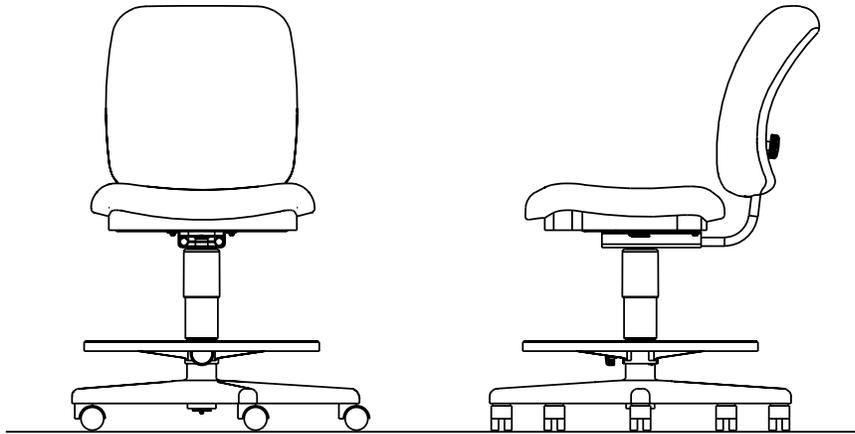

KEY DIMENSIONS

Max. Width.....	26-3/4"
Max. Depth.....	30"
Max. Height.....	49-3/4"
Seat Size	
Width.....	20"
Usable Depth.....	17"
Height from Floor.....	21-3/4" - 31-7/8"
Back Size	
Width.....	16-1/4"
Height from Seat.....	15-1/4" - 17-3/4"

Back Lumbar

Height..... 9-1/2" - 12"

Footring

Diameter..... 20"

Height from floor..... 7-1/8" - 12-3/4"

CONSTRUCTION

Caster..... Black hooded 2" diameter dual wheel.

Optional Caster... See Dealer Nrt Pricer

Base..... Black 5 legged plastic nylon base.

Control..... Black heavy gauge steel, 17-4 taper.

Seat..... Compound-curved shaped blow-molded plastic, 2" thick urethane foam cushion.

Back..... Compound-curved shaped blow-molded plastic, 1-1/2" thick urethane foam cushion.

Arm..... Optional: Model H5991 - See Model Spec No. 53-4368

H5995 - See Model Spec No. 53-4345

Upholstery..... See List Pricer. Customer own material (COM) required yardage per SKU = 1.0 yards.

Chair Weight..... 27 pounds.

Shipping Weight.. 34 pounds.

Shipped..... Two-piece assembly

Shipping Size..... 30.50" wide x 26.38" deep x 22.50" high (10.5 cubic feet)

Flammability..... Furnished upon request by The HON Company Customer Service. Model H5905 meets the

Rating State of California Department of Consumer Affairs Technical Bulletin 117 requirements.

Model H5905FC meets the State of California Department of Consumer Affairs Technical Bulletin 133 requirements.

Special Features... A pneumatic gas cylinder is used for height adjustment of chair.

Note..... All measurements are per BIFMA/CMD procedures.