


Technical Specifications

Task, Pneumatic,
Back Height,
Swivel, Multi-task

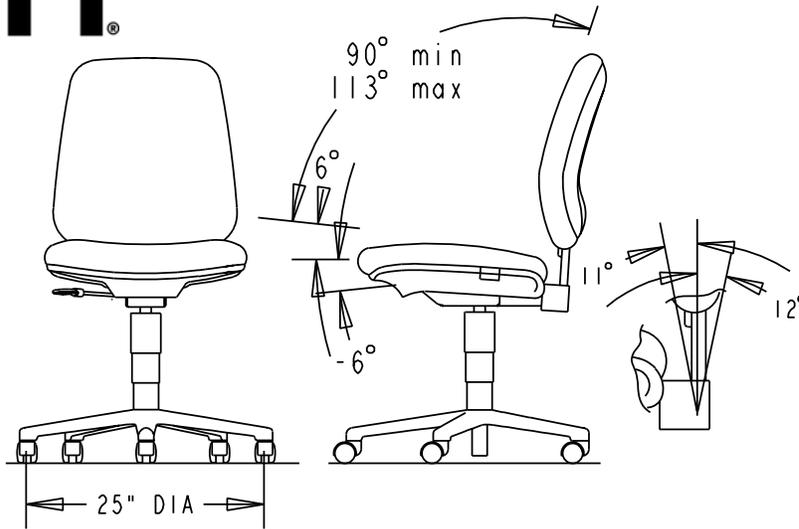

KEY DIMENSIONS

Max. Width.....	26"
Max. Depth.....	34"
Max. Height.....	42-1/2"
Seat Size	
Width.....	20"
Usable Depth.....	15" - 18"
Height from Floor.....	15-1/2" - 20-1/2"
Back Size	
Width.....	18"
Height from Seat.....	17-1/2" - 20"

Back Lumbar

Height.....	
Arm Size	
Distance between arms.....	
Height from floor.....	
Height from seat.....	
Width.....	
Length.....	
Arm Set-Back.....	

CONSTRUCTION

- Caster..... Monochromatic hooded 2" diameter dual wheel.
- Optional Caster... See Dealer Net Pricer
- Base..... Black 5 leg plastic nylon base.
- Control..... Black heavy gauge steel, multi-task allowing seat and back angle, positioning, 17-4 taper.
- Seat..... 5/8" thick 5-ply plywood, 3-1/2" thick molded urethane foam cushion.
- Back..... Compound-curved shaped blow-molded plastic, 1-1/2" thick urethane foam cushion.
- Arm..... Optional: Model: H7795 - See Model Spec No. 53-4343
HHW103 - See Model Spec No. 53-9199
- Upholstery..... See List Pricer. Customer own material (COM) required yardage per SKU = 1.0 yards.
- Chair Weight..... 32 pounds.
- Shipping Weight.. 40 pounds.
- Shipped..... Completely assembly
- Shipping Size..... 27.13" wide x 26.13" deep x 37.00" high (15.2 cubic feet)
- Flammability
- Rating..... Furnished upon request by The HON Company Customer Service. Model H7703 meets the State of California Department of Consumer Affairs Technical Bulletin 117 requirements.
- Special Features... A pneumatic gas cylinder is used for height adjustment of chair.
- Note..... All measurements are per BIFMA/CMD procedures.