

# LHQM

Quantum® Thermoplastic



**Intended Use**  
Suitable for applications requiring quick installation of both exit sign and unit equipment. Attractive 10" tall, streamlined design is great for above-the-door applications and other tight fits.

**Construction**  
Precision-molded thermo-plastic housing is impact-resistant, corrosion-proof and UV-stabilized to resist discoloration.

Quick-Mount® installation. Innovative, snap-together

design allows for installation in less than three minutes.

Factory assembled and prewired.

Replaceable chevron directional indicator knockouts for choice of direction.

Side-mount lamp heads reduce overall height, allowing for easy fit over doorways.

Long-life LEDs feature very low energy consumption and rated life up to 10 years.

Dual-voltage input standard (120/277V).

Sealed, maintenance-free, lead-calcium battery standard. Nickel-cadmium battery optional.

Two 5.4W wedge-based krypton lamps offer 32% more light output than standard incandescent lamps.

Patented MR24, multifaceted reflector significantly improves photometric performance; 60-100% more light delivered to the path of egress.

Universal (top, end or back) mounting with canopy included.

Optional high-output battery (HO) to power a remote head or exit.

U.S. Patent No. 5, 611, 163; 5, 646, 502; 5, 526, 251; 5, 797, 673 and D379, 373. Other patents pending.

**Listings**

UL Listed. Meets UL924. UL damp location listed (50° to 104°F (10° to 40°C) standard. NOM Certified (see Options).



ORDERING INFORMATION

For shortest lead times, configure products using **bolded options**.

Example: LHQM S W 3 R

Series	Face type	Housing	Number of faces	Letter color	Options
LHQM LED exit/unit	<b>S</b> Stencil	(blank) Black <b>W</b> White	<b>3</b> Single with extra faceplate and color panel for field conversion to double-face	<b>R</b> Red <b>G</b> Green	<b>N</b> Nickel-cadmium battery <sup>1</sup> <b>HO</b> High-output lead-calcium battery <b>HO RO</b> High-output lead-calcium battery, less lamp heads <b>NOM</b> Meets Mexican standards <sup>2</sup>

ADDITIONAL INFORMATION

For additional product information, visit [www.lithonia.com](http://www.lithonia.com).


FAMILY	REMOTE OUTPUT CAPACITY			
	STANDARD COMBO	COMBO/NI-CAD BATTERY (N)	COMBO/HIGH-OUTPUT BATTERY (HO)	COMBO/NO HEADS (RO) AND HIGH-OUTPUT BATTERY (HO)
LHQM	NA	NA	12W	24W

AC LAMP	ELECTRICAL APPLICATION DATA								STANDARD LAMP	WATTS
	AC INPUT			OUTPUT VOLTS	OUTPUT WATTS					
	VOLTS	AMPS	WATTS		1-1/2 HRS	2 HRS	3 HRS			
LED Red/Green	120	.23	3.3	6	14	10	7	MR24 K0606	5.4	
LED Red/Green	277	.23	3.3	6 (HO)	24	18	12	MR24 K0606	5.4	

ACCESSORIES	
ORDER SEPARATELY	
ELA MR24 K0606	Compact MR24 remote head (6W, 6V krypton lamp)
ELA MR24 K0906	Compact MR24 remote head (9W, 6V krypton lamp)
ELA NX H0606	NEMA 4X sealed-beam remote fixture (6W, 6V halogen lamp)
ELA WG3	Wireguard (back mount only)

Drawings are for dimensional detail only and may not represent actual mechanical configuration. Dimensions are shown in inches (centimeters) unless otherwise noted.

Shipping weight 7.36 lbs (3.3 kg)

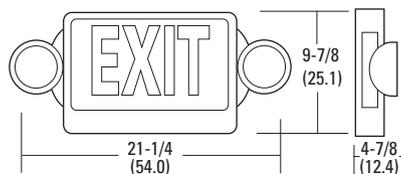

Notes

- 1 Not available with HO.
- 2 Available with stencil on panel faces in white housing and red letters only.