



|                |      |
|----------------|------|
| Catalog Number |      |
| Notes          | Type |

## FEATURES & SPECIFICATIONS

### INTENDED USE

Provides general illumination for outdoor use in residential and light commercial applications. Ideal for walkways, yards, patios, play areas and driveways creating an inviting exterior space as well as providing safety and security.

### ATTRIBUTES

Dusk-to-dawn photocell automatically turns on at dusk and off at dawn for convenience and energy savings. Rugged, weather and rust resistant die-cast aluminum housing in bronze or white finish. 7" clear acrylic diffuser provides a wide spread uniform illumination.

Standard with 70W normal power factor ballast (120 volt, 60Hz). Starts instantly down to 0°F (-18°C).

Includes (1) 70W high pressure sodium (HPS) medium base lamp.

### LISTING

CUL listed to US and Canadian safety standards and suitable for wet locations.

### WARRANTY


Guaranteed for one year against mechanical defects in manufacture.

Outdoor General Purpose

# Area Light

## Dusk-to-Dawn - Designer

High Pressure Sodium

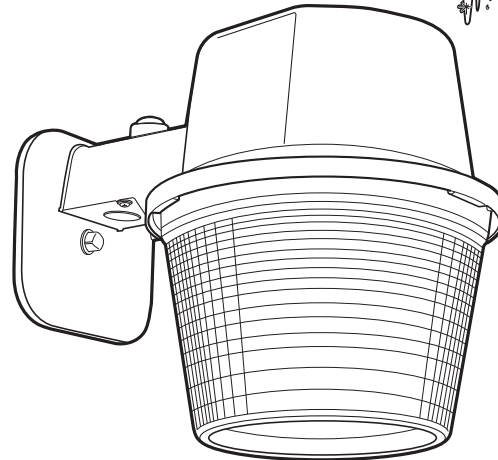


## DIMENSIONS

| Fixture Source | Lamp Configuration | Model Number | Number of Lamps               | (A) Width inches (cm) | (B) Height inches (cm) | (C) Extension* inches (cm) |
|----------------|--------------------|--------------|-------------------------------|-----------------------|------------------------|----------------------------|
| HPS            |                    | OALDA 70S    | (1) 70 (HPS) medium base lamp | 7-5/8" (19.25)        | 10-7/8" (27.38)        | 8-3/4" (21.18)             |

\* Maximum extension from wall

All dimensions are in inches (centimeters)

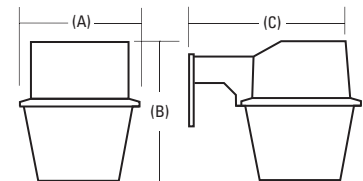

## ORDERING INFORMATION

Choose the boldface catalog nomenclature that best suits your needs and write it on the appropriate line. Order accessories as separate catalog numbers.

Example: **OALDA 70S 120 P LP BZ <4**

|  |
|--|
| <b>Model Number<sup>1</sup></b>  |
| <b>OALDA 70S 120 P LP</b> (1) 70W (HPS) medium base lamp <b>Included</b> |

|                  |
|------------------|
| <b>Finish</b>    |
| <b>BZ</b> Bronze |

|                                       |
|---------------------------------------|
| <b>Master Pack</b>                    |
| <b>M4</b> (4) Master packs per carton |

Notes:

1. **INCLUDES** - (1) 70W (HPS) medium base lamp.

# Area Light Outdoor General Purpose

---

## PHOTOMETRICS

Full photometric data report available within 2 weeks from request. Consult factory.



**Consumer Products**

One Lithonia Way, Conyers, GA 30012

Phone: 800-748-5070 Fax: 770-860-3903

In Canada: 160 Avenue Labrosse, Point-Claire, P.Q., H9R 1A1

[www.lightahome.com](http://www.lightahome.com)