

Catalog Number
Notes
Type

FEATURES & SPECIFICATIONS

INTENDED USE

Provides years of maintenance-free general illumination for residential and commercial outdoor applications such as yards, driveways, patios, loading areas and warehouses. Motion activation deters intruders.

CONSTRUCTION

Three tool-free adjustable heads allow for easy aiming up/down or side to side.

Rugged cast aluminum, corrosion-resistant housing in bronze or white.

Clear acrylic lenses are fully gasketed to keep out moisture, dirt and bugs.

120V driver operates at 60Hz.

Rated for outdoor installations, -40°C minimum ambient.

OPTICS

High-performance 5000K CCT LEDs produce 1719 lumens and maintain 70% of light output at 50,000 hours of service. (Nominal correlated color temperature per ANSI C78-377-2008; LED lifespan based on IESNA LM-80-08 results and calculated per IESNA TM-21-11 methodology.)

Dual array motion sensor provides 180° detection with up to 70 feet forward range, and additional downward perimeter protection for added security.

Sensitivity and on-time adjustable knobs provide precision control, and the sensor has a manual override option.

An integrated photocell prevents activation during daylight.

INSTALLATION

Mounts easily to existing junction box on wall or under building eave.

Adjustable heads allow precise illumination.

Not recommended to wire multiple fixtures in parallel.

LISTINGS

UL/C-UL Certified to US and Canadian safety standards. Wet location listed for mounting higher than 4' off the ground.

WARRANTY

Five-year limited warranty. Full warranty terms located at

www.acuitybrands.com/CustomerResources/Terms_and_conditions.aspx.

NOTE: Specifications are subject to change without notice.


Actual performance may differ as a result of end-user environment and application.

Outdoor General Purpose

OFLR 9 MO

LED FLOODLIGHT WITH MOTION SENSOR
3 ADJUSTABLE HEADS

High Performance LED

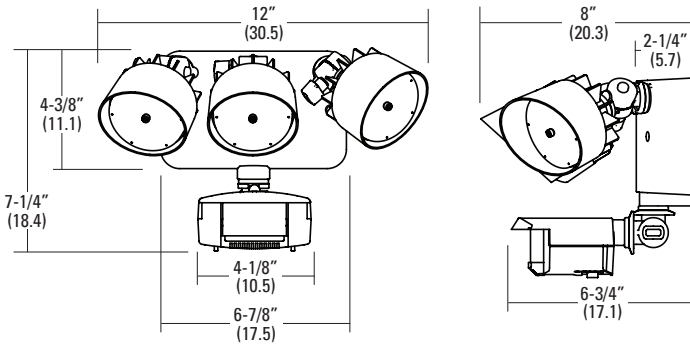

All dimensions are inches (centimeters).

ORDERING INFORMATION

All configurations of this product are considered "standard" and have short lead times.

Example: OFLR 9LC 120 MO BZ

OFLR	9LC	120	MO	
Series	Number of LEDs	Voltage	Features	Finish
OFLR LED floodlight	9LC 9 LEDs, 3 heads	120 120 volts	MO Motion sensor	BZ Bronze WH White

3-Head LED Floodlight with Motion Sensor

PHOTOMETRICS

Full photometric data report available within 2 weeks from request. Consult factory.

